




SOFT-CLOSE HINGE




HG-JHW / HG-JHWG




- Soft-Close damper keeps lid from slamming shut.
- Surface mount type.
- Two different damper direction available for various application.
- Operating temperature: 32~104°F (0~40°C)
- Operating angle: 115°/Dead angle 5°

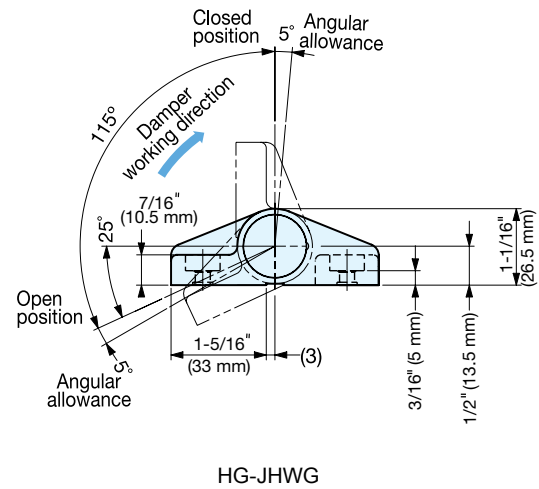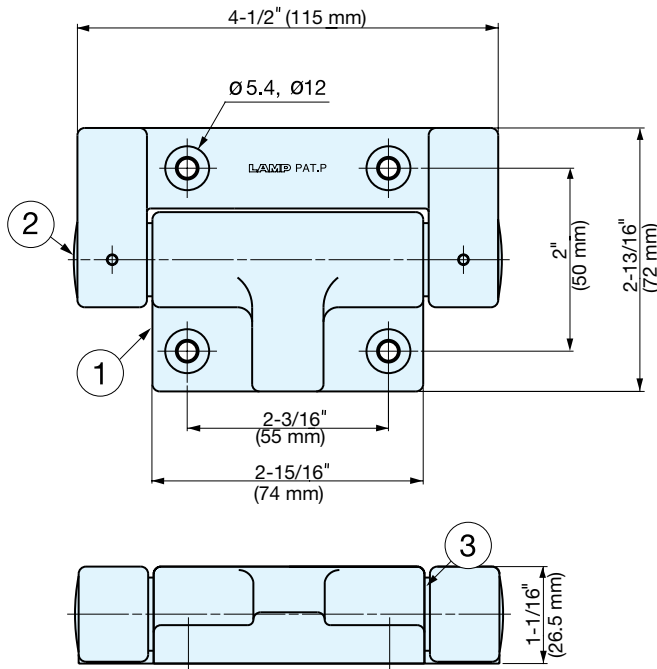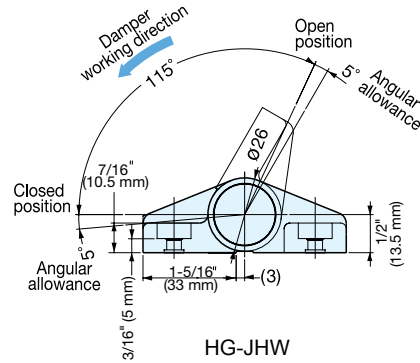

Installation

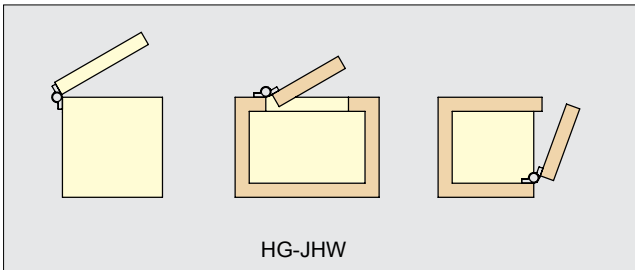

Installation

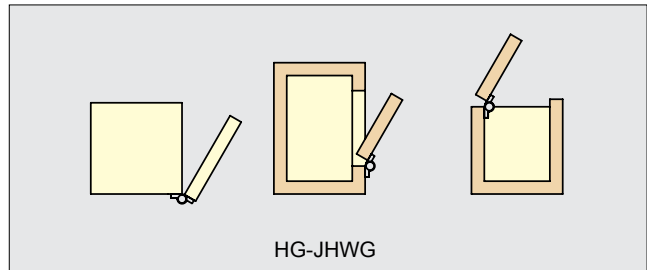

Item No.	Torque per pair	Weight (g)	Box (pcs)	Carton (pcs)
HG-JHW50	53~88 lbs-in (61~102 kgf-cm)	200	4	64
HG-JHW70	88~124 lbs-in (102~143 kgf-cm)			
HG-JHWG50	53~88 lbs-in (61~102 kgf-cm)			
HG-JHWG70	88~124 lbs-in (102~143 kgf-cm)			

No.	Part Name	Material	Color
①	Bracket	PBT Plastic/Zinc Alloy	Dark Grey
②	Cap	Polypropylene	
③	Damper	304 Stainless Steel	Plain

\* Sold per piece.