



FOLDING HANDLE



HK



- 90° folding handle. Can be tilted when not in use.
- Handle clicks (temporary holding function) into open and closed position.

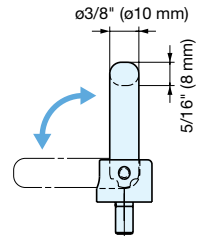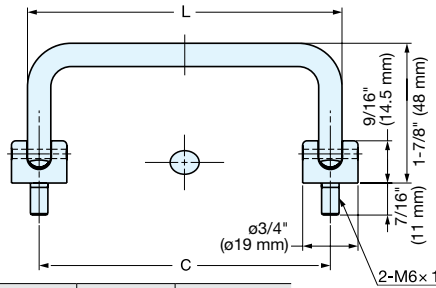

| Item No. | C | L | Load Capacity | Weight (g) | Box (pcs) | Carton (pcs) |
|----------|-------------------|------------------|-----------------|------------|-----------|--------------|
| HK-80 | 3-1/8" (80 mm) | 3-7/16" (88 mm) | 110 lbs (50 kg) | 125 | 10 | 100 |
| HK-100 | 3-15/16" (100 mm) | 4-1/4" (108 mm) | | 136 | | |
| HK-120 | 4-3/4" (120 mm) | 5-1/16" (128 mm) | | 146 | | |


| Material | Finish |
|---------------------|--------|
| 304 Stainless Steel | Mirror |

TRANSOM HANDLE



2LC

- Ideal for harsh and high corrosive environments.

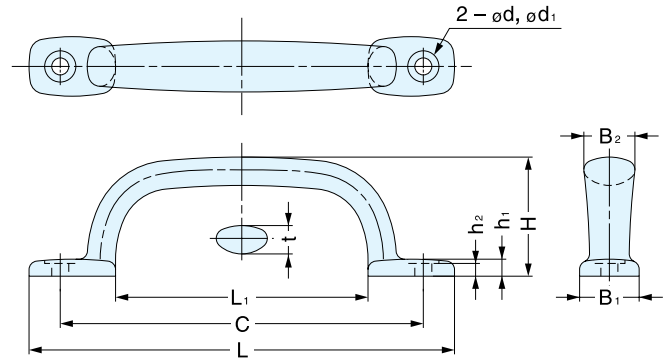

| Material | Finish |
|---------------------|--------|
| 316 Stainless Steel | Mirror |

| Item No. | L | L ₁ | C | B ₁ | B ₂ | H | h ₁ | h ₂ | t | d | d ₁ | Weight (g) | Box (pcs) | Carton (pcs) | Screw |
|----------|-------------------|-----------------|------------------|----------------|----------------|-----------------|----------------|----------------|--------------|--------------|----------------|------------|-----------|--------------|--------|
| 2LC-80 | 3-1/8" (80 mm) | 1-1/4" (32 mm) | 2-1/2" (64 mm) | 5/8" (16 mm) | 9/16" (14 mm) | 1-3/8" (35 mm) | 1/4" | 3/16" (4 mm) | 5/16" (8 mm) | 3/16" (5 mm) | 3/8" (9.5 mm) | 70 | 12 | 144 | 4 × 20 |
| 2LC-120 | 4-3/4" (120 mm) | 2-1/2" (64 mm) | 3-3/4" (96 mm) | 11/16" (18 mm) | 5/8" (16 mm) | 1-7/16" (36 mm) | (5.5 mm) | 3/16" (9 mm) | 3/8" (9 mm) | (5 mm) | (9.5 mm) | 106 | 8 | 96 | |
| 2LC-150 | 5-15/16" (150 mm) | 3-1/2" (89 mm) | 5-1/16" (128 mm) | 13/16" (21 mm) | 11/16" (18 mm) | 1-5/8" (42 mm) | 1/4" | (4.5 mm) | 3/8" | 1/4" | 7/16" (11 mm) | 172 | 6 | 72 | 5 × 32 |
| 2LC-180 | 7-1/16" (180 mm) | 4-5/8" (118 mm) | 6-5/16" (160 mm) | 15/16" (23 mm) | 13/16" (20 mm) | 1-3/4" (45 mm) | 1/4" | (6.5 mm) | 3/16" | (6 mm) | (11 mm) | 225 | 3 | 36 | |