



# HANDLE

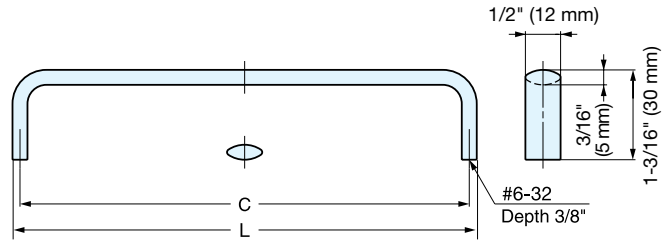

## KC-S

• Ideal for harsh and high corrosive environments.

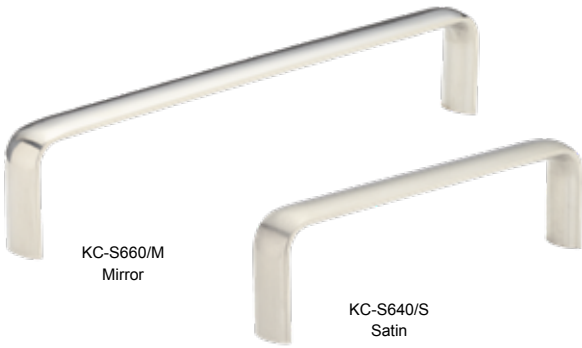

Item No.	L	C	Weight (g)	Box (pcs)	Carton (pcs)
KC-S635/M KC-S635/S	3-11/16" (93.9 mm)	3-1/2" (88.9 mm)	67	20	200
KC-S640/M KC-S640/S	4-3/16" (106.6 mm)	4" (101.6 mm)	71		
KC-S650/M KC-S650/S	5-3/16" (132 mm)	5" (127 mm)	85		
KC-S660/M KC-S660/S	6-3/16" (157.4 mm)	6" (152.4 mm)	95		


Material	Finish
316 Stainless Steel	Mirror (M) Satin (S)

# HANDLE



## EK-S

• Ideal for harsh and high corrosive environments.

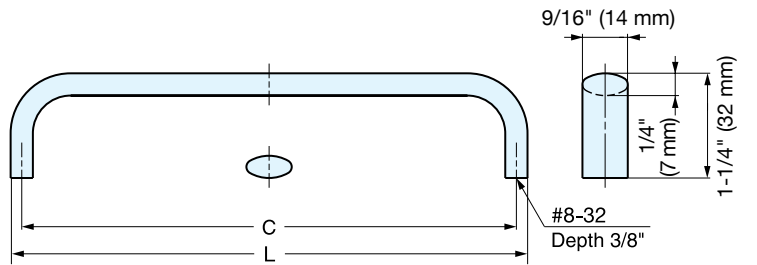


Item No.	L	C	Weight (g)	Box (pcs)	Carton (pcs)
EK-S635/M EK-S635/S	3-3/4" (95.9 mm)	3-1/2" (88.9 mm)	90	20	200
EK-S640/M EK-S640/S	4-1/4" (108.6 mm)	4" (101.6 mm)	91		
EK-S650/M EK-S650/S	5-1/4" (134 mm)	5" (127 mm)	113		
EK-S660/M EK-S660/S	6-1/4" (159.4 mm)	6" (152.4 mm)	122		

Material	Finish
316 Stainless Steel	Mirror (M) Satin (S)

# HANDLE



## XL-JS

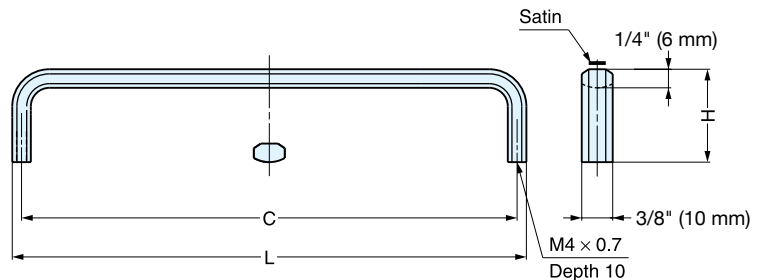

Item No.	L	C	H	Weight (g)	Box (pcs)	Carton (pcs)
XL-JS165TT	6-9/16" (166 mm)	6-5/16" (160 mm)	1-3/16" (30 mm)	81	15	150
XL-JS260TT	10-1/4" (260 mm)	10" (254 mm)	1-5/16" (33 mm)	122	10	100
XL-JS360TT	14-1/16" (358 mm)	13-7/8" (352 mm)	1-7/16" (36 mm)	166		

Material	Finish
316 Stainless Steel	Mirror and Satin Combination