


## STAINLESS STEEL MAGNETIC CATCH (ULTRA-THIN/BACK MOUNT) MC-159-ST



- The bolts are designed to be fixed with nuts from the back side.
- As there are no screw heads, it is easy to install and keep the flat surface clean
- Neodymium magnet for strong magnetic force.
- Ultra-thin design with 1/8" (3 mm) thickness.
- Counter plate of back-mount type is also available.

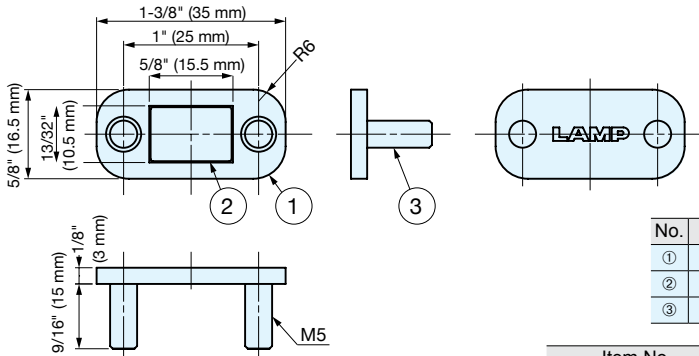


| No. | Part Name | Material            | Finish          |
|-----|-----------|---------------------|-----------------|
| ①   | Body      | 430 Stainless Steel | Barrel Polished |
| ②   | Magnet    | Zinc Alloy          | Neodymium       |
| ③   | Stud Bolt | 303 Stainless Steel | -               |

| Item No.    | Magnetic Force  | Weight (g) | Box (pcs) | Carton (pcs) |
|-------------|-----------------|------------|-----------|--------------|
| MC-159-2-ST | 4.41 lbs (2 kg) | 14         | 400       | 1200         |
| MC-159-4-ST | 8.82 lbs (4 kg) |            |           |              |

## STAINLESS STEEL COUNTER PLATE (BACK MOUNT) MC-159U-ST



- The bolts are designed to be fixed with nuts from the back side.
- As there are no screw heads, it is easy to install and keep the flat surface clean

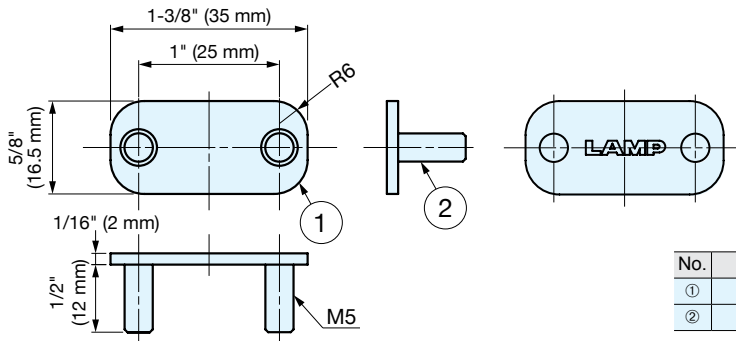

| No. | Part Name | Material            | Finish          |
|-----|-----------|---------------------|-----------------|
| ①   | Body      | 430 Stainless Steel | Barrel Polished |
| ②   | Stud Bolt | 303 Stainless Steel | -               |

| Item No.   | Weight (g) | Box (pcs) | Carton (pcs) |
|------------|------------|-----------|--------------|
| MC-159U-ST | 13.2       | 50        | 1000         |