


MAGNETIC CATCH (SNAP-IN TYPE)



MC-FS34

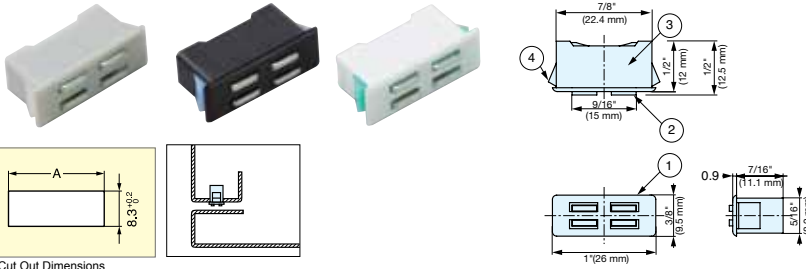

- Snap-in magnetic catch for sheet metal applications.
- Compact size

Item No.	Body Color	Spring Color	Magnetic Force	Weight (g)	Box (pcs)	Carton (pcs)
MC-FS34WW	White	White	2.9 lbs (1.3 kg)	5.3	200	2000
MC-FS34GW	Grey		4.8 lbs (2.2 kg)			
MC-FS34WB	White	Blue	2.9 lbs (1.3 kg)			
MC-FS34BB	Black		4.8 lbs (2.2 kg)			
MC-FS34GB	Grey	Green	2.9 lbs (1.3 kg)			
MC-FS34WG	White		4.8 lbs (2.2 kg)			
MC-FS34GG	Grey		4.8 lbs (2.2 kg)			


Item No.	Panel Thickness	A (mm)
MC-FS34WW/GW	0.5	22.6 +0.2, 0
	0.8	23.7 +0.2, 0
MC-FS34WB/BB/GB	1.0	22.7 ±0.1
	1.2	23.5 ±0.1
	1.4	24.0 ±0.1
MC-FS34WG/GG	1.6	22.7 ±0.1
	2.0	23.8 ±0.1

No.	Part Name	Material	Finish/Color
①	Body	Polyamide	Gray/Black/White
②	Yoke	Steel	Yellow Zinc Chromate
③	Magnet	Ferrite	-
④	Spring	Polyacetal	Blue/Green/White

MAGNETIC CATCH (SNAP-IN TYPE)



MC-FS

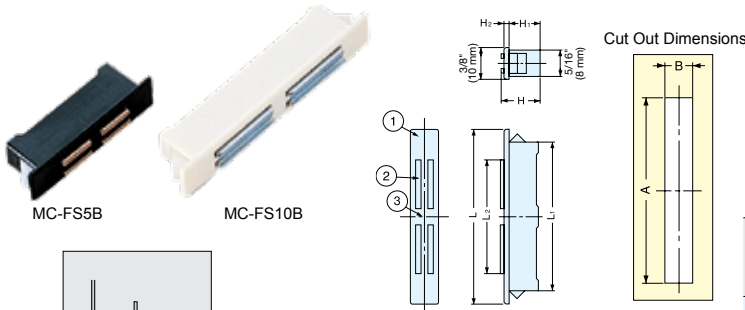

- Snap-in magnetic catch for sheet metal applications.

No.	Part Name	Material	Finish/Color
①	Housing	ABS	White (W), Black (B)
②	Yoke	Steel	Yellow Zinc Chromate
③	Magnet	Ferrite	-


Door Thickness	Cut Out Dimensions			
	MC-FS5		MC-FS10	
	A	B	A	B
0.8	21/64" (8.2 mm)	21/64" (8.2 mm)	2-5/32" (55mm)	21/64" (8.2 mm)
1.0			2-3/16" (55 mm)	
1.2			2-13/64" (56 mm)	
1.6			2-7/32" (56.5 mm)	
2.0			2-7/32" (56.5 mm)	

Item No.	L	L ₁	L ₂	H	H ₁	H ₂	Magnetic Force	Wt (g)	Box (pcs)	Ctn (pcs)
MC-FS5W/B	1-9/16" (40 mm)	1-5/16" (33.9 mm)	7/8" (21.6 mm)	17/32" (13.5 mm)	7/16" (11.2)	1/16" (1.2)	4.8 lbs (2.2 kg)	9	200	2000
MC-FS10W/B	2-1/2" (64 mm)	2-1/8" (54.5 mm)	1-11/16" (43 mm)	35/64" (14 mm)	7/16" (11.5)	1/16" (1.5)	9.9 lbs (4.5 kg)	20	50	1000

MAGNETIC CATCH (SNAP-IN TYPE)



MC-FP

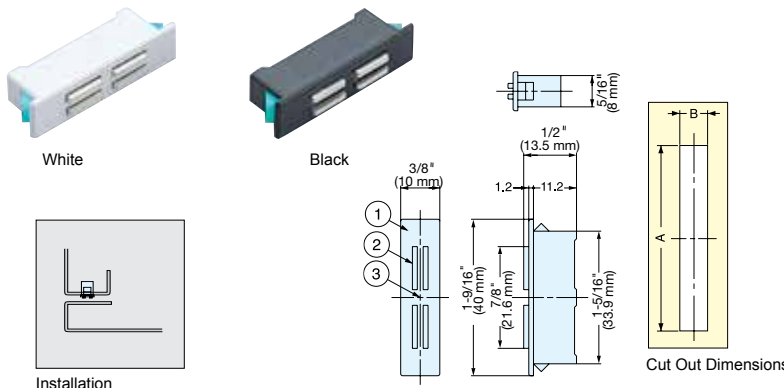

- Snap-in magnetic catch for sheet metal applications.
- Small design with a strong magnetic force.

No.	Part Name	Material	Finish/Color
①	Housing	ABS	White (WT), Black (BL)
②	Yoke	Steel	Yellow Zinc Chromate
③	Magnet	Neodymium	-

Door Thickness	Cut Out Dimensions	
	A	B
0.8	1-5/16" (34.1 mm)	5/16" (8.2 mm)
1.0		
1.2		
1.6		
2.0	1-7/16" (36.5 mm)	

Item No.	Magnetic Force	Weight (g)	Box (pcs)	Carton (pcs)
MC-FP5SWT	9.9 lbs (4.5 kg)	9	200	2000
MC-FP5SBL				