

LARGE HANDLE



MDH

HANDLES


LARGE HANDLES

- Handle bars available in 304 stainless steel (304SS) or carbon fiber reinforced polymer (CFRP). Posts are zinc die cast with a chrome (CR) finish.
- Includes hexagonal M8 × 15 bolts.
- Assembly required.




MDH-PS




MDH-PC

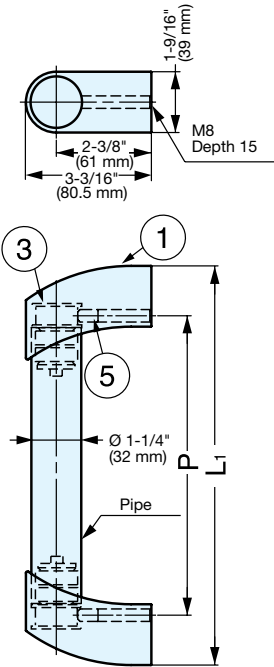

INLINE

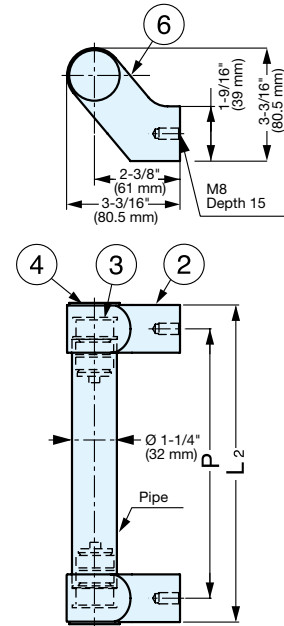

OFFSET

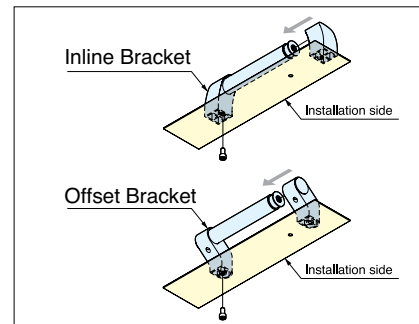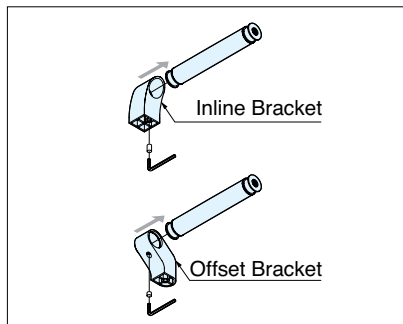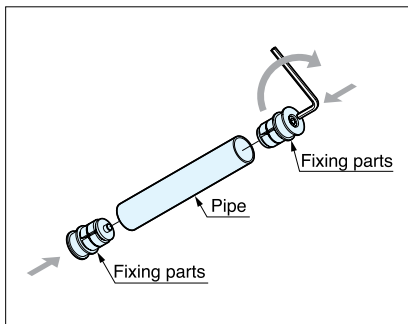

No.	Part Name	Material	Finish/Color
①	Bracket (Straight)	Zinc Alloy	Matte Chrome
②	Bracket (Offset)		
③	Fixing Parts		
④	Cover	Polyacetal	
⑤	HEX set screw M8x15	Stainless Steel	Black
⑥	HEX set screw M8x8		Plain

Item No.	Material	P	L ₁	L ₂	Weight (g)	
MDH-PS192	304 Stainless Steel	7-9/16" (192 mm)	10-1/16" (256 mm)	8-7/8" (226 mm)	1386	1506
MDH-PS350		13-3/4" (350 mm)	16-5/16" (414 mm)	15-1/8" (384 mm)	1729	1849
MDH-PS500		19-11/16" (500 mm)	22-3/16" (564 mm)	21" (534 mm)	2052	2172
MDH-PS800		31-1/2" (800 mm)	34" (864 mm)	32-13/16" (834 mm)	2702	2822
MDH-PS1200		47-1/4" (1200 mm)	49-3/4" (1264 mm)	48-9/16" (1234 mm)	3572	3692
MDH-PC192	CFRP	7-9/16" (192 mm)	10-1/16" (256 mm)	8-7/8" (226 mm)	1072	1192
MDH-PC350		13-3/4" (350 mm)	16-5/16" (414 mm)	15-1/8" (384 mm)	1134	1254
MDH-PC500		19-11/16" (500 mm)	22-3/16" (564 mm)	21" (534 mm)	1193	1313
MDH-PC800		31-1/2" (800 mm)	34" (864 mm)	32-13/16" (834 mm)	1311	1431
MDH-PC1200		47-1/4" (1200 mm)	49-3/4" (1264 mm)	48-9/16" (1234 mm)	1469	1589