

KNOB



MRB

MRB-S/CR
Chrome




MRB-S/SN
Satin Nickel



MRB-L/PB-T
Polished Brass



MRB-L/SMK-T
Smoke

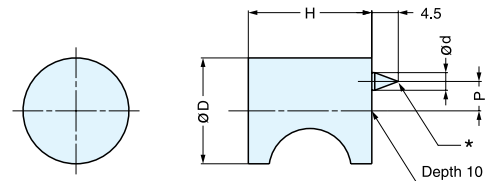

*MRB-L No anti-rotation pin.

| Material | Finish |
|----------|----------------------------------|
| Brass | Chrome (CR) |
| | Polished Brass (PB)/(MRB-L only) |
| | Smoke (SMK)/(MRB-L only) |
| | Satin Nickel (SN) |

| Item No. | D | H | P | d | Weight (g) | Box (pcs) | Carton (pcs) | Screw |
|-------------|----------------|----------------|--------------|-------------|------------|-----------|--------------|-----------|
| MRB-S/CR | 11/16" (18 mm) | 13/16" (21 mm) | 3/16" (5 mm) | 1/8" (3 mm) | 38 | 30 | 300 | M4 x 25 |
| MRB-S/SN | | | | | | | | |
| MRB-L/CR-T | 15/16" (24 mm) | | - | - | 70 | | | #8-32 x 1 |
| MRB-L/PB-T | | | | | | | | |
| MRB-L/SMK-T | | | | | | | | |
| MRB-L/SN-T | | | | | | | | |

KNOB




SY



SY-16/SN
Satin Nickel



SY-22/PB
Polished Brass

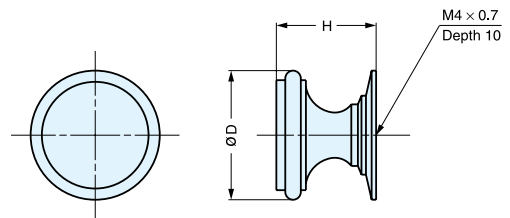

| Material | Finish |
|----------|---------------------|
| Brass | Polished Brass (PB) |
| | Satin Nickel (SN) |

Please specify the finish when ordering.

| Item No. | D | H | Weight (g) | Box (pcs) | Carton (pcs) |
|----------|--------------|----------------|------------|-----------|--------------|
| SY-16 | 5/8" (16 mm) | 9/16" (15 mm) | 10 | 40 | 400 |
| SY-22 | 7/8" (22 mm) | 11/16" (17 mm) | 21 | 30 | 300 |

KNOB



MKZ



MKZ-S/SMK
Smoke



MKZ-S/PB
Polished Brass




MKZ-L/SB
Satin Brass



MKZ-L/SN
Satin Nickel



MKZ-S/CR
Chrome

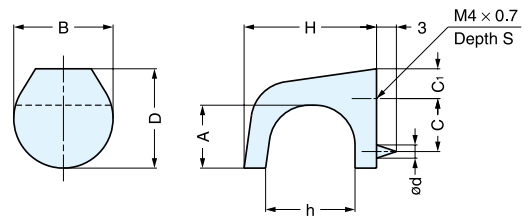

| Material | Finish |
|------------|--|
| Zinc Alloy | Chrome (CR), Polished Brass (PB), Smoke (SMK), Satin Brass (SB), Satin Nickel (SN) |

Please specify the finish when ordering.

| Item No. | D | A | B | H | h | C | C ₁ | d | S | Weight (g) | Box (pcs) | Carton (pcs) |
|----------|----------------|----------------|----------------|----------------|----------------|---------------|----------------|--------------|-------------|------------|-----------|--------------|
| MKZ-S | 9/16" (15 mm) | 3/8" (9.5 mm) | 9/16" (15 mm) | 13/16" (20 mm) | 1/2" (13.5 mm) | 5/16" (8 mm) | 3/16" (4.5 mm) | 1/16" (2 mm) | 1/4" (6 mm) | 11 | 50 | 500 |
| MKZ-L | 13/16" (21 mm) | 1/2" (12.5 mm) | 13/16" (20 mm) | 1" (26 mm) | 11/16" (17 mm) | 7/16" (11 mm) | | | 1/4" (7 mm) | 29 | | |