

RECESSED HOOK



NF-K

HOOKS

RECESSED HOOK



Pearl Chrome

Chrome

Matte Black




- The arm section is spring loaded to automatically retract when not in use.
- The product does not protrude when the arm is folded in, creating a flush design and ensuring safety.
- Can also be mounted to sheet metal using the NF-50D or NF-50 bracket (sold separately).
- Round type (NF-R) also available.


Recommended Screw:

- 4x15 cross-recessed pan head or tapping screws. For panel thickness 1"~1-1/8" (25-29 mm)
- 4x20 cross-recessed pan head or tapping screws. For panel thicker than 1-3/16" (30 mm)


NF-K52

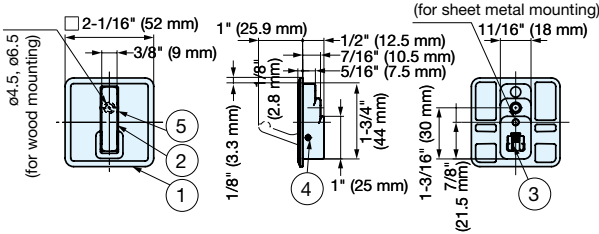


Wood Mounting (thickness 1"~1-1/8" (25-29 mm))

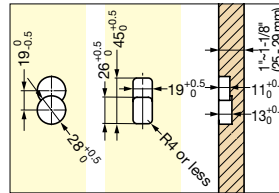


Wood Mounting (thickness 1-3/16" (30 mm) or more)

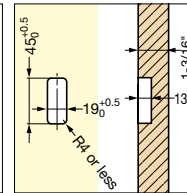


Sheet Metal Mounting

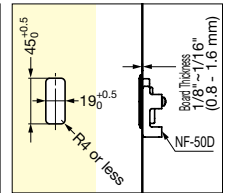


NF-K64

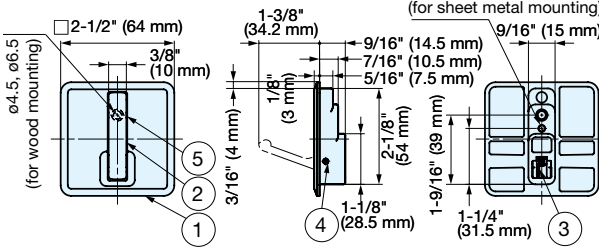


Wood Mounting (thickness 1"~1-1/8" (25-29 mm))

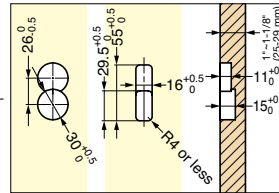


Wood Mounting (thickness 1-3/16" (30 mm) or more)

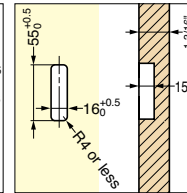


Sheet Metal Mounting

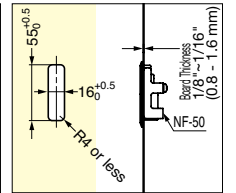


NF-K77

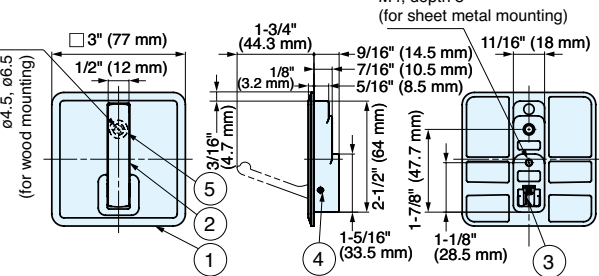


Wood Mounting (thickness 1"~1-1/8" (25-29 mm))

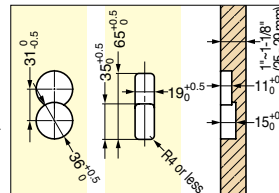

Wood Mounting (thickness 1-3/16" (30 mm) or more)

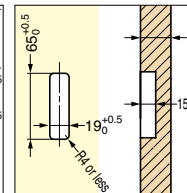

Sheet Metal Mounting

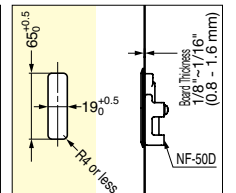

Item No.	Finish	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
NF-K52-SCR	Pearl Chrome Plating	44 lbs (20 kg)	77	10	120
NF-K52-CR	Chrome Plating				
NF-K52-BL	Matte Black				
NF-K64-SCR	Pearl Chrome Plating	44 lbs (20 kg)	95	10	120
NF-K64-CR	Chrome Plating				
NF-K64-BL	Matte Black				
NF-K77-SCR	Pearl Chrome Plating	44 lbs (20 kg)	145	10	120
NF-K77-CR	Chrome Plating				
NF-K77-BL	Matte Black				

No.	Part Name	Material
①	Body	Zinc Alloy
②	Arm	
③	Spring	304 Stainless Steel
④	Knurled Pin	303 Stainless Steel
⑤	Cushioning Rubber	Chloroprene Rubber