

RECESSED HOOK



NF-R

HOOKS

RECESSED HOOK



Dull Chrome



Chrome




Matte Black

- Hook is spring loaded to retract.
- Ideal for vibration or shock application.




No.	Part Name	Material
①	Main Body	Zinc Alloy (ZDC)
②	Arm	
③	Spring	304 Stainless Steel
④	Knurled Pin	303 Stainless Steel
⑤	Cushioning Rubber	Chloroprene Rubber (CR)


NF-R52

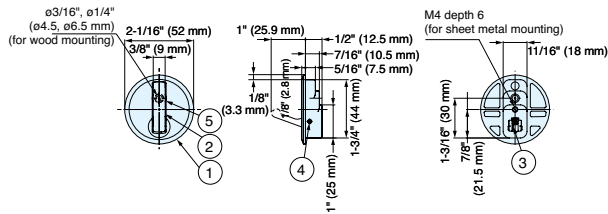


Wood Mounting (thickness 25-29 mm)

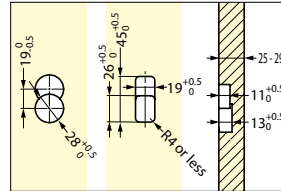


Wood Mounting (thickness 30 mm or more)

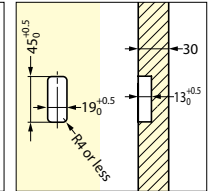


Metal Sheet Mounting

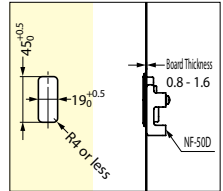


NF-R64

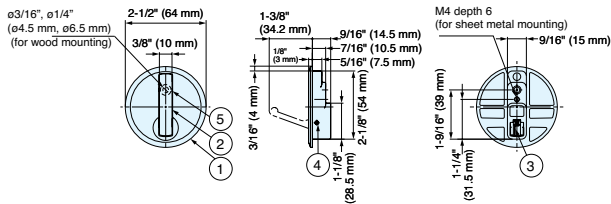


Wood Mounting (thickness 25-29 mm)

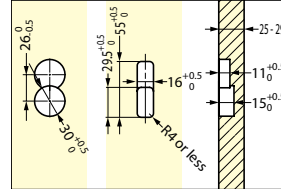


Wood Mounting (thickness 30 mm or more)

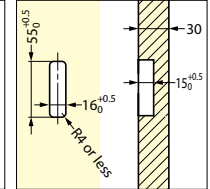


Metal Sheet Mounting

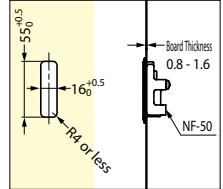


NF-R77

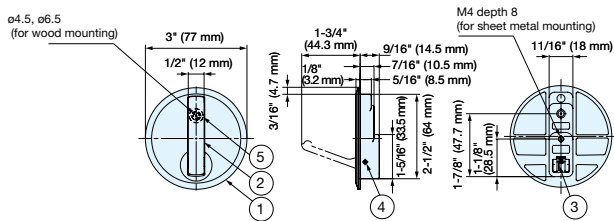


Wood Mounting (thickness 25-29 mm)

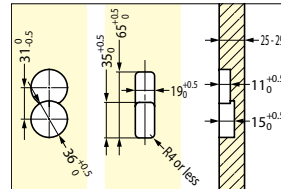

Wood Mounting (thickness 30 mm or more)

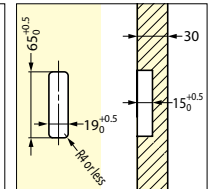

Metal Sheet Mounting

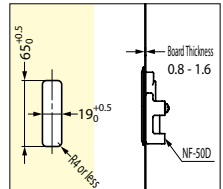

Item No.	Load Capacity	Weight (g)	Finish	Box (pcs)	Carton (pcs)	Material
NF-R52-SCR	44 lbs (20 kg)	70	Dull Chrome	10	120	Zinc Alloy
NF-R52-CR			Chrome Plating	10	120	
NF-R52-BL			Matte Black	10	120	
NF-R64-SCR		90	Dull Chrome	10	120	
NF-R64-CR			Chrome Plating	10	120	
NF-R64-BL			Matte Black	10	120	
NF-R77-SCR		130	Dull Chrome	10	120	
NF-R77-CR			Chrome Plating	10	120	
NF-R77-BL			Matte Black	10	120	