

ADJUSTABLE SOFT-DOWN STAY






NSDX-10

LID SUPPORTS

ADJUSTABLE SOFT-DOWN STAYS



- For DOWNWARD-OPENING FLAP DOOR used with piano, butt or drop Hinges (SDH-001, SDH-P, P.238).
- NSDX-10 is designed to hold door in closed position.
- Speed adjustment screw located on front for easy adjustment.
- Torque Calculation:
 $Torque = Door\ Height \times 0.5 \times Door\ Weight$
 Per Piece: 19~60 lbs-in (20~70 kg-cm)
 Per Pair: 38~120 lbs-in (40~140 kg-cm)

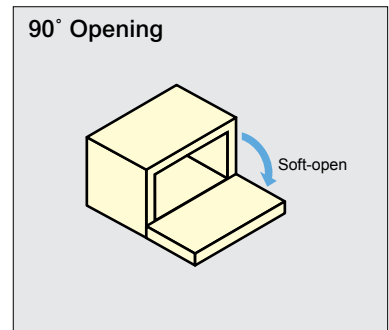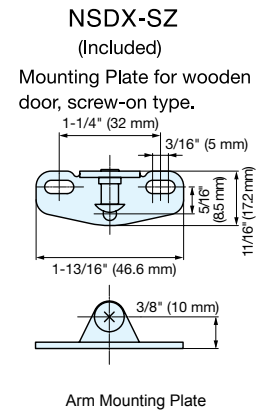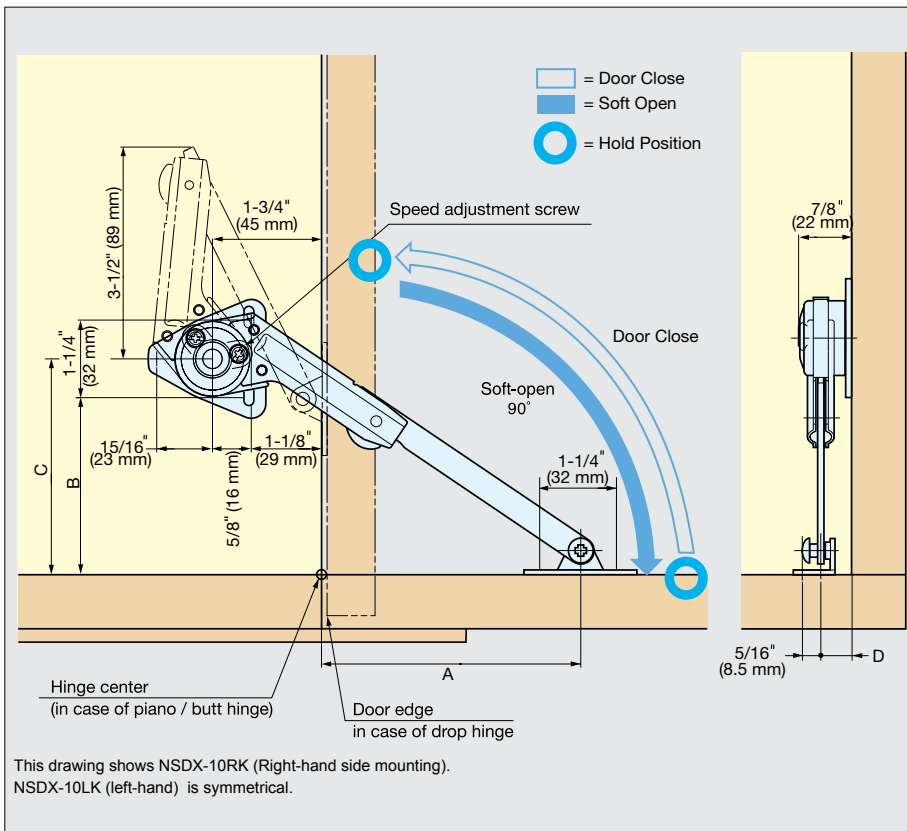

Hinge Type	A	B	C	D
☆ Drop Hinge (SDH-001)	3-13/16" (97 mm)	3-9/16" (91 mm)	4-3/16" (107 mm)	7/16" (11 mm)
Piano/Butt Hinge	3-9/16" (90 mm)	3-7/8" (99 mm)	4-1/2" (115 mm)	

☆ In case overlay 16 mm

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
NSDX-10RK Right	181	20	80	Zinc Alloy	Nickel
NSDX-10LK Left				Steel	