

# CONCEALED HINGE





# RK-50

HINGES

CONCEALED HINGES



- Max. Door size :  
W 17-3/4" × H 27-9/16" (W450 × H700 mm)
- Min. Door thickness : 9/16" (15 mm)
- Max. Door weight : 5.7 lbs/pair (2.6 kg/pair)

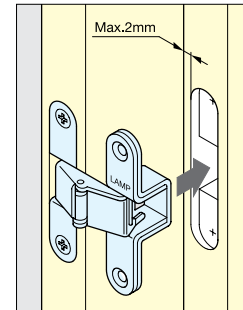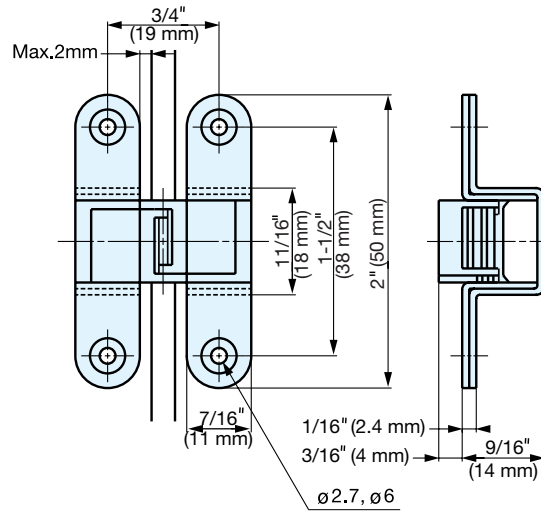

Installation

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
RK-50	28	24	240	304 Stainless Steel	Satin

## 3-WAY Adjustable Concealed Hinge HES3D Series



Sizes vary for use with 1-1/2" thick doors to a minimum of 3/4" thick doors. Find more sizes, finishes and information about the HES3D Series Hinges on page 180~184, 309~311.

