


KNOB



RS-38

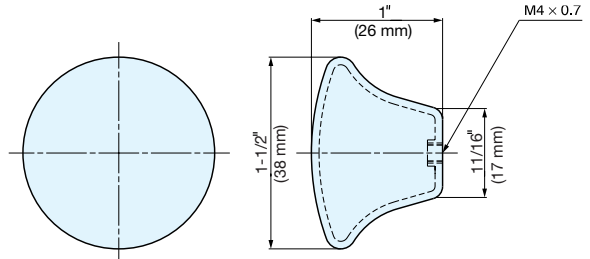

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
RS-38/S	20	20	200	304 Stainless Steel	Satin

KNOB




RSS



RSS-25/M
Mirror



RSS-50/S
Satin

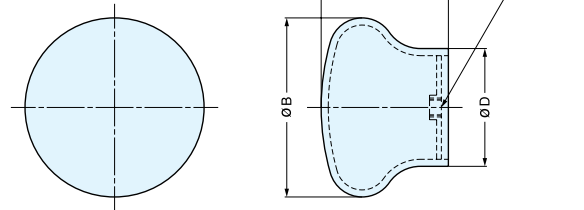

Material	Finish
304 Stainless Steel	Mirror (M) Satin (S)

Item No.	A	B	D	Weight (g)	Box (pcs)	Carton (pcs)	Screw
RSS-25/M* RSS-25/S*	7/8" (22 mm)	1" (25 mm)	11/16" (18 mm)	8.5	20	200	M4 x 30
RSS-30/M* RSS-30/S*	15/16" (23 mm)	1-3/16" (30 mm)	13/16" (20 mm)	11.0			M4 x 30
RSS-38/M RSS-38/S	1-1/16" (27 mm)	1-1/2" (38 mm)	1" (25 mm)	16.0			M5 x 30
RSS-50/M RSS-50/S	1-5/16" (34 mm)	2" (50 mm)	1-3/8" (35 mm)	30.0			M5 x 30

*NSF Compliant

KNOB



DJ-22




DJ-22/SNI
Satin Nickel



DJ-22/PB
Polished Brass



DJ-22/CR
Chrome

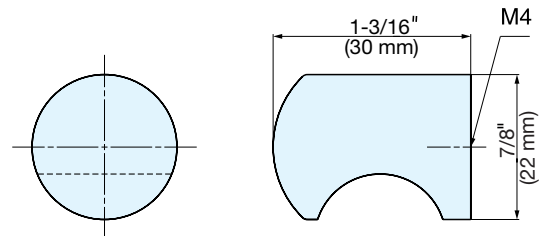

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
DJ-22/SNI	80	20	200	Brass	Satin Nickel (SN)
DJ-22/PB					Chrome (CR)
DJ-22/CR					Polished Brass (PB)

Please specify the finish when ordering.