

# AUTOMATIC HEIGHT ADJUSTING LEVELING GLIDE

**LOAD CAPACITY**  
50 kg  
110 lbs



## SAJ30

CASTERS & LEVELING GLIDES

LEVELING GLIDES



- Self height adjustment feature up to 3 mm (1/8") & 6 mm (15/64").
- Gel inside of the glide allows for gentle adjustment to uneven surfaces.
- Automatically adjusts each time the table is moved.
- Ideal for tables which are frequently moved. (e.g. Restaurants, Cafeteria, shop etc.)

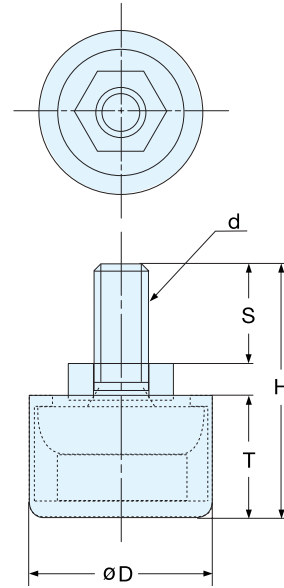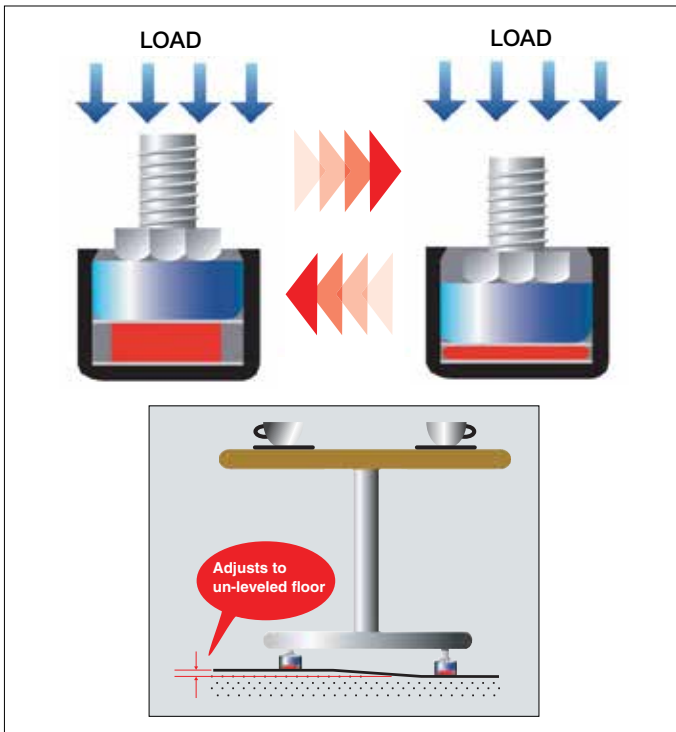

SAJ-WRENCH

Part Name	Material	Finish	Box (pcs)	Carton (pcs)
SAJ-WRENCH10 (For M6)	Steel	Yellow Zinc Chromate	1	40
SAJ-WRENCH13 (For M8)				
SAJ-WRENCH14 (For N2.5)				
SAJ-WRENCH17 (For N3,M10)				

Part Name	Material	Finish / Color
Body	Polyethylene	Black
Nut (10)	Steel	Chromate
Nut (12)		
Screw		

Item No.	Height Adjustment	D	H	T	S	d	Applicable Table Weight			Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
							6 pcs use	5 pcs use	4 pcs use				
SAJ30-10N2.5	1/8" (3 mm)	1-1/4" (32 mm)	1-5/16" (33 mm)	3/4" (19 mm)	11/32" (9 mm)	W5/16	22~39 lbs (10~18 kg)	17~33 lbs (8~15 kg)	15~26 lbs (7~12 kg)	110 lbs (50 kg)	40	400	
SAJ30-10N3			1-15/32" (37 mm)		15/32" (12 mm)	W3/8							
SAJ30-10M6			1-11/32" (34 mm)		3/8" (10 mm)	M6							
SAJ30-10M8			1-5/16" (33 mm)		11/32" (9 mm)	M8							
SAJ30-10M10			1-15/32" (37 mm)		7/16" (11 mm)	M10							
SAJ30-12N2.5			1-5/16" (33 mm)		11/32" (9 mm)	W5/16							
SAJ30-12N3			1-15/32" (37 mm)		15/32" (12 mm)	W3/8							
SAJ30-12M6			1-11/32" (34 mm)		3/8" (10 mm)	M6							
SAJ30-12M8			1-5/16" (33 mm)		11/32" (9 mm)	M8							
SAJ30-12M10			1-15/32" (37 mm)		M10								
SAJ30-12-6N2.5	1/4" (6 mm)	1-1/4" (32 mm)	1-21/32" (42 mm)	15/16" (24 mm)	7/16" (11 mm)	W5/16	39~79 lbs (18~36 kg)	33~66 lbs (15~30 kg)	26~53 lbs (12~24 kg)	110 lbs (50 kg)	40	400	
SAJ30-12-6N3					W3/8								
SAJ30-12-6M6			1-23/32" (44 mm)		15/32" (12 mm)	M6							
SAJ30-12-6M8			1-21/32" (42 mm)		3/8" (10 mm)	M8							
SAJ30-12-6M10			1-5/8" (41 mm)		3/8" (10 mm)	M10							