



Type	SDR-A300	
	Standard Sliding	
Roller	Top Recessed	Top Surfaced
Door Weight	Max. 660 lbs (300 kg)	
Door Thickness	Min. 1-3/8" (35 mm)	
Door Width	Min. 23-5/8" (600 mm)	


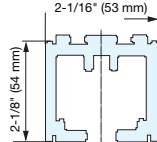
- 660 lbs (300 kg) Heavy Duty Model
- Ceiling and Barn Door Mount
- Recessed and Top Surface Mounted door brackets
- Double rollers with ball bearings
- Quiet precision movement
- Low profile minimum gap of 1/8" (3 mm) Recess Mount
- Vertical Adjustment $\pm 1/16"$ (1 mm)
 - o Recessed mount $\pm 1/4"$ (6 mm)
 - o Surface mount $\pm 1/16"$ (2 mm)

■ How to order





1. Select track and track length
 - 1A. Select any optional parts for track
2. Select a mounting type

Ordering Information



■ 1. Track Options

Track Type	Length	Item No.	Description
Standard Aluminum Track	118-1/8" (3000 mm)	SDR-A300-3000	 


■ 1A Optional Parts for Track

 SDR-A-4131 Bottom Guide Channel	 SDR-A300-30057 End Caps for Tracks	 SDR-A-4140 Bottom Guide Roller	 SDR-A300-30064 Short Bracket
---	--	--	--


■ 2. Hardware Set

Door Mount	Item No.	Set Details
Top Recessed	SDR-A300TR-PRT	 Top Recessed Roller Set
Top Surface	SDR-A300TS-PRT	 Top Surface Roller Set


TRACK MOUNTING OPTIONS

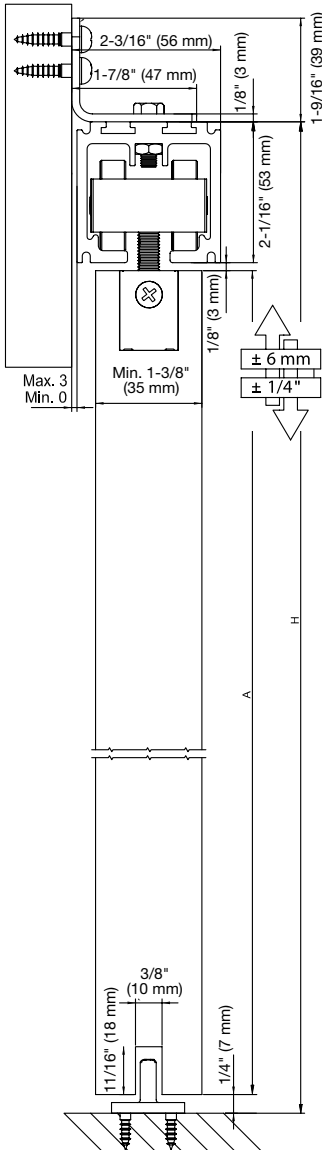

Top Recessed (SDR-A300TR)

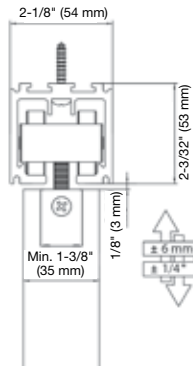


Ceiling Mount
Traditional Ceiling
mount option shown
with recessed rollers.

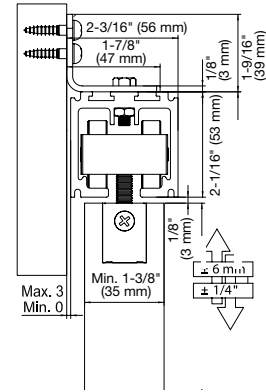


**Wall Mount w/
Short Bracket**
Top track short bracket
for Barn Door style
mounting that allows fast
and simple installation.

Top Surface (SDR-A300TS)

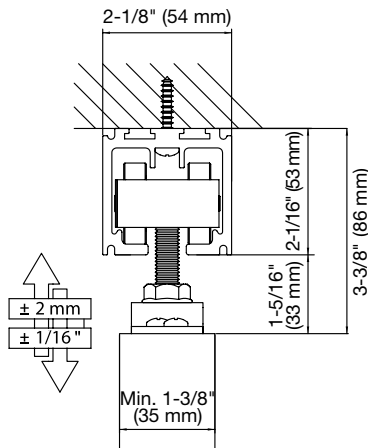



Ceiling Mount
Traditional Ceiling
mount option shown.
Fascia can be mounted
on both sides if needed.

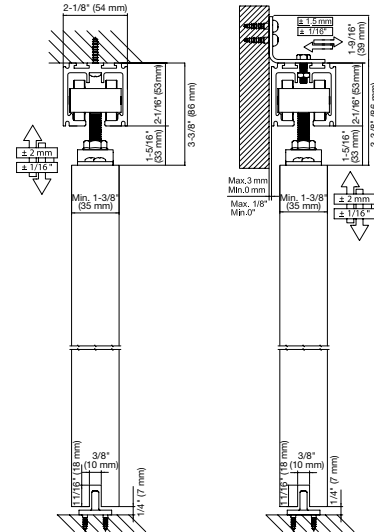

**Wall Mount w/
Short Bracket**
Top track short bracket
for Barn Door style
mounting that allows fast
and simple installation.

Track Details

Top Recessed (SDR-A300TR)

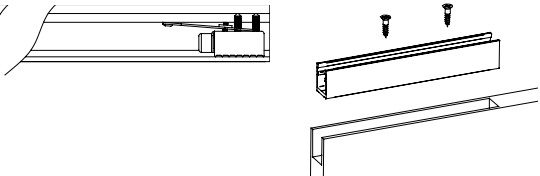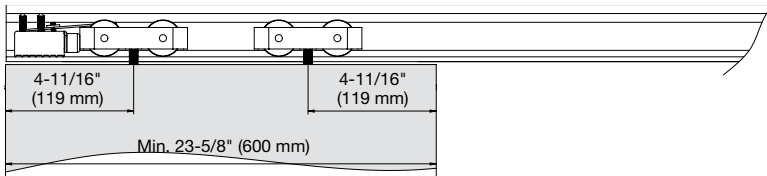

Top Surface (SDR-A300TS)

