


GATE LATCH



SSG



- Gate latch with holes for pad lock. (Pad lock not supplied.)

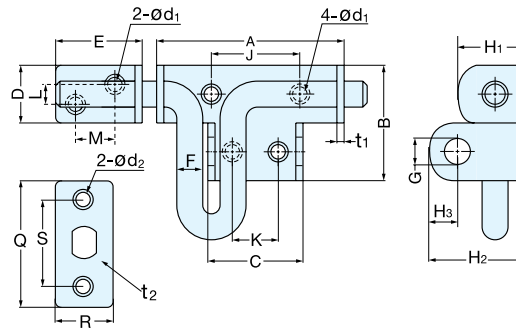

Material	Finish
304 Stainless Steel	Satin, Black

Item No.	A	B	C	D	E	F	G	H ₁	H ₂	H ₃
SSG-45	1-3/4" (45)	1-1/8" (28)	1" (26)	9/16" (14)	13/16" (21)	1/4" (6)	1/4" (7)	5/8" (16.0)	13/16" (20.5)	5/16" (7.5)
SSG-45-BL										
SSG-65	2-9/16" (65)	1-9/16" (40)	1-5/16" (33)	13/16" (20)	1-1/8" (29)	3/8" (9)	3/8" (10)	7/8" (21.5)	1-1/8" (29.0)	3/8" (10)
SSG-85	3-3/8" (85)	1-13/16" (46)	1-5/8" (42)	1" (26)	1-5/16" (34)	1/2" (12)		1-1/8" (28.0)	1-3/8" (35.5)	7/16" (11)

Item No.	J	K	L	M	Q	R	S	d ₁	d ₂	t ₁	t ₂	Weight (g)	Box (pcs)	Carton (pcs)
SSG-45	7/8" (22)	7/16" (11)	1/16" (2)	5/16" (8)	1-1/4" (32)	9/16" (15)	7/8" (22)	3/16" (4.8)	3/16" (4.8)	1/16" (2.0)	1/16" (1.2)	65	20	240
SSG-65	1-3/16" (30)	9/16" (14)	3/16" (4)	9/16" (14)	1-9/16" (40)	11/16" (18)	1-1/8" (28)	1/4" (5.9)	1/4" (5.9)	1/8" (2.5)	1/16" (1.5)	175	10	100
SSG-85	1-1/2" (38)	13/16" (21)	5/16" (8)	11/16" (17)	1-7/8" (48)	7/8" (22)	1-3/8" (35)	1/4" (6.0)	3/16" (5.2)	1/8" (3.0)	1/16" (1.5)	400	5	60


BAR LATCH




SSL



- Latch can be locked by sliding-in the bar.
- Slide out and lift the bar to release.

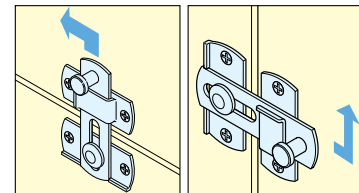

Installation

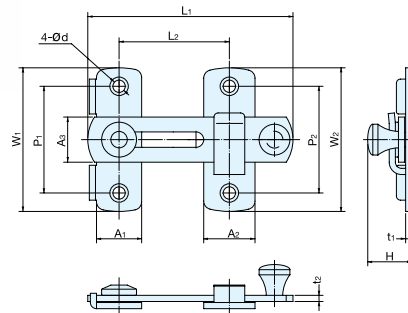

Material	Finish
304 Stainless Steel	Polished

Item No.	L ₁	L ₂	W ₁	W ₂	A ₁	A ₂	A ₃	P ₁	P ₂	H	t ₁	t ₂	d	Screw	Weight (g)	Box (pcs)	Carton (pcs)
SSL-50	2" (50)	20±4	1-3/8" (35)	1-3/8" (35)	1/2" (13)	9/16" (15)	1/2" (13)	1" (26)	1" (26)	9/16" (14.5)	1/16" (2.0)	1/16" (2.0)	ø4.2, ø6.2	3.0 × 16	32	20	600
SSL-70	2-3/4" (70)	28±6	2" (50)	2" (50)	11/16" (18)	13/16" (20)	11/16" (18)	1-7/16" (37)	1-7/16" (37)	3/4" (19.0)	1/16" (2)	1/8" (2.5)	ø5.2, ø8.0	3.5 × 16	68		360
SSL-100	3-15/16" (100)	45±15	2-3/4" (70)	2-3/4" (70)	7/8" (22)	1" (25)	7/8" (22)	2-1/16" (52)	2-1/16" (52)	7/8" (21.5)	1/8" (3)	1/8" (3.0)	ø5.8, ø9.0	4.0 × 25	142	10	160