


WIRE HOOK

NSF COMPONENT | RoHS | STAINLESS 304 STEEL | LOAD CAPACITY 3-8 kg 6.6-17.6 lbs | TEST 4 P.696 | TY

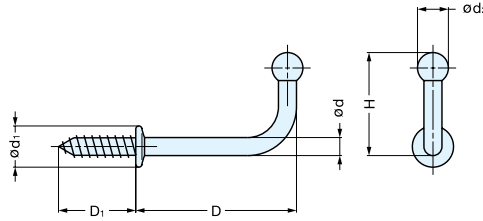


Material	Finish
304 Stainless Steel	Polished

Item No.	D	D ₁	H	d	d ₁	d ₂	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
TY-20	7/8" (21.8)	7/16" (11)	9/16" (14)	1/8" (2.7)	1/4" (6.5)	3/16" (4.5)	6.6 lbs (3 kg)	1.5	200	7200
TY-25	1-1/16" (27.0)	1/2" (13)	11/16" (17)	1/8" (3.0)	1/4" (7.0)	3/16" (5.0)		3.0		
TY-30	1-1/4" (31.2)	9/16" (15)	13/16" (20)	1/8" (3.5)	5/16" (8.0)	1/4" (6.0)	15.4 lbs (7 kg)	5.0	100	1800
TY-35-15	1-7/16" (36.5)	9/16" (15)	15/16" (23)	3/16" (4.0)	3/8" (9.0)	1/4" (6.5)		7.0		
TY-40-15	1-11/16" (43.5)		1-1/16" (27)	3/16" (4.5)	3/8" (10.0)	5/16" (7.5)	17.6 lbs (8 kg)	11.0	50	900

(units in mm)

WIRE HOOK

RoHS | STAINLESS 304 STEEL | LOAD CAPACITY 3-12 kg 6.6-26 lbs | TEST 4 P.696 | TF

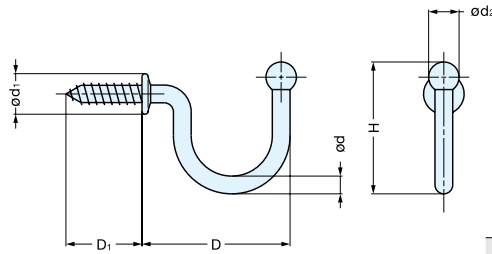


Material	Finish
304 Stainless Steel	Polished

Item No.	D	D ₁	H	d	d ₁	d ₂	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
TF-20	13/16" (20.8)	7/16" (11)	13/16" (20)	1/8" (2.7)	1/4" (6.5)	3/16" (4.5)	6.6 lbs (3 kg)	3.0	200	7200
TF-30	1-1/8" (29.2)	9/16" (15)	1" (26)	1/8" (3.5)	5/16" (8.0)	1/4" (6.0)	15.4 lbs (7 kg)	5.5	100	1800
TF-35	1-9/16" (40.5)	13/16" (20)	1-3/8" (35)	3/16" (4.5)	3/8" (10.0)	5/16" (7.5)	26.0 lbs (12 kg)	13.5	50	900

(units in mm)

WIRE HOOK

RoHS | STAINLESS 304 STEEL | LOAD CAPACITY 5-12 kg 11-26 lbs | TEST 4 P.696 | TL

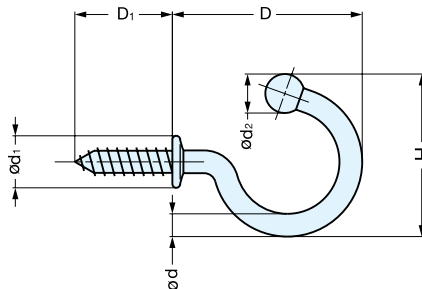

Material	Finish
304 Stainless Steel	Polished

Item No.	D	D ₁	H	d	d ₁	d ₂	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
TL-15	11/16" (16.8)	7/16" (11)	9/16" (15)	1/8" (2.7)	1/4" (6.5)	3/16" (4.5)	11 lbs (5 kg)	1.9	200	7200
TL-20	7/8" (22.8)		13/16" (20)					2.1		
TL-30	1-1/8" (29.2)	9/16" (15)	1" (25)	1/8" (3.5)	5/16" (8.0)	1/4" (6.0)	6.0	50	900	
TL-40	1-9/16" (40.5)	13/16" (20)	1-5/16" (34)	3/16" (4.5)	3/8" (10.0)	5/16" (7.5)	26 lbs (12 kg)	13.5	50	900

(units in mm)