

LEVEL ADJUSTABLE SHELVING SYSTEM

SPECIAL ORDER

VT-DF




- Slotted shelving system for flexible layout.
- Shelves can be installed anywhere in the slot.
- Simple and easy installation.
- Use with desired panel to match the surrounding design.
- Snap-in type catch for easy panel installation.
- Wall Panel Size:
Thickness-20 mm
Width-Max. 71-21/32" (1820 mm)
Height- 4-1/8"~17-23/32" (105~450 mm)
*Panel not included.
- Designed to have space behind panels for electric wiring, and for rotating/seasonal displays.
- Shelf bracket for wood or glass available. (Shelf board not included.)
- Level adjustable.



Snap in panels installed



Snap in panels removed

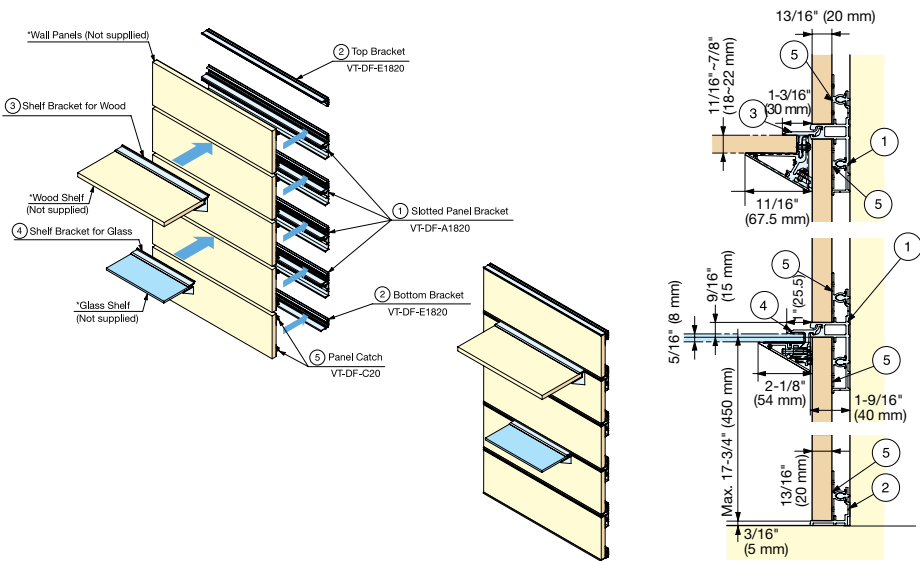

No.	Item No.	Part Name	Dimensions	Material	Finish/Color	Length	Wall Panel Thickness	Shelf Board Size			Load Capacity (kg)
								Width	Depth	Thickness	
①	VT-DF-A1820	Slotted Panel Bracket		Aluminum	Anodized	71-21/32" (1820 mm)	25/32" (20 mm)	-	-	-	-
②	VT-DF-E1820	Top/Bottom Bracket		Aluminum	Anodized	71-21/32" (1820 mm)	25/32" (20 mm)	-	-	-	-
③	VT-DS-X-450	Shelf Bracket For Wood		Aluminum	Anodized Grey	17-23/32" (450 mm)	-	17-23/32"~23-5/8" (450~600 mm)	5-29/32"~11-13/16" (150~300 mm)	23/32"~7/8" (18~22 mm)	88 lbs (40 kg)
	31-1/2" (800 mm)					31-1/2"~35-7/16" (800~900 mm)					
④	VT-DS-G-450	Shelf Bracket For Glass		ABS	Anodized Grey	17-23/32" (450 mm)	-	17-23/32"~23-5/8" (450~600 mm)	5-29/32"~11-13/16" (150~300 mm)	5/16" (8 mm)	22 lbs (10 kg)
	26-31/32" (685 mm)					26-31/32"~35-7/16" (685~900 mm)					
⑤	VT-DF-C20	Panel Catch		Polyacetal	Natural	-	-	-	-	-	-