



# GLASS PIVOT HINGE (INSET)

# XL-GC04

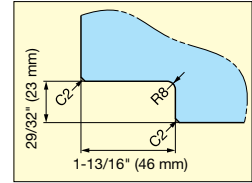

- Inset-type hinge for glass cabinet.
- Sold as a pair (top/bottom).
- Compatible with glass door lock XL-GC02 and bracket XL-GC05 (both sold separately).
- Door Size: Max. W19-11/16" × H47-1/4" × t5/16" (W500 × H1200 × t8 mm)

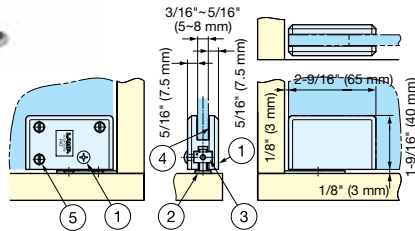

Cut Out Dimension

No.	Part Name	Material	Finish/Color
①	Body	Zinc Alloy	Chrome
②	Bottom Plate	Steel	Chrome
③	Plate	304 Stainless Steel	Plain
④	Spacer	PVC	Black
⑤	Screws	304 Stainless Steel	Plain



Item No.	Glass Thickness	Load Capacity (kg)	Weight (g)	Box (pairs)	Carton (pairs)
XL-GC04-C	3/16"~5/16" (5~8 mm)	26.5 lbs (12 kg)/Door	560	1	24

# GLASS BRACKET


# XL-GC05



- Bracket for hinge XL-GC04 (sold separately).
- For use when top panel is glass.

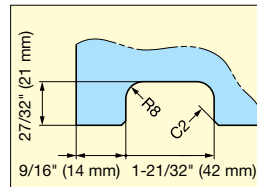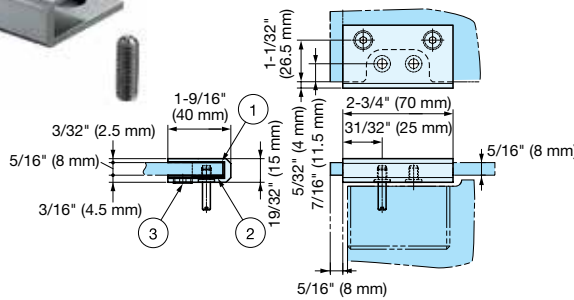

Cut Out Dimension (Top Panel)

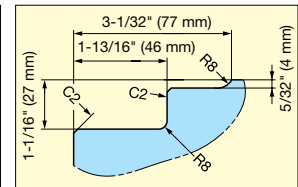

Cut Out Dimension (Glass Door)

Item No.	Type	Glass Thickness	Weight (g)	Box (pcs)	Carton (pcs)
XL-GC05-R-C	Right	5/16" (8 mm)	174	1	24
XL-GC05-L-C	Left				




No.	Part Name	Material	Finish/Color
①	Bracket	Zinc Alloy	Chrome
②	Spacer	Synthetic Rubber	Clear
③	Screws	304 Stainless Steel	Plain

# GLASS HINGE (OVERLAY, W/CATCH)

# XL-GC07



- 3/8" (10 mm) Overlay hinge with catch for glass cabinetry.
- Max. Door Size: W19-11/16" × H47-1/4" × t1/4" (W500 × H1200 × t6 mm)
- Not for use with lock XL-GC02.

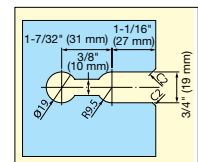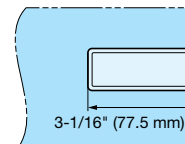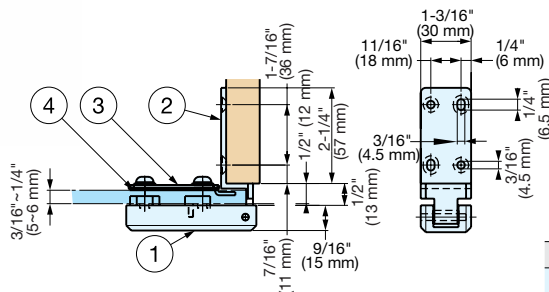

Cut Out Dimension

Item No.	Glass Thickness (mm)	Load Capacity	Weight (g)	Box (pcs)	Carton (pcs)
XL-GC07-C	3/16"~1/4" (5~6 mm)	26.5 lbs (12 kg)/Door	301	1	24

No.	Part Name	Material	Finish/Color
①	Body	Zinc Alloy	Chrome
②	Hinge Plate		
③	Backplate	Steel	Chrome
④	Spacer	Synthetic Rubber	Black