
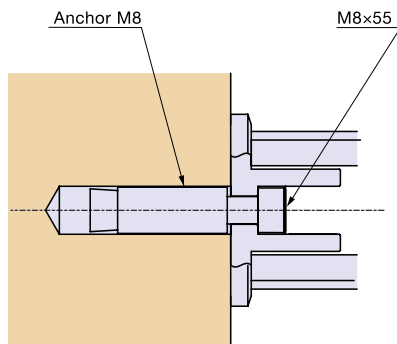


- Sold per each. Glass not included.
- Supplied with stainless steel Hex Socket Cap Screw (M8 x 55), concrete anchor (for M8, ø14 mm hole) and 8 mm allen key
- Tempered glass recommended.

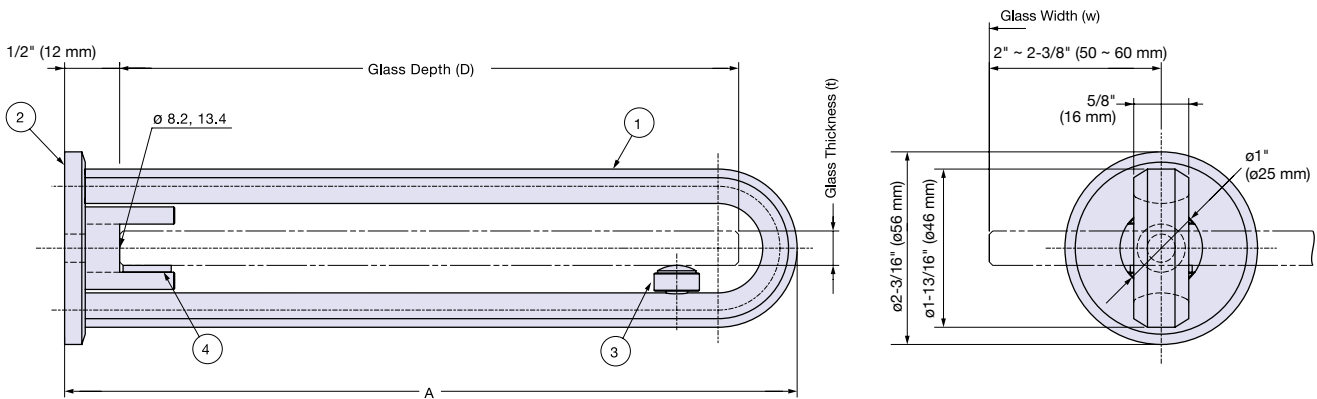

Item No.	A	Glass Dimensions (Per 2 Clamps)			Weight (g)	Box (pcs)
		t	D	W		
ZL-2201-120	5-29/32" (150 mm)	5/16"	4-3/4" (120 mm)	Max. 25-3/16" (640 mm)	293	2
ZL-2201-180	8-1/4" (210 mm)	5/16" or 3/8" (8 mm or 10 mm)	7-1/16" (180 mm)	Max. 31-1/2" (800 mm)	403	
ZL-2201-240	10-5/8" (270 mm)	5/16" or 3/8" (8 mm or 10 mm)	9-7/16" (240 mm)	Max. 37-13/16" (960 mm)	438	

No.	Part Name	Material	Finish/Color
①	Shelf Holder	316 Stainless Steel	ZweiL
②	Base Plate		ZweiL/Clear
③	Level Adjuster	316 Stainless Steel/Polyurethane	ZweiL/Clear
④	Bumper	Synthetic Rubber	Black