



# TSS3

## HEAVY DUTY STAINLESS STEEL SLIDE FULL EXTENSION SPECIAL APPLICATION

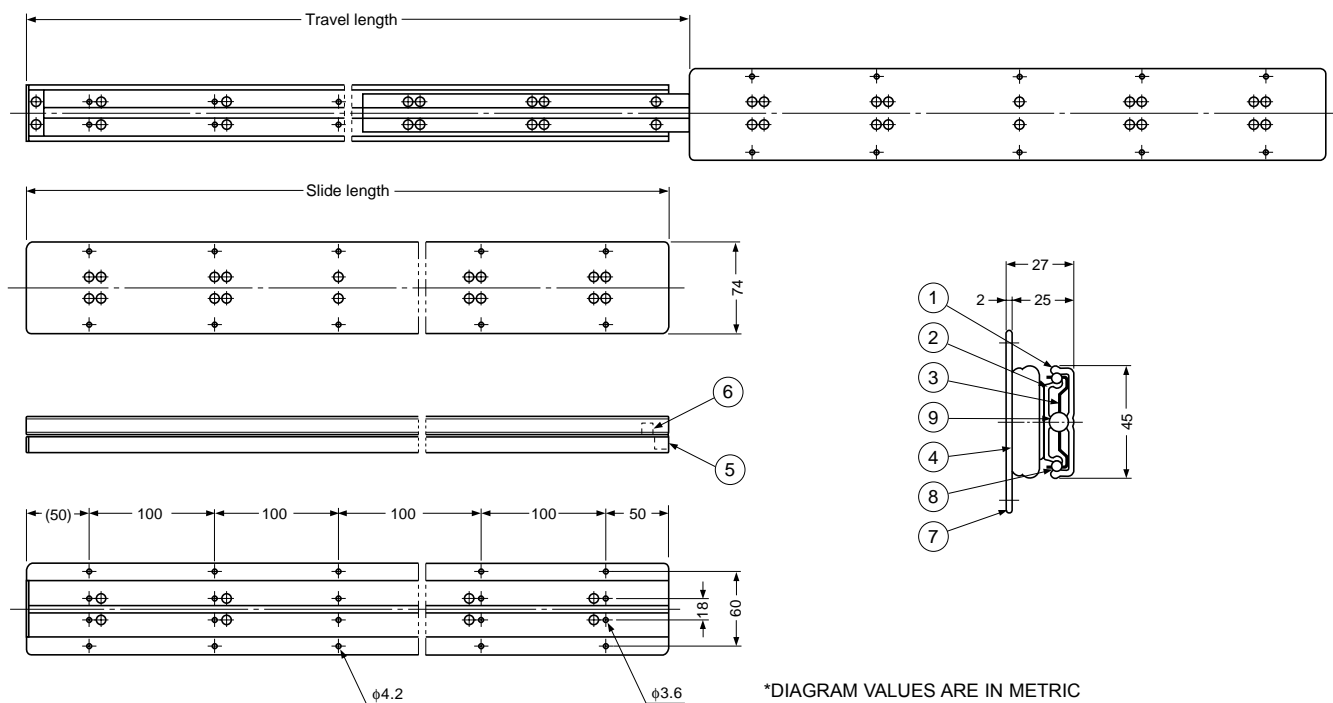


\*DIAGRAM VALUES ARE IN METRIC

PART NO	SLIDE LENGTH	TRAVEL LENGTH	LOAD RATING
			(KG/PAIR)
TSS3-300	300 (11.81")	336 (13.23")	95 (209 LBS)
TSS3-400	400 (15.75")	436 (17.17")	90 (198 LBS)
TSS3-500	500 (19.69")	536 (21.1")	85 (187 LBS)
TSS3-600	600 (23.62")	636 (25.04")	80 (176 LBS)
TSS3-800	800 (31.5")	836 (32.91")	65 (143 LBS)
TSS3-1000	1000 (39.37")	1036 (40.79")	50 (110 LBS)

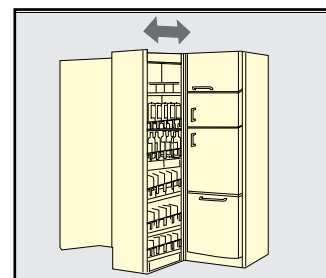

NO	PART	MATERIAL
1	OUTER RAIL	SUS304
2	INNER RAIL	SUS304
3	RETAINER	SUS304
4	END STOPPER	POLYAMIDE
5	OUTER GUIDE	POLYACETAL
6	INNER GUIDE	POLYACETAL
7	PLATE	SUS304
8	LARGE BALLS	STEEL
9	SMALL BALLS	STEEL

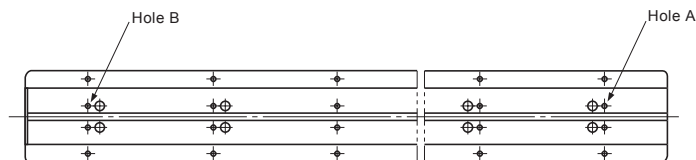

## MOUNTING INSTRUCTIONS

1. Extend the plate all the way and pre-drill holes for installation screws at designated diameter on side wall so that slides can be level for hole-B. Close plate side to original position and find holes through access holes located on back side.
2. Tighten screws temporary in hole-A first and then do the same thing on hole-B through an access hole from backside. After confirming that it is level, tighten all the screws.
3. Mount plate side on drawer after pre-drilling holes for installation screws at designated diameter so that slides can be level and tighten all the screws.