




# HIGH TEMPERATURE MAGNETIC CATCH



MC-YN005HP



- Suitable for high temperature environments up to 250°C (482°F).
- Optional counterplates:
  - MC-JM49
  - AS-68

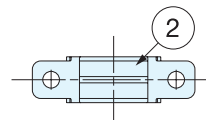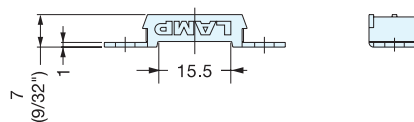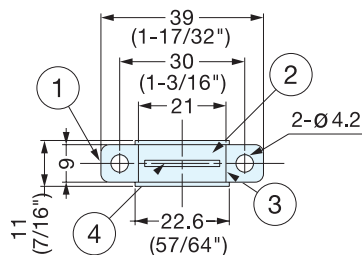

No.	Part Name	Material	Finish/Color
①	Yoke	430 Stainless Steel	Plain
②	Magnet	Samarium Cobalt	-
③	Housing	304 Stainless Steel	Plain
④	Center Yoke	430 Stainless Steel	

Item No.	Magnetic Force (kg)	Weight (g)	Box (pcs)	Carton (pcs)
MC-YN005HP-20	2.0 ( 4.4 lbs )	11	200	1000
MC-YN005HP-50	5.1 ( 11.0 lbs )			



# HIGH TEMPERATURE MAGNETIC CATCH



MC0083HP



- Suitable for high temperature environments up to 250°C (482°F).
- Strong magnetic force.
- Optional counterplates:
  - MC-JM49
  - AS-68

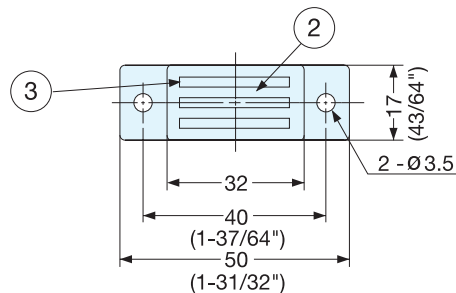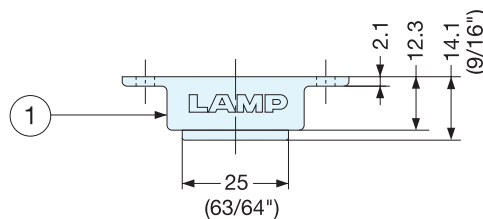

No.	Part Name	Material	Finish/Color
①	Housing	304 Stainless Steel	Plain
②	Magnet	Samarium Cobalt	-
③	Yoke	430 Stainless Steel	Plain

Item No.	Magnetic Force (kg)	Weight (g)	Box (pcs)	Carton (pcs)
MC0083HP-70	7 (15 lbs)	40	40	400
MC0083HP-140	14 (31 lbs)			