


DOOR HANDLE

STAINLESS
304
STEEL

DSI-3310

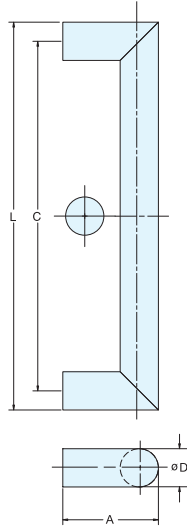

- For use with DSI mounting kits (sold separately, See P.10).
- Please specify Interior/Exterior type when ordering:
 - Posts for Exterior handles are threaded to accept screws.
 - Posts for Interior handles have set screws for DSI mounting kits.
- Similar style to DIH series cabinet handles. (P.36)


Material	Finish
304 Stainless Steel	Satin

Item No.		D	L	C	A	Weight (kg)		Box (pcs)	Carton (pcs)
Interior	Exterior					Interior	Exterior		
DSI-3310-15-15I	DSI-3310-15-15E	15	165 (6-1/2")	150 (5-29/32")	55 (2-3/16")	0.32 (0.7 lbs)	0.32 (0.7 lbs)	1	10
DSI-3310-15-20I	DSI-3310-15-20E		215 (8-1/2")	200 (7-7/8")		0.39 (0.9 lbs)	0.40 (0.9 lbs)		
DSI-3310-15-30I	DSI-3310-15-30E		315 (12-3/8")	300 (11-13/16")		0.52 (1.1 lbs)	0.54 (1.2 lbs)		
DSI-3310-20-20I	DSI-3310-20-20E	20	220 (8-11/16")	200 (7-7/8")	65 (2-9/16")	0.16 (0.4 lbs)	0.18 (0.4 lbs)		
DSI-3310-20-25I	DSI-3310-20-25E		270 (10-5/8")	250 (9-27/32")		0.18 (0.4 lbs)	0.20 (0.4 lbs)		
DSI-3310-20-30I	DSI-3310-20-30E		320 (12-5/8")	300 (11-13/16")		0.20 (0.4 lbs)	0.23 (0.5 lbs)		
DSI-3310-30-25I	DSI-3310-30-25E	30	280 (11")	250 (9-27/32")	90 (3-9/16")	0.48 (1.1 lbs)	0.48 (1.1 lbs)		
DSI-3310-30-30I	DSI-3310-30-30E		330 (12")	300 (11-13/16")		0.52 (1.1 lbs)	0.52 (1.1 lbs)		
DSI-3310-30-35I	DSI-3310-30-35E		380 (14-15/16")	350 (13-25/32")		0.59 (1.3 lbs)	0.57 (1.3 lbs)		
DSI-3310-30-60I	DSI-3310-30-60E		630 (24-13/16")	600 (23-5/8")		0.95 (2.1 lbs)	0.95 (2.1 lbs)		

DOOR HANDLE

STAINLESS
304
STEEL

DSI-3330

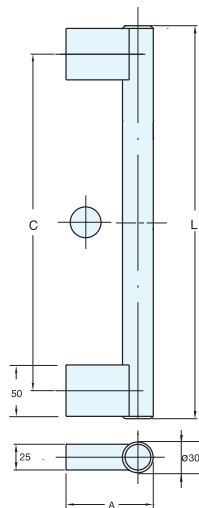

- For use with DSI mounting kits (sold separately, See P.10).
- Please specify Interior/Exterior type when ordering:
 - Posts for Exterior handles are threaded to accept screws.
 - Posts for Interior handles have set screws for DSI mounting kits.
- Similar style to 16 and 27 series cabinet handles. (P.36)

Material	Finish
304 Stainless Steel	Satin

Item No.		L	C	A	Weight (kg)		Box (pcs)	Carton (pcs)
Interior	Exterior				Interior	Exterior		
DSI-3330-30-30I	DSI-3330-30-30E	350	300 (11-13/16")	90 (3-9/16")	1.49 (3.3 lbs)	1.57 (3.5 lbs)	1	10
DSI-3330-30-50I	DSI-3330-30-50E	550	500 (19-11/16")		1.70 (3.7 lbs)	1.70 (3.7 lbs)		