

# BUTT HINGE




# 100 SERIES




SN




CR

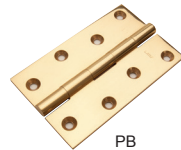

PB

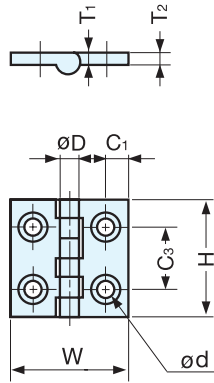

101-106

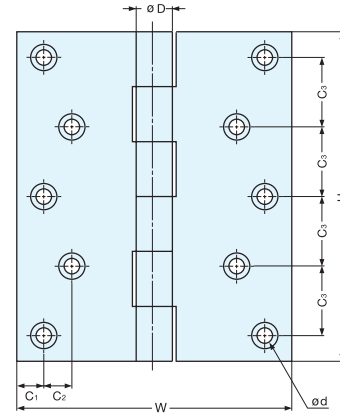

107-109

Material	Finish
Brass	Satin Nickel (SN), Chrome (CR), Polished Brass (PB)

Please specify the finish when ordering.

Item No.	H	W	T <sub>1</sub>	T <sub>2</sub>	D	C <sub>1</sub>	C <sub>2</sub>	C <sub>3</sub>	d	Holes	Weight (g)	Box (pcs)	Carton (pcs)
101	25 ( 63/64" )	27 ( 1-1/16" )	2.0	1.8	4.5	5	-	14.0	3.0	4	11	100	1000
102	32 ( 1-17/64" )							19.0			14		
103	38 ( 1-1/2" )							13.0			20		
104	50 ( 1-31/32" )	32 ( 1-17/64" )	2.2	2.1	5.2	6	-	18.0	3.5	6	30	50	500
105	65 ( 2-9/16" )	38 ( 1-1/2" )	2.4	2.3	6.1	7	-	25.0	3.6		54		
106	75 ( 2-61/64" )	42 ( 1-21/32" )	2.6	2.5	7.1	8	-	27.0	3.8		77		
107	90 ( 3-35/64" )	56 ( 2-13/64" )	3.2	2.8	8.0	7	5	24.6	4.1	8	146	10	100
108	100 ( 3-15/16" )	68 ( 2-43/64" )	3.5	3.0	8.5	9	6	26.0	4.5		206		
109	125 ( 4-59/64" )	82 ( 3-7/32" )	4.2	3.7	10.0	10	10	26.3	5.1		370		



# TABLETOP PIANO HINGE



# HG-MH



• Not a load bearing hinge, requires secondary support.

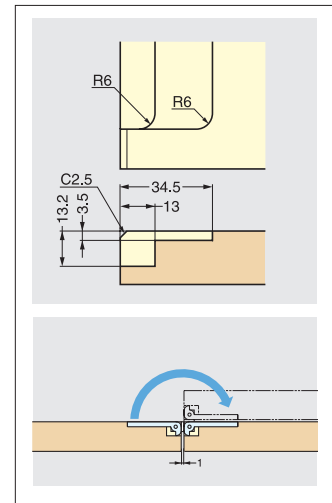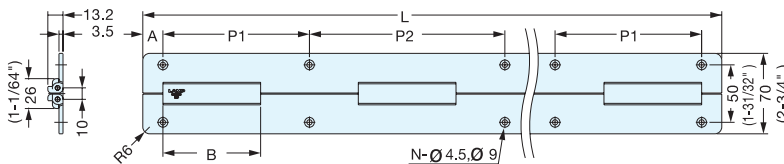

Installation

Item No.	Material	Finish/Color	L	A	P <sub>1</sub>	P <sub>2</sub>	B	# of Holes	Box (pcs)
HG-MH400S	Aluminum/ 304 Stainless Steel (Pin)	Silver	400 ( 15-3/4" )	15.0	111.0	148	74	8	15
HG-MH400BR		Brown							
HG-MH400BL		Black							
HG-MH800S		Silver	800 ( 31-1/2" )	17.5	127.5	170	85	12	10
HG-MH800BR		Brown							
HG-MH800BL		Black							
HG-MH1100S		Silver	1100 ( 43-5/16" )	16.5	145.5	194	97	14	6
HG-MH1100BR		Brown							
HG-MH1100BL		Black							