






SOFT-CLOSE DAMPENING HINGE



HG-JHM14

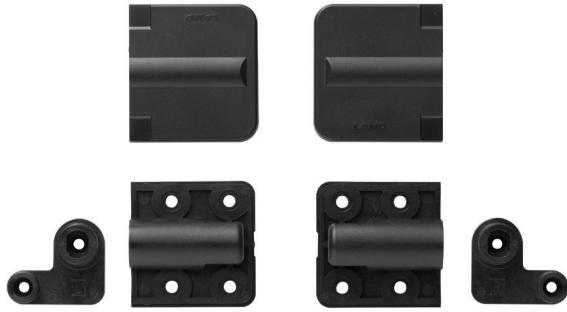

- Hinge with built-in damper to keep lid from slamming shut.
- Mortise mount type.

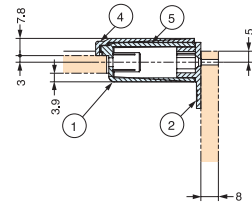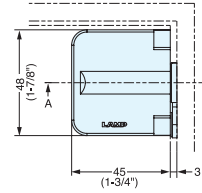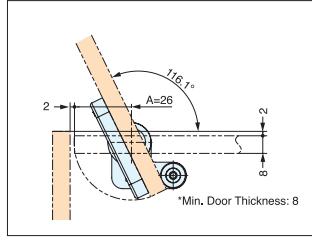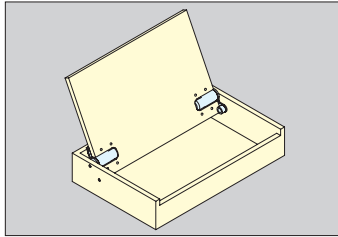


Item No.	Color	Torque per piece (kgf·cm)	Weight (g)	Box (pcs)	Carton (pcs)
HG-JHM14-S-8BL	Black	5~8 (4.3~7 lbs-in)	51	20	220
HG-JHM14-S-8WT	White				
HG-JHM14-S-15BL	Black	8~15 (7.0~13 lbs-in)	51	20	220
HG-JHM14-S-15WT	White				
HG-JHM14-S-20BL	Black	15~20 (13.0~17 lbs-in)	51	20	220
HG-JHM14-S-20WT	White				

No.	Part Name	Material	Finish
①	Bracket	Polyacetal	Black /White
②	Mounting Plate R	PBT plastic	
③	Mounting Plate L		ABS plastic
④	Face Plate	ABS plastic	
⑤	Damper	304 Stainless Steel	-

UNDER PANEL MOUNTING BRACKET






UKZ14

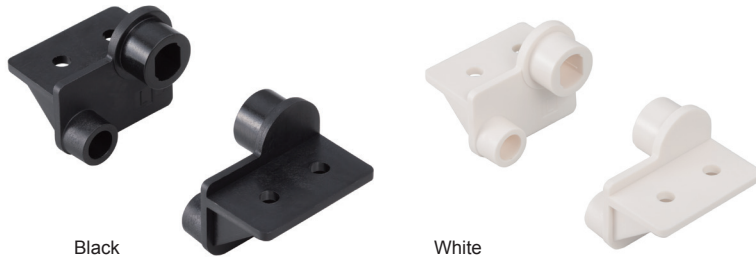

Black

White

- Under panel installation bracket for HG-JHM14 Soft-Close hinge.

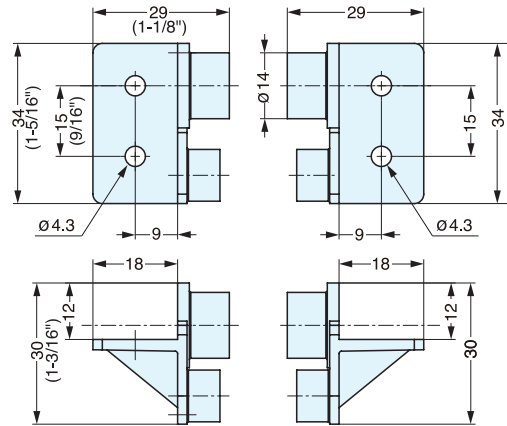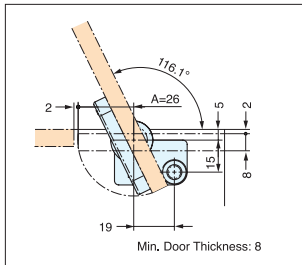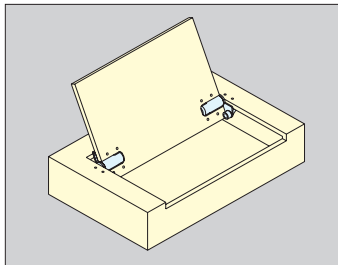

Item No.	Material	Color
UKZ14-BL	PBT Plastic	Black
UKZ14-WT		White