

# INSET GLASS DOOR HINGE (W/CATCH)






## GH-450



SN

CR

GA

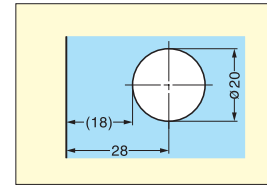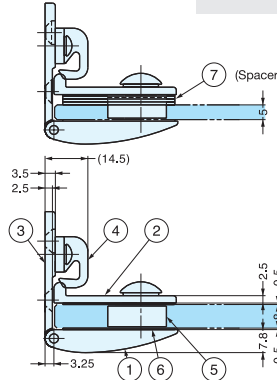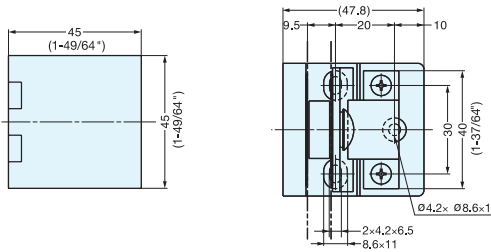

Cut Out Dimensions

- Glass hinge with catch.
- For Inset use
- Suitable for showcases
- Mounting position adjustable: Vertically  $\pm 1$  mm  
Horizontally  $\pm 1.2$  mm
- Spacer included to accommodate different glass thickness.


Item No.	Applicable Door Thickness	Applicable Glass Door Size /Pair	
GH-450/SN	5-8 mm	W:600 mm (23-5/8") H:1200 mm (47") Maximum 15 kg (33 lbs)	
GH-450/CR	5 mm : Use with 3 spacers 6 mm : Use with 2 spacers		
GH-450/GA	8 mm : Spacer not required		
Item No.	Weight (g)	Box (pcs)	Carton (pcs)
GH-450/SN	212	10	40
GH-450/CR			
GH-450/GA			

No.	Part Name	Material	Finish		
			SN	CR	GA
①	Face Plate	Brass	Satin Nickel	Chrome	Gold
②	Fixing Plate				
③	Mounting Plate				
④	Catch	Polyamide	Black		
⑤	Glass Adjustment Block				
⑥	Pad	Rubber			
⑦	Spacer	Polypropylene			

# GLASS DOOR HINGE (GLASS FRAME TYPE, W/O CATCH)






## GH-450G

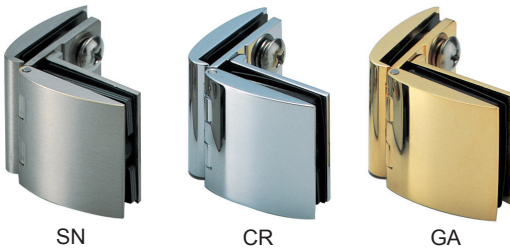


SN

CR

GA

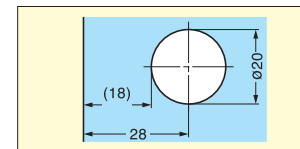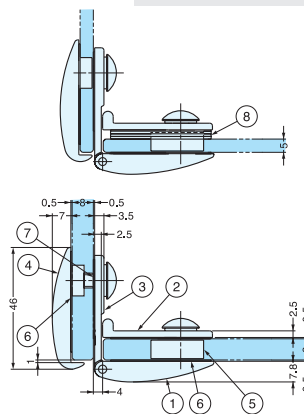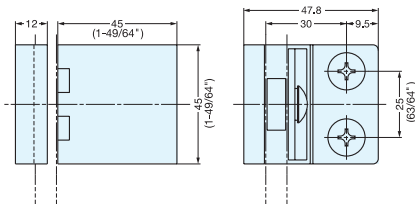

Cut Out Dimensions

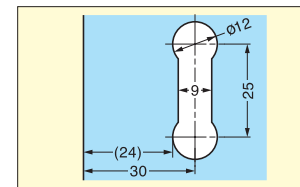

Cut Out Dimension for Side Panel

- For glass frame use.
- Suitable for showcases.
- Mounting position adjustable: Horizontally  $\pm 1.2$  mm
- Spacers included to accommodate different glass thickness.

Item No.	Applicable Door Thickness	Applicable Glass Door Size /Pair	
GH-450G/SN	5-8 mm	W:600 mm (23-5/8") H:1200 mm (47") Maximum 15 kg (33 lbs)	
GH-450G/CR	5 mm : Use with 3 spacers 6 mm : Use with 2 spacers		
GH-450G/GA	8 mm : Spacer not required		
Item No.	Weight (g)	Box (pcs)	Carton (pcs)
GH-450G/SN	320	10	40
GH-450G/CR			
GH-450G/GA			

No.	Part Name	Material	Finish		
			SN	CR	GA
①	Face Plate	Brass	Satin Nickel	Chrome	Gold
②	Fixing Plate				
③	Mounting Plate				
④	Side Plate	Polyamide	Black		
⑤	Glass Adjustment Block				
⑥	Pad A	Rubber			
⑦	Pad B				
⑧	Spacer	Polypropylene			