


HALF OVERLAY GLASS DOOR HINGE (W/CATCH)




GHC-34/8

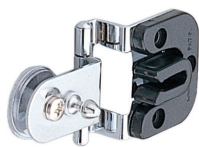


GHC-34/8/CR



GHC-34/8/BLK

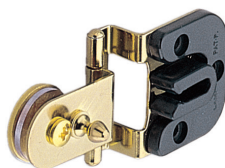


GHC-34/8/PB

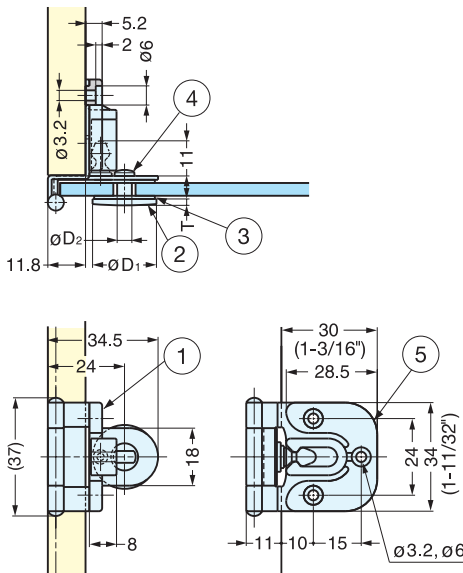

Glass Thickness (mm)	A (mm)	Overlay (mm)
4	19	7
5	18	6
6	17	5

Item No.	D ₁	D ₂	d	T	Weight (g)	Box (pcs)	Carton (pcs)
GHC-34/8/CR	20	6.5	8	2	36	40	600
GHC-34/8/PB	20	6.5	8	2	36		
GHC-34/8/BLK	21	8.0	10	3	32		

- Half overlay.
- Hinge will hold door in closed position without secondary support.
- Door thickness: 4-6 mm
- Door size: Max. W450 × H700 (W17-3/4" × H27-9/16")
- Door weight: Max. 4 kg/pair (8.8 lbs/pair)

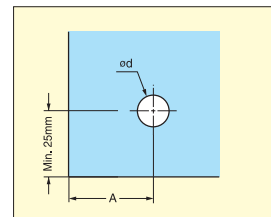


Cut Out Dimension

No.	Part Name	Material	Finish
①	Body	GHC-34/8/BLK	304 Stainless Steel
		GHC-34/8/CR	Steel
		GHC-34/8/PB	Aluminum
②	Plate	GHC-34/8/BLK	Black
		GHC-34/8/CR	Chrome
③	Washer	PVC	Clear
④	Screw	Steel	Nickel
⑤	Catch	Polyacetal	Black


HALF OVERLAY GLASS DOOR HINGE (W/CATCH)



GHC-34-8CR-K

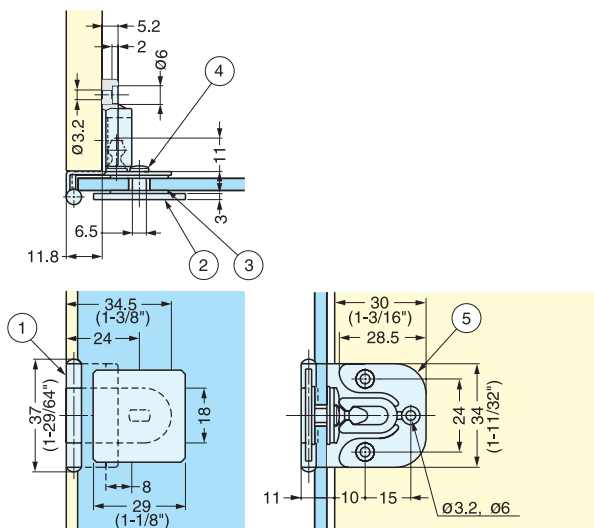

- Half overlay.
- Hinge for glass/acrylic doors.
- Door thickness: 4-6 mm.
- Door size: Max. W450 × H700 (W17-3/4" × H27-9/16")
- Door weight: Max. 4 kg/pair (8.8 lbs/pair)
- Rounded plate GHC-34/8/CR is available.

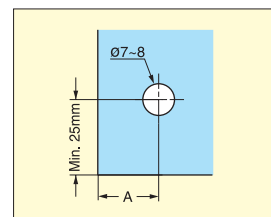

Cut Out Dimension

Glass Thickness (mm)	A (mm)	Overlay (mm)
4	19	7
5	18	6
6	17	5

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
GHC-34-8CR-K	43	40	600

No.	Part Name	Material	Finish/Color
①	Body	Steel	Chrome
②	Plate	Zinc Alloy	Chrome
③	Washer	PVC	Clear
④	Screw	Steel	Nickel
⑤	Stopper	Polyacetal (POM)	Black