



WIRE HOOK

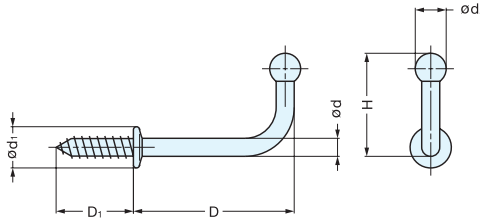

TY

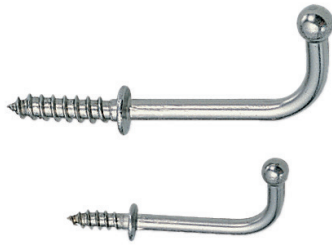



Material	Finish
304 Stainless Steel	Polished

Item No.	D	D ₁	H	d	d ₁	d ₂	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
TY-20	21.8 (55/64")	11	14 (35/64")	2.7	6.5	4.5	3 (6.6 lbs)	1.5	200	7200
TY-25	27.0 (1-1/16")	13	17 (43/64")	3.0	7.0	5.0		3.0		
TY-30	31.2 (1-7/32")	15	20 (25/32")	3.5	8.0	6.0	7 (15.4 lbs)	5.0	100	3600
TY-35-15	36.5 (1-7/16")	15	23 (29/32")	4.0	9.0	6.5		7.0		
TY-40-15	43.5 (1-23/32")		27 (1-1/16")	4.5	10.0	7.5		8 (17.6 lbs)	11.0	50

WIRE HOOK



TF

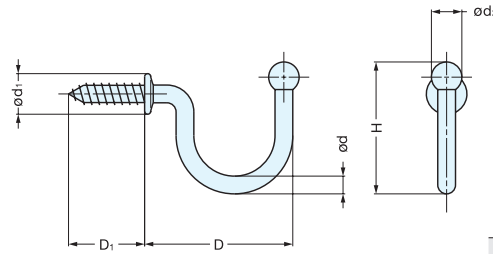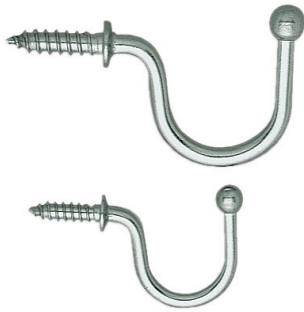



Material	Finish
304 Stainless Steel	Polished

Item No.	D	D ₁	H	d	d ₁	d ₂	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
TF-20	20.8 (13/16")	11	20 (25/32")	2.7	6.5	4.5	3 (6.6 lbs)	3.0	200	7200
TF-30	29.2 (1-5/32")	15	26 (1-1/32")	3.5	8.0	6.0	7 (15.4 lbs)	5.5	100	1800
TF-35	40.5 (1-19/32")	20	35 (1-3/8")	4.5	10.0	7.5	12 (26.0 lbs)	13.5	50	900

WIRE HOOK



TL

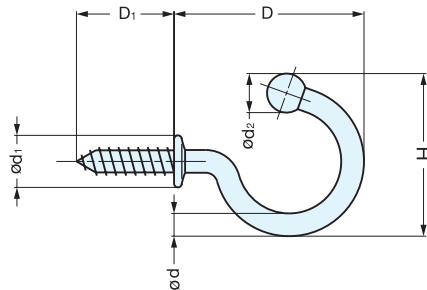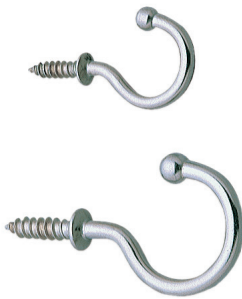

Material	Finish
304 Stainless Steel	Polished

Item No.	D	D ₁	H	d	d ₁	d ₂	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
TL-15	16.8 (21/32")	11	15 (19/32")	2.7	6.5	4.5	5 (11 lbs)	1.9	200	7200
TL-20	22.8 (29/32")		20 (25/32")					2.1	100	3600
TL-30	29.2 (1-5/32")	15	25 (63/64")	3.5	8.0	6.0	6.0	50	900	
TL-40	40.5 (1-19/32")	20	34 (1-11/32")	4.5	10.0	7.5	12 (26 lbs)	13.5	50	900