

# LEVEL ADJUSTABLE SHELVING SYSTEM

# VT-DF

SHELF & SUPPORT HARDWARE

LEVEL ADJUSTABLE SHELVING SYSTEM




- Slotted shelving system for flexible layout.
- Shelves can be installed anywhere in the slot.
- Simple and easy installation.
- Use with desired panel to match the surrounding design.
- Snap-in type catch for easy panel installation.
- Wall Panel Size:  
Thickness-20 mm  
Width-Max. 1820 mm (71-21/32")  
Height-105~450 mm (4-1/8"~17-23/32")  
\*Panel not included.
- Designed to have space behind panels for electric wiring, and for rotating/seasonal displays.
- Shelf bracket for wood or glass available. (Shelf board not included.)
- Level adjustable.



Snap in panels installed



Snap in panels removed

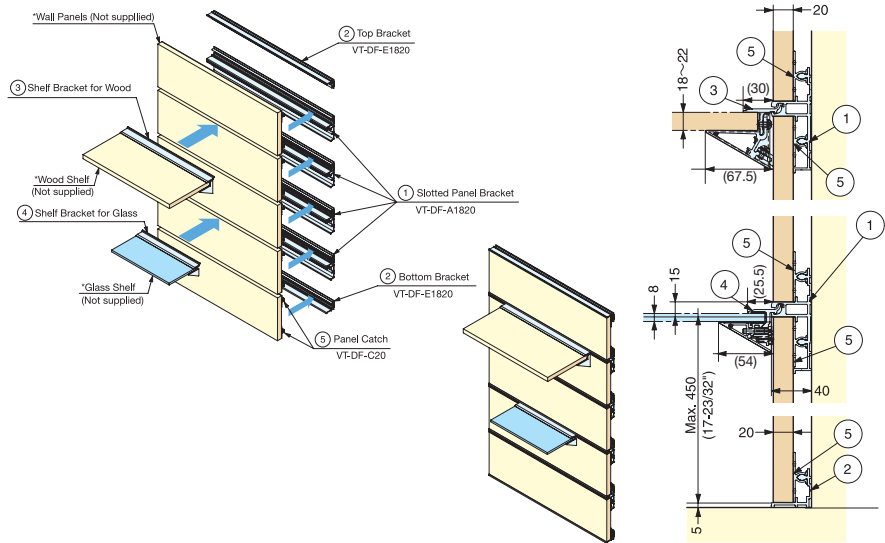

No.	Item No.	Part Name	Dimensions	Material	Finish/Color	Length	Wall Panel Thickness	Shelf Board Size			Load Capacity (kg)
								Width	Depth	Thickness	
①	VT-DF-A1820	Slotted Panel Bracket	 8pcs. of catch ⑤ included.	Aluminum	Anodized	1820 mm	20 mm	-	-	-	-
②	VT-DF-E1820	Top / Bottom Bracket	 8pcs. of catch ⑤ included.			1820 mm	20 mm	-	-	-	-
③	VT-DS-X-450	Shelf Bracket For Wood		Aluminum	Anodized Grey	450 mm	-	450~600 mm	150~300 mm	18~22 mm	40 kg (88 lbs)
	VT-DS-X-800					800 mm		800~900 mm			
④	VT-DS-G-450	Shelf Bracket For Glass		ABS	Anodized Grey	450 mm	-	450~600 mm	150~300 mm	8 mm	10 kg (22 lbs)
	VT-DS-G-685					685 mm		685~900 mm			
⑤	VT-DF-C20	Panel Catch		Polyacetal	Natural	-	-	-	-	-	-