

# CABINET LOCK




2650


LOCKS

CABINET LOCKS


- Cabinet lock with 90° rotating cylinder for right-handed doors (see diagram below).
- Up to 48 key changes available for 2650-16; up to 96 key changes available for each of 2650-22 and 2650-30.
- Please specify keyed alike or differently when ordering.
- Can be used with spacer TSSP (P.629), sold separately.

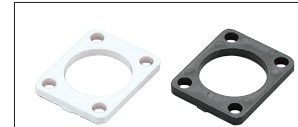


TSSP SERIES (Sold separately)

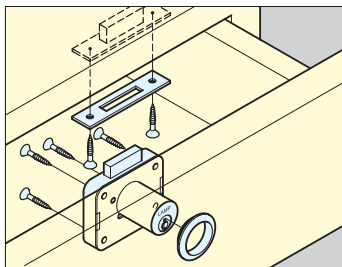


Installation for drawer

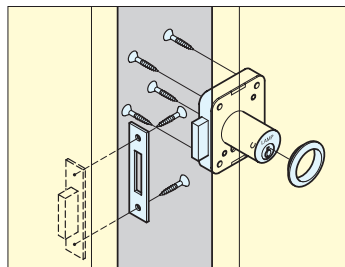

Installation for right-handed door

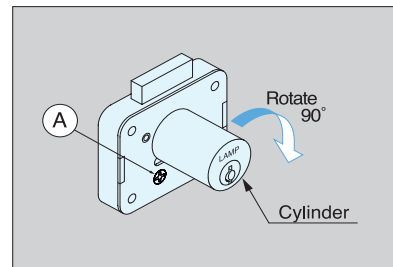

To rotate cylinder, loosen screw ⑥ and rotate cylinder 90° clockwise and tighten it afterwards.

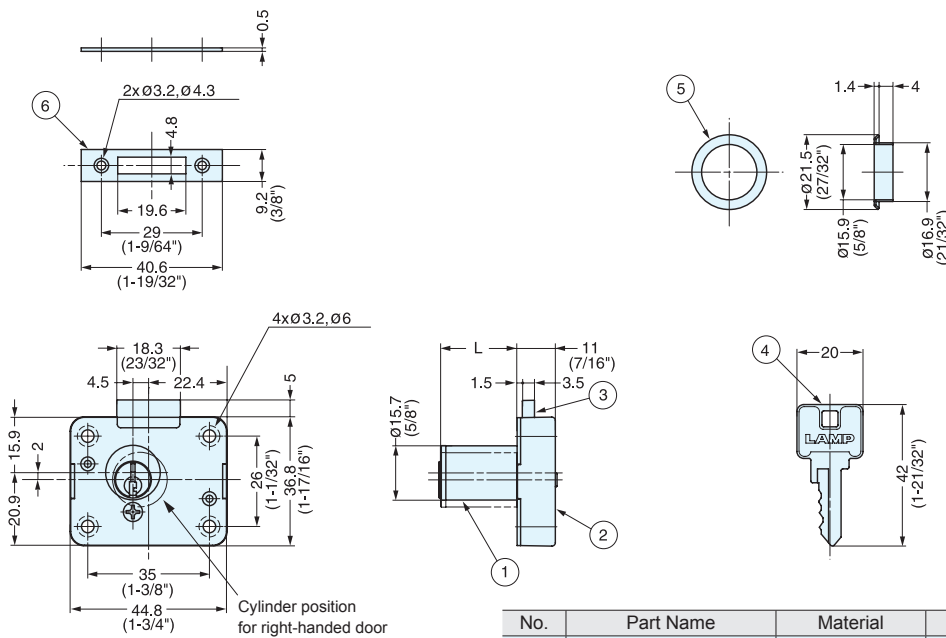

No.	Part Name	Material	Finish
①	Cylinder Housing	Zinc Alloy	Satin Nickel
②	Body		Yellow Zinc Chromate
③	Dead Bolt		Nickel
④	Key	Brass	Nickel
⑤	Ring		Satin Nickel
⑥	Counterplate		Plain

Item No.	L	Door Thickness	Weight (g)	Box (pcs)	Carton (pcs)
2650-16-DN	16 ( 5/8" )	16 ( 5/8" )	81.5	12	240
2650-22-DN	22 ( 7/8" )	22 ( 7/8" )	89.5		
2650-30-DN	30 ( 1-3/16" )	30 ( 1-3/16" )	98.0		