

# HIGH SECURITY CABINET CYLINDER LOCK (W/ ROUND STEM KEY)




7110




- Round stem dimple key is difficult to duplicate, and the cylinder lock is difficult to pick, adding additional security.
- Key can be easily inserted into the lock at any angle.
- Lock is non-handed, and can be installed on cabinet drawers, swinging doors, display cases, or cabinets for safes.
- Includes 3 keys, counterplate and wood screws for installation.
- Specify keyed alike or different when ordering.
- Maximum 500,000 key changes available.
- Master keying options available by special order.


Unlike regular keys, these keys can be inserted at any angle.

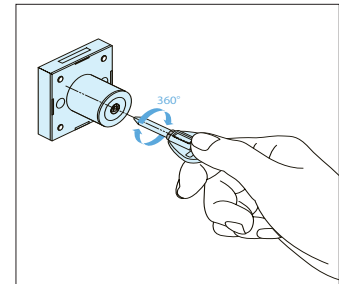



Insert key easily in cabinets that are difficult to access.

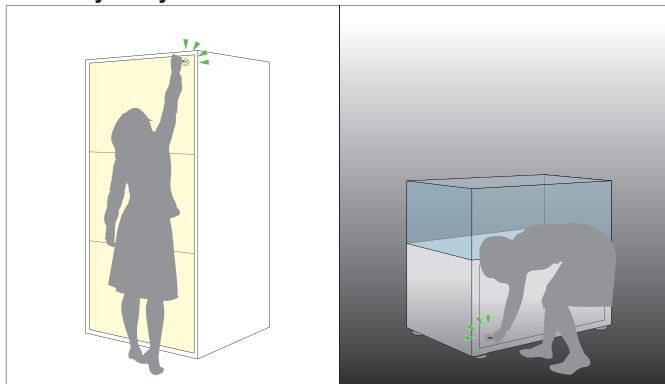

Drawer Application

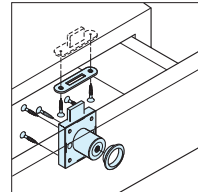


Swinging Door Applications

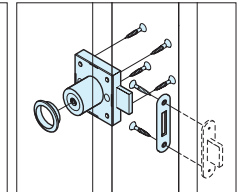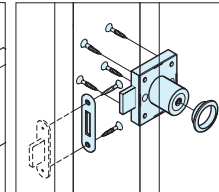

Right handed door

Left handed door

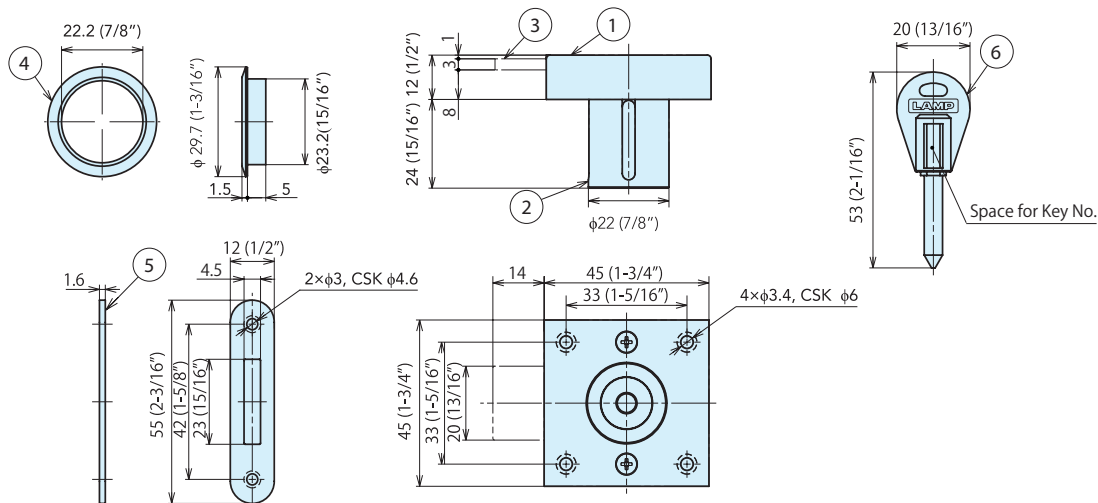

No.	Part Name	Material	Finish
①	Body	304 Stainless Steel	Plain
②	Cylinder	Brass	Nickel
③	Dead Bolt	304 Stainless Steel	Plain
④	Ring	Brass	Nickel
⑤	Strike	Steel	
⑥	Key	304 Stainless Steel, Plastic (POM)	Plain

Item No.	Frame Thickness (mm)	Cylinder Diameter (mm)	Weight (g)	Box (pcs)	Carton (pcs)
7110-24-DN	22~24 (7/8"~15/16")	22 (7/8")	160	12	60