

# PUSH-TO-OPEN DOOR LATCH (DOOR UP TO 36"X96")



## ML-ZN80

CATCHES & LATCHES

PUSH-TO-OPEN DOOR LATCH




ML-ZN80WT

ML-ZN80BL


- For doors up to 36" x 96" with a push force of 11 lbs. Ideal for use with the HES3D-E190 Concealed Door Hinge series.
- Magnet allows tolerance with 1.5° swivel.
- Hidden Mounting Screw Design for clean appearance and easy installation.
- Passed 100,000 open/close private cycle test.

### [Installation]


#### • Inset Doors

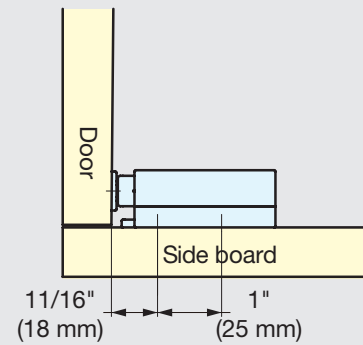

#### • Overlay Doors

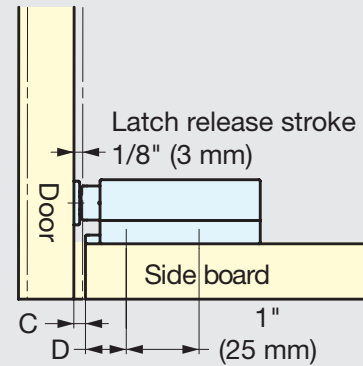

Please make sure there is a "C Clearance" on the side board. It makes the installation easier to align the edge of the body to the edge of the side board.

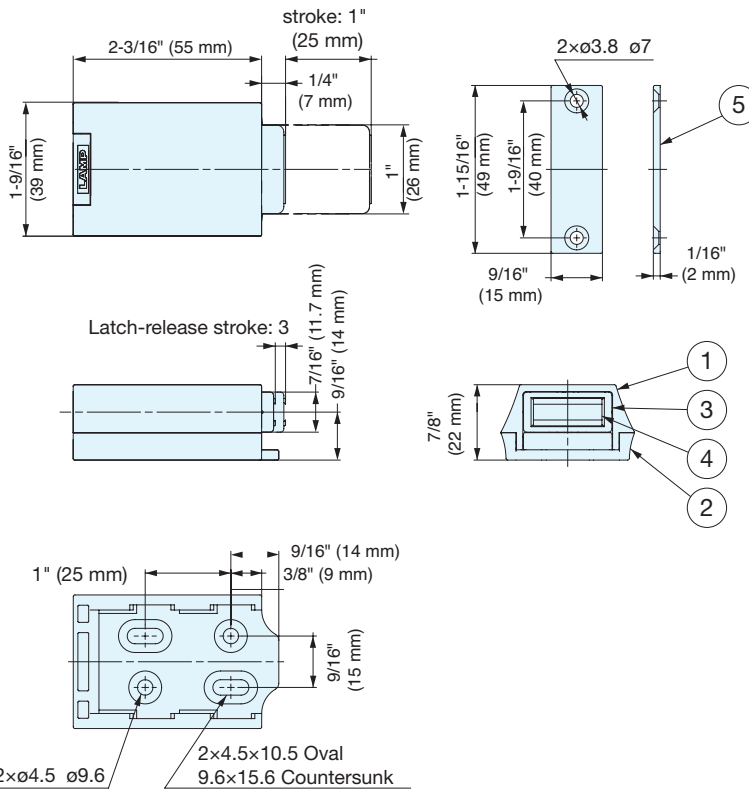

| No. | Part Name      | Material        | Finish/Color           |
|-----|----------------|-----------------|------------------------|
| ①   | Body           | Zinc Alloy      | White (WT), Black (BL) |
| ②   | Mounting Plate |                 |                        |
| ③   | Latch          | Plastic (PA)    | Plain                  |
| ④   | Magnet         | Ferrite         |                        |
| ⑤   | Strike Plate   | Stainless Steel | Polished               |

| Item No.  | Magnetic Force | Push Force    | Weight (g) | Max. Door Specs (Reference) |          |              |           |              |
|-----------|----------------|---------------|------------|-----------------------------|----------|--------------|-----------|--------------|
|           |                |               |            | Height                      | Width    | Weight (lbs) | Box (pcs) | Carton (pcs) |
| ML-ZN80WT | 6.6 lbs (3 kg) | 11 lbs (5 kg) | 160        | 96-1/16"                    | 36"      | 275 (125 kg) | 10        | 40           |
| ML-ZN80BL |                |               |            | (2440 mm)                   | (915 mm) |              |           |              |