

ADJUSTABLE SOFT-DOWN STAY (SHORT-ARM)





NSDX-10(R/L)K/TV

LID SUPPORTS

ADJUSTABLE COMPACT SOFT-DOWN STAYS



- For DOWNWARD-OPENING FLAP DOOR with concealed, piano, butt or drop hinges.
- Short arm type designed for shorter door height applications.
- Handed: Specific left and right hand mounting.
- Torque Calculation:
 - Torque = Door Height x 1/2 x Door Weight
 - Per Piece: 10 ~ 20 kgf·cm (8.7 ~ 17.4 lbs·in)
 - Per Pair: 20 ~ 40 kgf·cm (17.4 ~ 34.7 lbs·in)

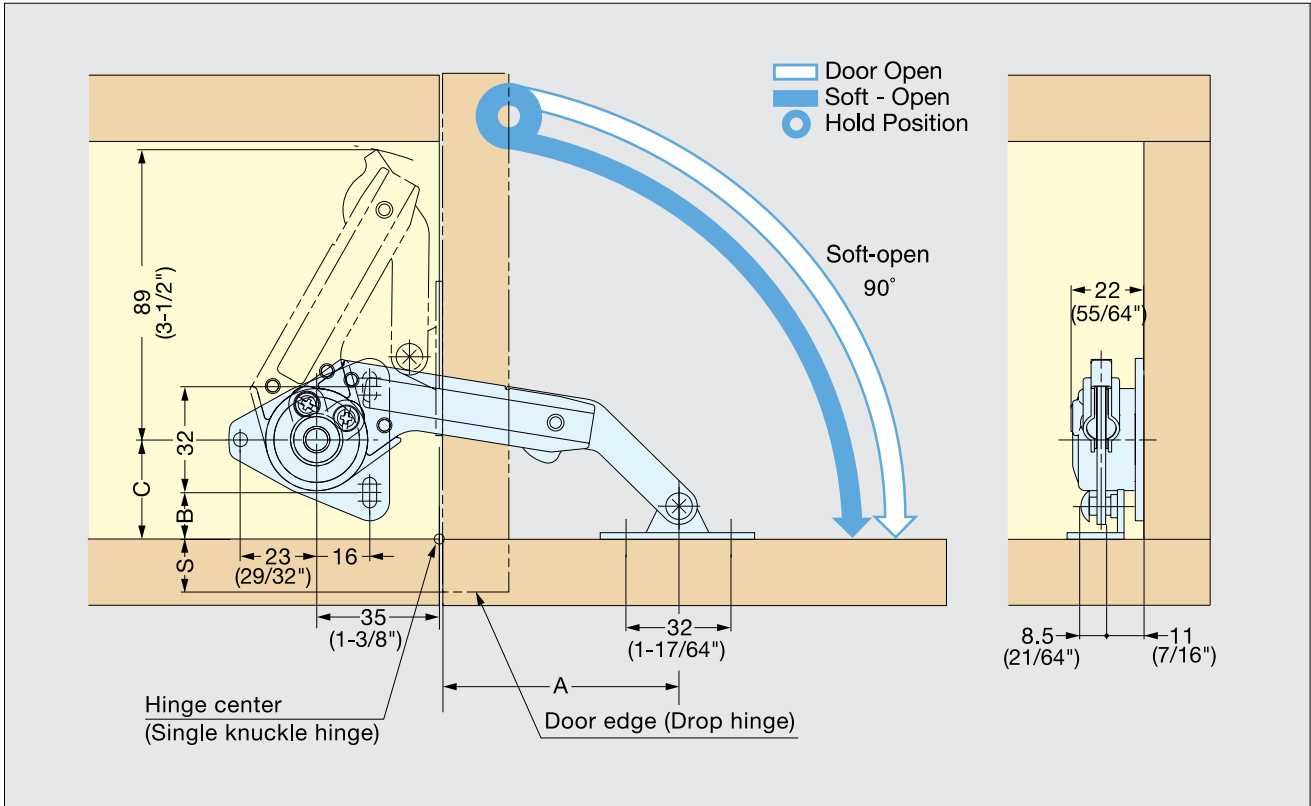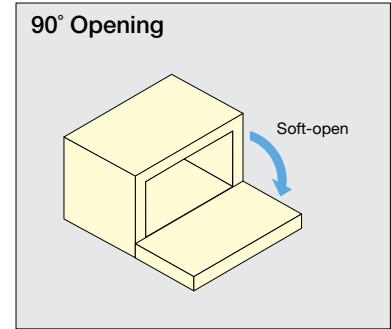

Hinge Type	A	B	C
Drop Hinge	58 (2-9/32")+S	14 (35/64")	30 (1-3/16")
Single Knuckle Hinge	71 (2-51/64")	27 (1-1/16")	43 (2-9/16")

Item No.	Material	Finish	Weight (g)	Box (pcs)	Carton (pcs)
NSDX-10RK/TV	Zinc Alloy/Steel	Nickel	143	20	80
NSDX-10LK/TV					