



HEAVY DUTY CLEAN ROOM HINGE



HG-CV127

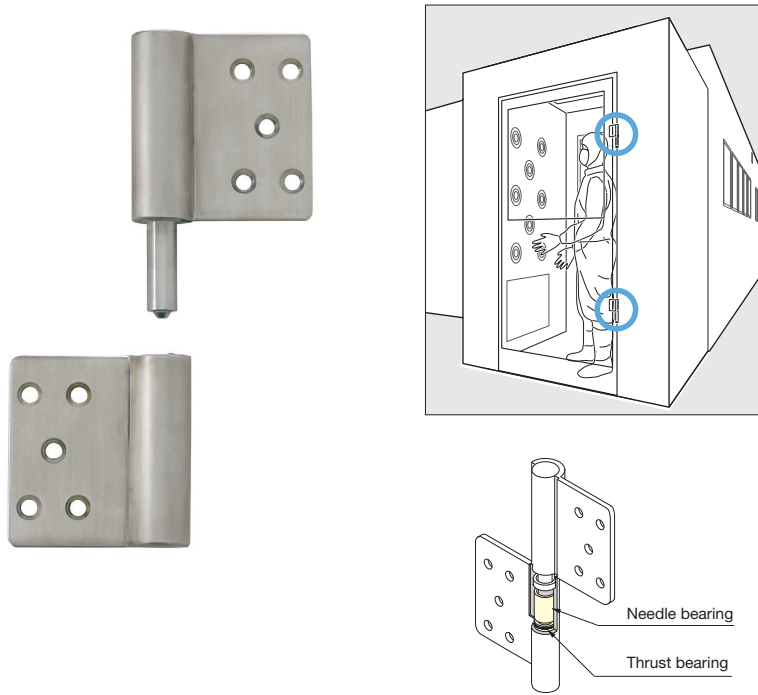

- No metal-to-metal contact.
- Special bearings minimize particles.
- Successfully passed 200,000 cycle test at the following door size.
 - Door Weight: MAX.100 kg/pair (220 lbs/pair)
 - Door Height: MAX.2,000 mm (78-3/4")
 - Door Width: MAX.900 mm (35-7/16")

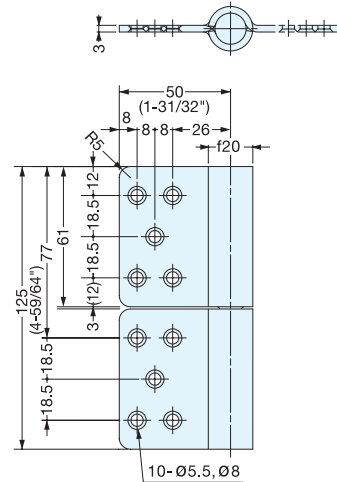



Item No.		Weight (g)	Box (pcs)	Carton (pcs)
Left	Right			
HG-CV127/L	HG-CV127/R	388	5	50

Material	Finish
304 Stainless Steel	Satin/Polished

CLEAN ROOM HINGE



HG-P100

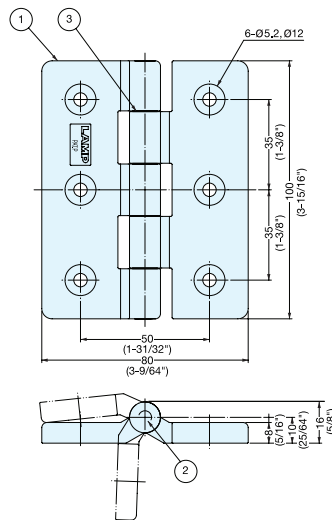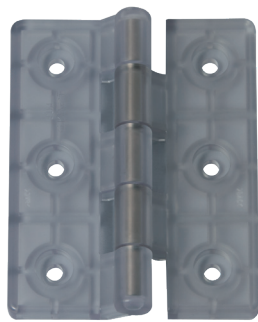

- Hinge leaves made with PVC material:
 - Ideal for semiconductor manufacturing machinery and transparent applications.
 - Weather and chemical resistant.
- Environmentally friendly - Lead free.
- Titanium pin

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Load Capacity (kgf / 2pcs)
HG-P100	74	30	240	10 (22lbs)

Material	Finish
Body	PVC
Hinge Pin	Titanium