


HIGH TEMPERATURE MAGNETIC CATCH



MC-YN005HP

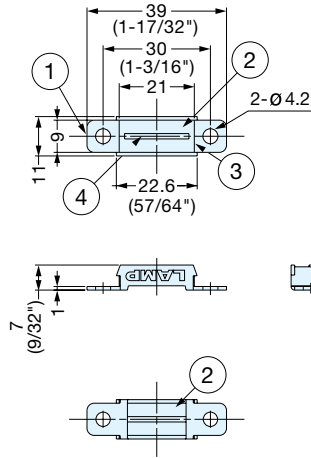

- Suitable for high temperature environments up to 250°C (482°F).
- Optional counterplates sold separately:
  - MC-JM49
  - AS-68


Item No.	Magnetic Force (kg)	Weight (g)	Box(pcs)	Carton(pcs)
MC-YN005HP-20	2.0 ( 4.4 lbs)	11	200	1000
MC-YN005HP-50	5.1 (11.0 lbs)			

No.	Part Name	Material	Finish/Color
①	Yoke	430 Stainless Steel	Plain
②	Magnet	Samarium Cobalt	-
③	Housing	304 Stainless Steel	Plain
④	Center Yoke	430 Stainless Steel	Plain

HIGH TEMPERATURE MAGNETIC CATCH



MC0083HP

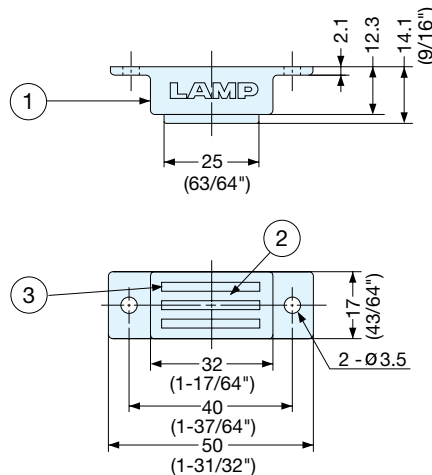

- Suitable for high temperature environments up to 250°C (482°F).
- Strong magnetic force.
- Optional counterplates sold separately:
  - MC-JM49
  - AS-68

Item No.	Magnetic Force (kg)	Weight (g)	Box(pcs)	Carton(pcs)
MC0083HP-70	7.1 (15.6 lbs)	40	40	400
MC0083HP-140	14.3 (31.5 lbs)			

No.	Part Name	Material	Finish/Color
①	Housing	304 Stainless Steel	Plain
②	Magnet	Samarium Cobalt	-
③	Yoke	430 Stainless Steel	Plain