



FLUSH SLAM LATCH




LC-48



- Door will be latched when closed.
- Pull paddle handle to open.
- Non-Handed: Can be installed on left or right side.
- Designed for panel thickness MAX 1.6 mm.
- Easy installation.
Insert the latch body through cutout section and simply screw-on the back plate.

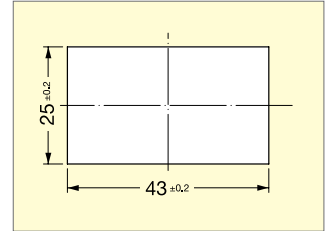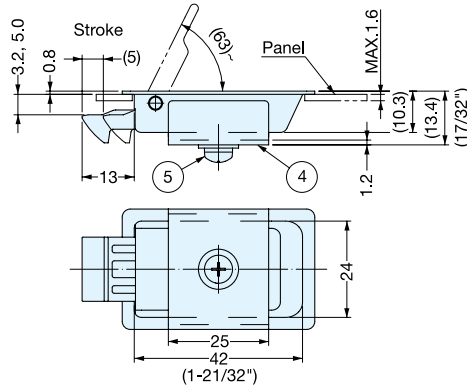

Cut Out Dimensions

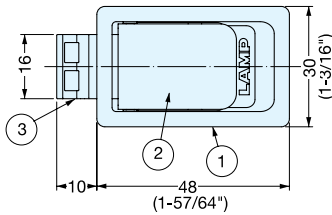

Item No.	Panel Thickness	Panel Thickness + Frame Thickness (mm)	Weight (g)	Box (pcs)	Carton (pcs)
LC-48-3	0.8 ~ 1.6	MAX 3.2	34	70	700
LC-48-5		MAX 5.0			

No.	Part Name	Material	Finish
①	Body	304 Stainless Steel	Plain
②	Lever		
③	Latch Bolt	PBT Plastic	White
④	Back Cover	304 Stainless Steel	Plain
⑤	Back Plate		



FLUSH SLAM LATCH





LC-65A



- Door will be latched when closed.
- Pull paddle handle to open.
- Non-Handed: Can be installed on left or right side.
- Designed for panel thickness 2.0~3.2 mm.
- Easy installation.
Insert the latch body through cutout section and simply screw-on the back plate.

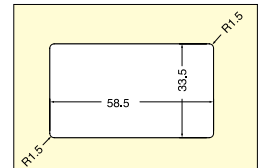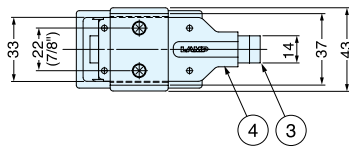

Cut Out Dimensions

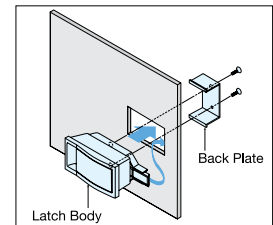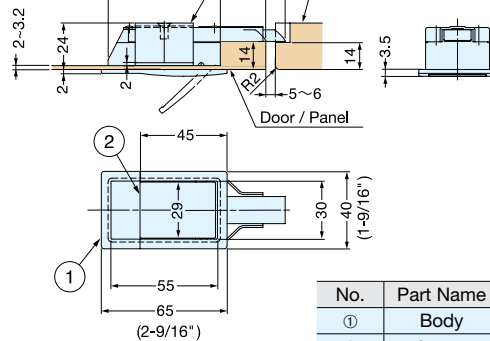

Item No.	Door Thickness (mm)	Weight (g)	Box (pcs)	Carton (pcs)
LC-65A	2.0 ~ 3.2	108	10	100

No.	Part Name	Material	Finish
①	Body	Aluminum Alloy	Silver
②	Lever		
③	Latch Bolt	Polyacetal	White
④	Back Cover	304 Stainless Steel	Plain
⑤	Back Plate		