

FULL EXTENSION SLIDE

LOAD RATING
50-95kg
110-209lbs



 





TSS-3

DRAWER SLIDES

STAINLESS STEEL SLIDES

- Full extension.
- Positive stop.
- Non-handed.
- Heavy duty.

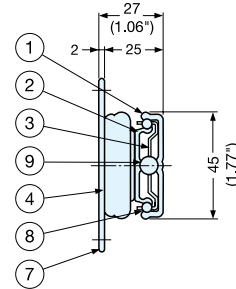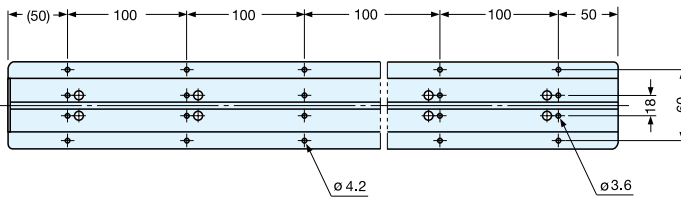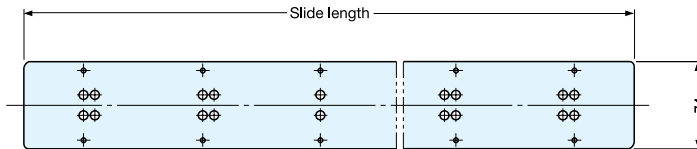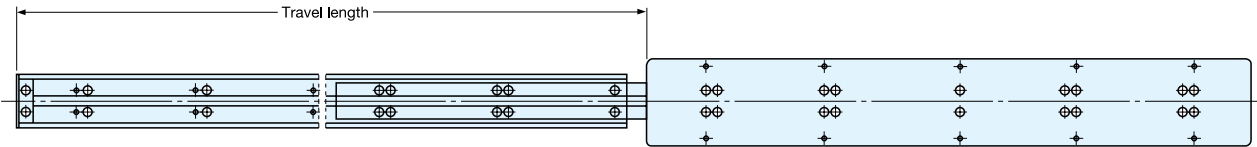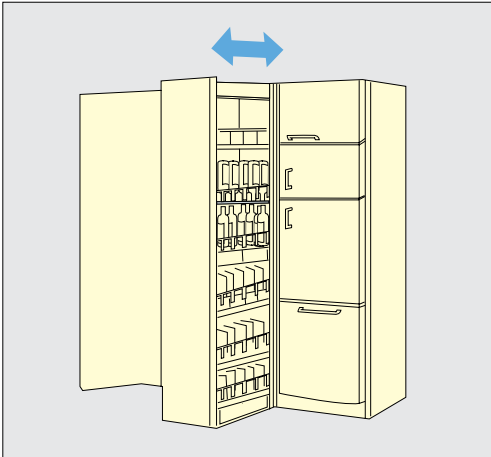

25.4mm=1"

| No. | Part Name | Material |
|-----|-------------|---------------------|
| ① | Outer Rail | 304 Stainless Steel |
| ② | Inner Rail | |
| ③ | Retainer | Polyamide |
| ④ | End Stopper | |
| ⑤ | Outer Guide | Polyacetal |
| ⑥ | Inner Guide | |
| ⑦ | Plate | 304 Stainless Steel |
| ⑧ | Large Balls | Steel |
| ⑨ | Small Balls | |

| Item No. | Slide Length | Travel Length | # of Holes | Load Rating (kg/pair) | Weight (g) | Box (pcs) |
|------------|------------------|------------------|------------|-----------------------|------------|-----------|
| TSS-3-300 | 300 (11-13/16") | 336 (13-15/64") | 6 | 95 (209 lbs) | 1380 | 4 |
| TSS-3-400 | 400 (15-3/4") | 436 (11-11/64") | 8 | 90 (198 lbs) | 1860 | |
| TSS-3-500 | 500 (19-11/16") | 536 (21-7/64") | 10 | 85 (187 lbs) | 2390 | |
| TSS-3-600 | 600 (23-5/8") | 636 (25-3/64") | 12 | 80 (176 lbs) | 2880 | |
| TSS-3-800 | 800 (31-1/2") | 836 (32-29/32") | 16 | 65 (143 lbs) | 3790 | |
| TSS-3-1000 | 1000 (39-3/8") | 1036 (40-25/32") | 20 | 50 (110 lbs) | 4710 | |