


STAINLESS STEEL TORQUE HINGE





HG-TS

HINGES


STAINLESS STEEL TORQUE HINGES

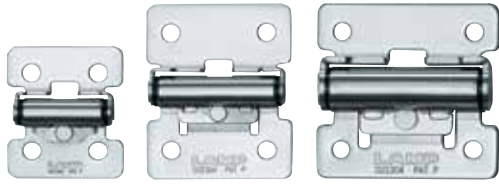


- Hinge with friction torque holds lid/door in desired position.
 - Stainless steel material ideal for harsh environments.
 - Free stop between 0~180 degrees.
 - Successfully passed 20,000 open/close private cycle tests.
- Note:
- Initial torque may vary - 20%~ + 40%.
 - At least 2 hinges necessary for 1 door.

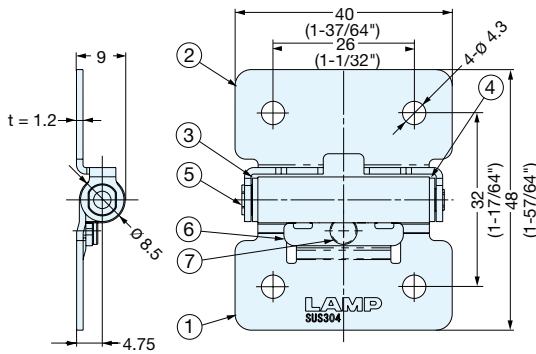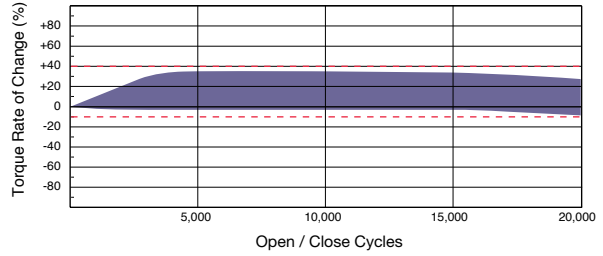


HG-TS07

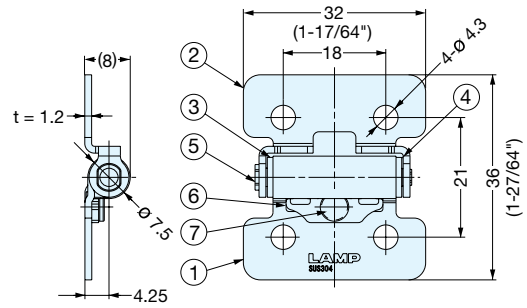

HG-TS03

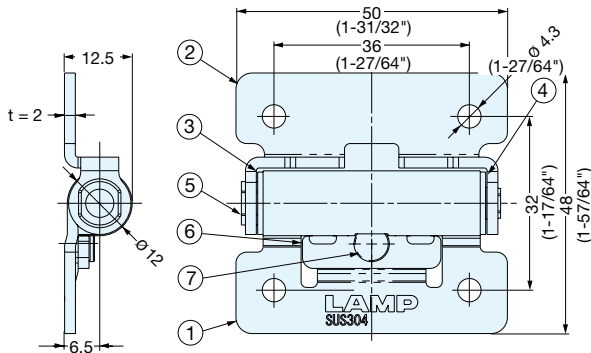

HG-TS15

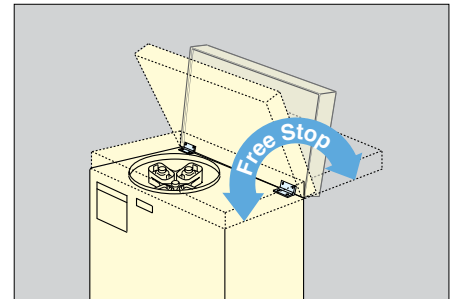

Item No.	Torque per piece (kgf-cm)	Weight (g)	Box (pcs)	Carton (pcs)
HG-TS03	3.6 (3.1 lbs-in)	15.0	50	500
HG-TS07	7.1 (6.2 lbs-in)	27.5		
HG-TS15	15.3 (13.3 lbs-in)	64.1	20	200

No.	Part Name	Material	Finish
①	Body	304 Stainless Steel	Polished
②	Base		
③	Fixing Tube	Polyacetal	Black
④	Fixing Tube		
⑤	Shaft	303 Stainless Steel	-
⑥	Press Washer	304 Stainless Steel	Polished
⑦	Pin		-