


HOOK



HJT

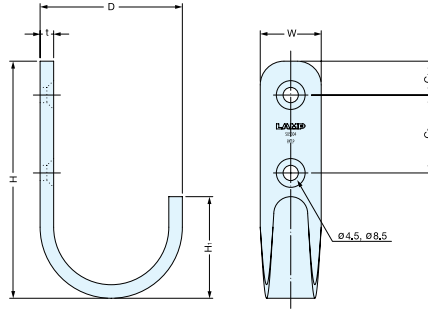

• 4mm thick material designed for excellent durability.

Material	Finish
304 Stainless Steel	Satin (S)/Black (BL)


Item No.	D	H	H <sub>1</sub>	t	W	C <sub>1</sub>	C <sub>2</sub>	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
HJT-55S	33 (9/32")	55 (5/32")	23	4	15	8	19	10 (22.0 lbs)	34	30	300
HJT-55SBL											
HJT-70S	43 (11/16")	70 (3/4")	30	4	18	10	23	8 (17.6 lbs)	53	20	200
HJT-70SBL											

SMALL HOOKS

FORK HOOK



EU

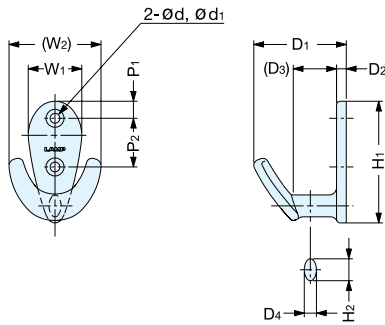

• Hook with unique design.  
 • Can hang 3 items at same time. Two on the tips and one on the neck.  
 • Two-pronged shape ideal for hats, coats, etc.

Item No.	W <sub>1</sub>	W <sub>2</sub>	D <sub>1</sub>	D <sub>2</sub>	D <sub>3</sub>	D <sub>4</sub>	H <sub>1</sub>	H <sub>2</sub>	d	d <sub>1</sub>	P <sub>1</sub>	P <sub>2</sub>
EU-50	22	38 (1-1/2")	38 (1-1/2")	4	17.8	5	50 (1-31/32")	9	4.0	7.4	7	20
EU-72	32	56 (2-13/64")	52 (2-3/64")	6	23.0	8	72 (2-53/64")	14	4.6	8.6	10	34


  

Item No.	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
EU-50	20 (44 lbs)	42	20	120	316 Stainless Steel	Mirror
EU-72	30 (66 lbs)	118	10	60		

HOOK



EW-65E, 80E

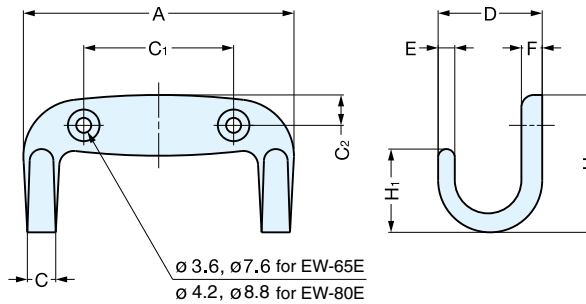

Material	Finish
304 Stainless Steel	Mirror

Item No.	A	C <sub>1</sub>	C	D	E	F	C <sub>2</sub>	H	H <sub>1</sub>	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)	Screw
EW-65E	65 (2-9/16")	36	6.5	25	4	5	7.3	33 (1-19/64")	20	20 (44 lbs)	52	10	100	3.1 × 16
EW-80E	80 (3-5/32")	44	8.0	32	5	6	9.0	42 (1-21/32")	25		93			3.8 × 20