



# RECESSED HOOK




NF-60



- Hook is spring loaded to retract.
- Ideal for vibration or shock applications.
- Panel Thickness: - Wood: Min. 25 mm (1")  
- Sheet metal: 0.8~1.6 mm with optional bracket NF-50, sold separately.

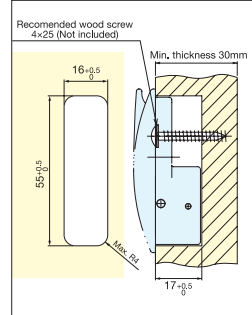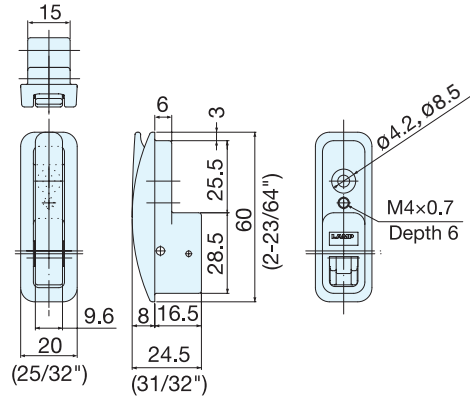

Bore Dimensions  
(For thickness over 30 mm)

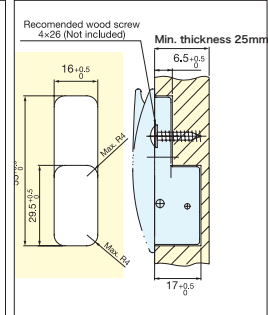

Bore Dimensions  
(For thickness 20~29 mm)

Part Name	Material	Color
Body	Aluminum	Grey
Pin/Spring	304 Stainless Steel	Plain
Rubber	Polychloroprene	Black



Item No.	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
NF-60	20 (44 lbs)	31	10	200

# RECESSED HOOK (W/SOFT CLOSE)

NF-60D



- Hook is spring loaded to retract and soft close.

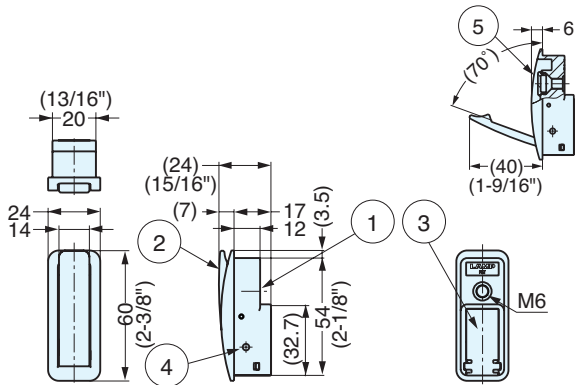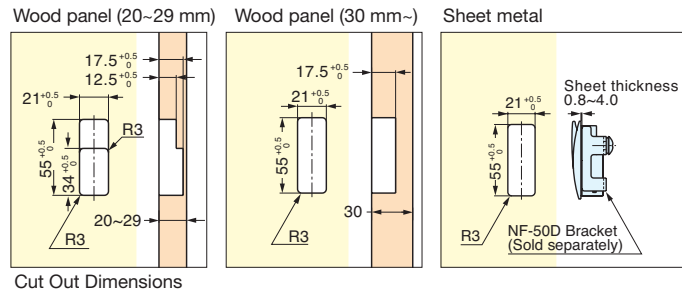

No.	Part Name	Material	Finish
①	Body	Aluminum Alloy	Dark Grey/Silver
②	Arm		Metallic Silver
③	Cover	Polyacetal	Dark Grey
④	Pin	304 Stainless Steel	Plain
-	Spring		
⑤	Bumper	Rubber	Black

Item No.	Color	Load Capacity (kg)	Weight (g)	Box (pcs)	Carton (pcs)
NF-60D/GR	Dark Grey	30 (66 lbs)	49	10	200
NF-60D/SL	Silver				
NF-60D/MSL	Metallic Silver				