
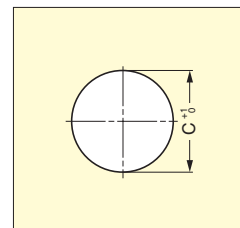


MULTI-PURPOSE LID (SOFT CLOSE)


STAINLESS
304
STEEL

AD-GD

- Soft and slow closing movement with a built-in damper mechanism.
- Horizontal use only.

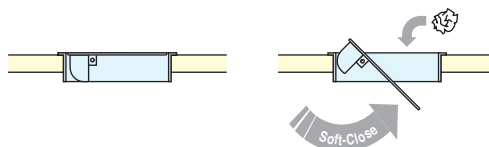

Cut Out Dimensions

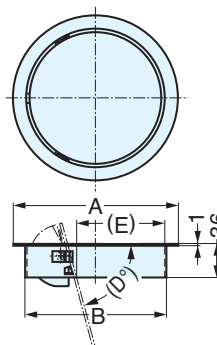

Material	Finish
304 Stainless Steel	Satin
303 Stainless Steel	
Polyacetal	
Steel	
CRC	
NBR (Rubber)	



Item No.	Old Item No.	A	B	C	D	E	Weight (g)	Box (pcs)	Carton (pcs)
AD-GD011-HL	AD-DH011-HL	5-23/64" (136)	4-11/64" (106)	4-7/32" (107)	3-27/64" (87)	2-7/16" (62)	460	1	10
AD-GD015-HL	AD-DH017-HL	6-11/16" (170)	5-3/4" (146)	5-25/32" (147)	2-61/64" (75)	3-35/64" (90)	1000		6
AD-GD020-HL	-	8-21/32" (220)	7-23/32" (196)	7-51/64" (198)	3-5/32" (80)	5-3/64" (128)	1060		4
AD-GD028-HL	-	11-13/16" (300)	10-55/64" (276)	10-15/16" (278)	3-1/32" (77)	7-21/64" (186)	1840		

MULTI-PURPOSE LID


STAINLESS
304
STEEL

AD-DH015-HL

- Self-leveling lid.
- Horizontal use only.

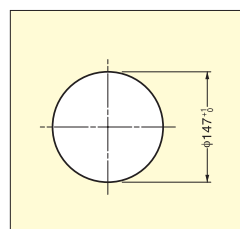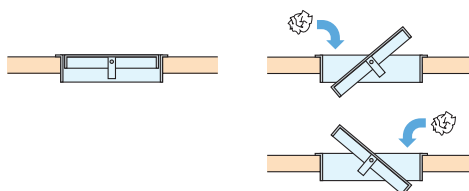

Cut Out Dimensions

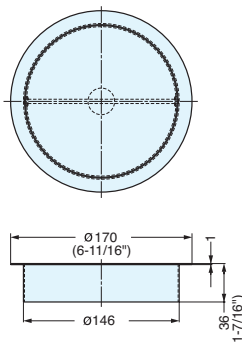

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
AD-DH015-HL	554	1	10	304 Stainless Steel	Satin