



HALF OVERLAY GLASS DOOR HINGE (W/CATCH)





GHC-34-8CR-K



- Half overlay.
- Hinge for glass/acrylic doors.
- Door thickness: 4-6 mm.
- Door size: Max. W450 x H700 (W17-3/4" x H27-9/16")
- Door weight: Max. 4 kg/pair (8.8 lbs/pain)
- Rounded plate GHC-34/8/CR is available.

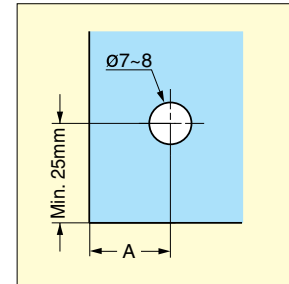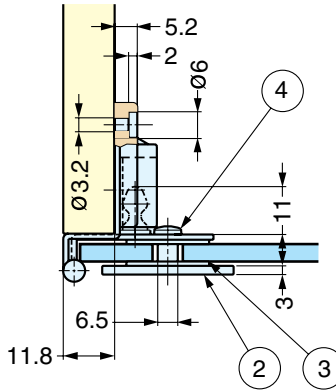

Cut Out Dimension

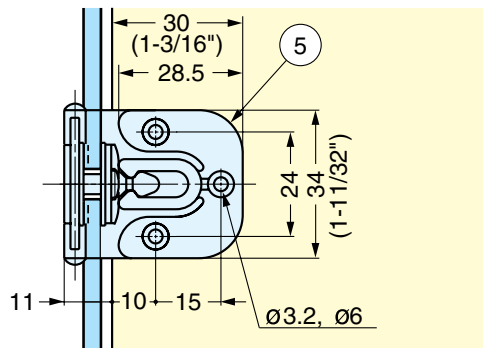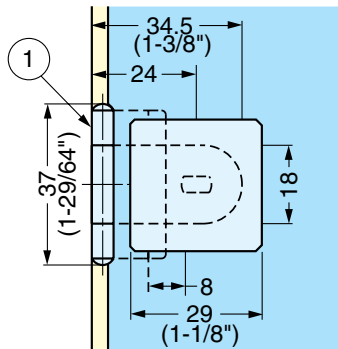

Glass Thickness (mm)	A (mm)	Overlay (mm)
4 (5/32")	19	7
5 (3/16")	18	6
6 (15/64")	17	5

No.	Part Name	Material	Finish/Color
①	Body	Steel	Chrome
②	Plate	Zinc Alloy	Chrome
③	Washer	PVC	Clear
④	Screw	Steel	Nickel
⑤	Stopper	Polyacetal (POM)	Black

Item No.	Weight (g)	Box (pcs)	Carton (pcs)
GHC-34-8CR-K	43	40	600