

STAINLESS STEEL MINI SLIDE FULL EXTENSION




SCR3-15S

 


B type shown.

- Full extension.
- Corrosion resistant.
- 3/8" (9.7 mm) side spacing.
- Thin profile design.

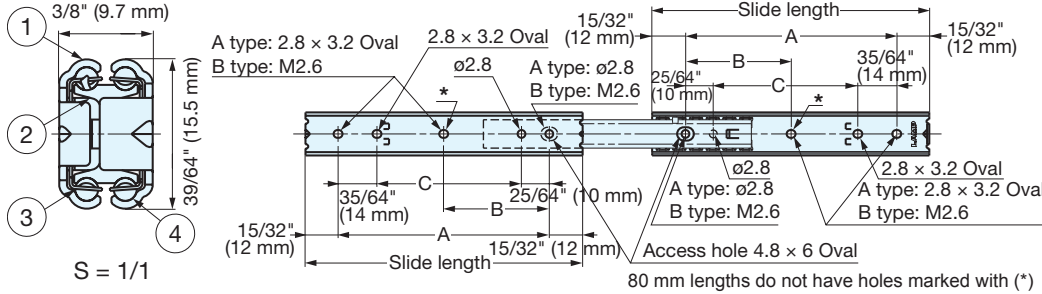

S = 1/1



No.	Part Name	Material
①	Outer Rail	304 Stainless Steel
②	Inner Rail	
③	Retainer	440 Stainless Steel
④	Bearing Balls	

Item No.	Holes	Slide Length	Travel Length	A	B	C	Load Capacity	Weight (g/pc)	Box (pcs)	Carton (pcs)
SCR3-15S-80A	A Type (Through Hole)	3-5/32" (80 mm)	3-13/16" (97 mm)	2-13/64" (56 mm)	-	1-17/64" (32 mm)	22.0 lbs (10 kgf)	36	50	200
SCR3-15S-100A		3-15/16" (100 mm)	4-59/64" (125 mm)	2-63/64" (76 mm)	1-1/2" (38 mm)	2-3/64" (52 mm)	24.2 lbs (11 kgf)	45		
SCR3-15S-150A		5-29/32" (150 mm)	6-31/32" (177 mm)	4-61/64" (126 mm)	2-31/64" (63 mm)	4-1/64" (102 mm)	26.4 lbs (12 kgf)	70		
SCR3-15S-80B	B Type (Screw Hole)	3-5/32" (80 mm)	3-13/16" (97 mm)	2-13/64" (56 mm)	-	1-17/64" (32 mm)	22.0 lbs (10 kgf)	36		
SCR3-15S-100B		3-15/16" (100 mm)	4-59/64" (125 mm)	2-63/64" (76 mm)	1-1/2" (38 mm)	2-3/64" (52 mm)	24.2 lbs (11 kgf)	45		
SCR3-15S-150B		5-29/32" (150 mm)	6-31/32" (177 mm)	4-61/64" (126 mm)	2-31/64" (63 mm)	4-1/64" (102 mm)	26.4 lbs (12 kgf)	70		