



in AMERICA



■ Kitchen & Bath Industry Show 2023





More Ways to Connect




Social Media and Beyond

Now more than ever, it is important to stay connected to see and share the latest in products and projects. Connect with us on your favorite social media platform, sign-up for our newsletters, visit our website regularly and subscribe to our YouTube channel for the latest Sugatsune news.



Scan the QR to sign-up
to our email list.

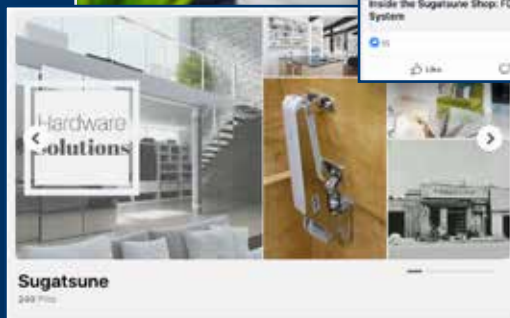


THE **VIRTUAL** SHOWROOM

We're pleased to bring you our all-new virtual showroom, designed to show hardware products such as hinges, hooks, lid stays, and door systems applied in various realistic living and work environments. The Sugatsune showroom features three environments, a small living space, manufacturing space, and medical area in addition to a lobby that allows customers to move around and play with featured hardware products. Paired with specification information, videos and other properties, visitors can experience and learn about new products as if they were going to a trade show or showroom.



SCAN TO EXPERIENCE

www.sugatsune.com/virtual-showroom

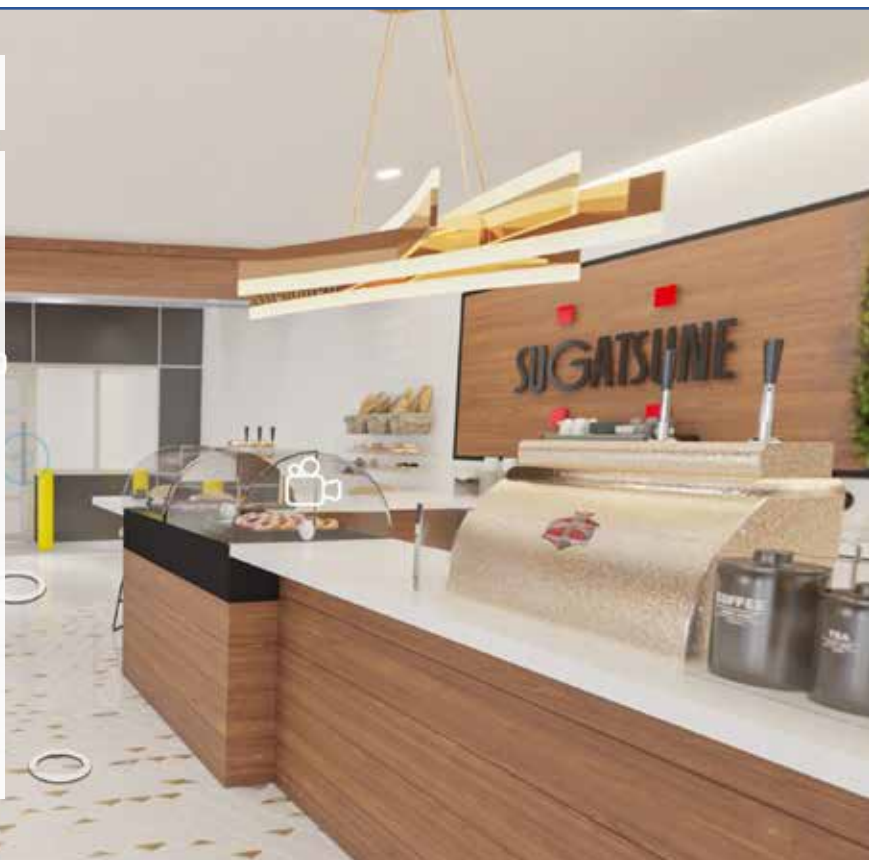

My friends at Sugatsune America Inc. opened their doors in the United States in 1982—and now, their 40-year anniversary of selling hardware and doing business in America is upon us... The use of hidden doors is a favorite touch for me, and I've always used Sugatsune's solutions to bring them to life... They've achieved great success in the United States, so far. To my friends at Sugatsune, let's have another 40 great years together!



—**Matt Risinger**
The Build Show Network



in **AMERICA**

serve this industry for many years to come.

As the first overseas subsidiary of Sugatsune Kogyo, Ltd, based in Japan for more than 90 years, we have continued to expand our line-up of architectural, industrial and specialty hardware here in America.

Our product lines include Sugatsune's proprietary soft motion Lapcon hardware, which you'll see throughout this brochure, complemented by our hinges, handles, catches, latches and other unique accessories.

As we look back at two very challenging years, not only for our industry but for our communities everywhere, we are grateful to our customers not only for their loyalty, but also for challenging us to develop new functional and decorative hardware to meet their application needs. Our commitment to innovation is matched by our commitment to providing unique, high quality products and customer service.


MonoFlat UNISON

	MFU1200-40	MFU1200-70
Door Width	31-1/2" ~ 47-1/4" (800~1200 mm)	
Door Height	Max. 106-5/16" (2700 mm)	
Door Thickness	1-3/16" ~ 1-9/16" (30~40 mm)	
Door Weight	44 ~ 88 lbs (20 ~ 40 kg)	88 ~ 154 lbs (40 ~ 70 kg)
Adjustability	Depth: ± 3.5 mm (1/8")	
	Horizontal: ± 4 mm (3/16")	
	Vertical: ± 4 mm (3/16")	

- Designed to CLOSE FLUSH against surrounding walls, providing a sleek appearance.
- UNIQUE MOVEMENT: Recesses in, and then slides sideways in a smooth continuous motion.
- CLEAN APPEARANCE: No floor tracks required on MFU-System.
- Excellent performance, reliable and fully adjustable.
- Features two-way damper to avoid slamming during opening or closing.
- DURABILITY: High durability, passed 100,000 open/close cycle test (private).



Item No.	Description	Door Weight
MFU1200-40-L (Light duty Left)	Left to Right Opening	44 ~ 88 lbs (20 ~ 40 kg)
MFU1200-40-R (Light duty Right)	Right to Left Opening	
MFU1200-70-L (Heavy duty Left)	Left to Right Opening	88 ~ 154 lbs (40 ~ 70 kg)
MFU1200-70-R (Heavy duty Right)	Right to Left Opening	

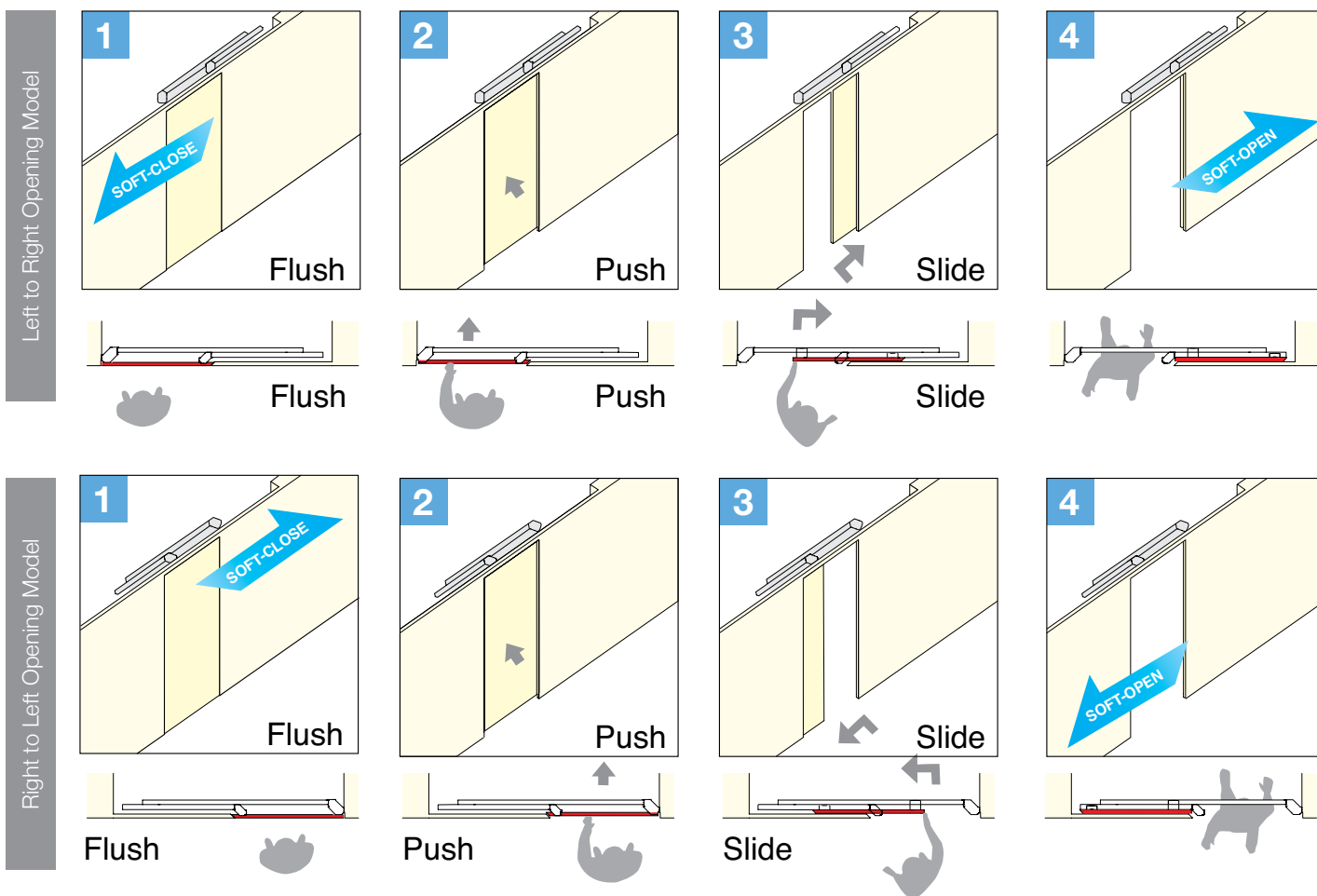

* The door cannot be opened from the inside without a handle (not included).



reddot award 2017
winner



GOOD
DESIGN

LIN-X1000



FULL SIZE DOORS LIN-X1000

- Lateral Opening Mechanism: Allows doors to swing out laterally in a small radius, ideal for tight front space application.
- Heavy Duty: Max. weight 198 lbs.(90 kg).
- 4-Way Adjustable: Vertical, horizontal, depth and parallel adjustment.
- Smooth Movement: Built-in dampers provide a smooth soft-closing movement.
- Use in various applications: Ideal for closet entryways, large pantry doors, storage, hidden rooms, etc.
- Hardware is non-handed: can be used for left-opening or right-opening doors.
- Designed for overlay installation, but can be installed flush with the surrounding cabinet or wall. Please contact customer service for details on inset installations.



GET MORE DETAILS

Door Width	29-1/2" ~ 43-5/16" (750 ~ 1100 mm)
Max. Door Height	117-5/16" (2980 mm)
Door Thickness	15/16" ~ 1-9/16" (24 ~ 40 mm)
Max. Door Weight	198 lbs (90 kg/door)

Item No.	Overlay	Material	Finish
LIN-X1000/WT-S	3/4"	Steel,	White
LIN-X1000/BL-S	(19 mm)	Aluminum	Black

Which System Works Best for You?

FOR DOORS

LIN-X1000

Door Width: 29-17/32" ~ 43-5/16" (750~1100 mm)
 Door Height: Max. 117-21/64" (2980 mm)
 Door Thickness: 15/16" ~ 1-37/64" (24~40 mm)
 Door Weight: Max. 198 lbs (90 kg) / Door

FOR MORE DETAILS
General Catalog Pg. 561

LIN-X800/LIN-X800H

Door Width: 29-17/32" ~ 33 7/16" (750~850 mm)
 Door Height: Max. 94-1/2" (2400 mm)/117-5/16" (2980 mm)
 Door Thickness: 15/16" ~ 1-9/16" (24~40 mm)
 Door Weight: Max. 88 lbs (40 kg) / Door

FOR CABINETS

LIN-X450

Door Width: 15-3/4" ~ 19-11/16" (400~500 mm)
 Door Height: Max. 94-1/2" (2400 mm)
 Door Thickness: 5/8" ~ 15/16" (15~24 mm)
 Door Weight: Max. 37.5 lbs (17kg) / Door

FOR MORE DETAILS
General Catalog Pg. 592

LIN-X600

Door Width: 21-5/8" ~ 25-9/16" (550~650 mm)
 Door Height: Max. 94-1/2" (2400 mm)
 Door Thickness: 5/8" ~ 15/16" (15~24 mm)
 Door Weight: Max. 52.8 lbs (24kg) / Door

SERIES FEATURES

- Easy Installation with 4-Way Adjustability
- Space-Saving with Lateral Movement
- Full Access to Corner Cabinets
- Soft, Self-Closing Movement
- No Track or Rails Needed
- Allows Door and Cabinets to Stop Freely




LIN-X800




LIN-X450

Adjustability

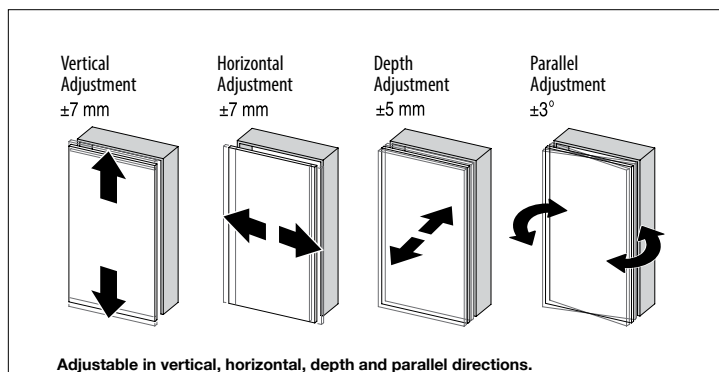

Installation Examples

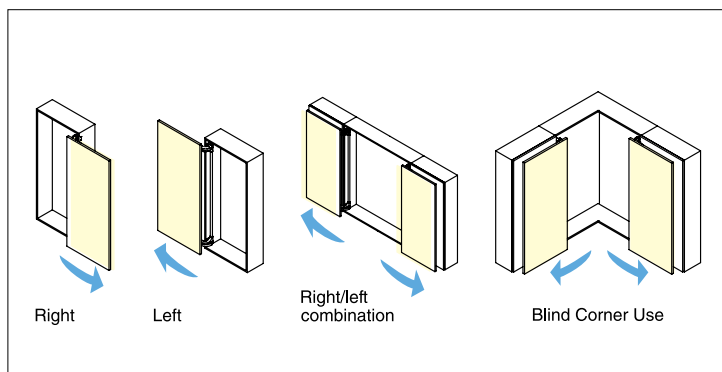

RECESSED MOUNT POCKET DOOR SYSTEM

FD80DHCHP-PD




	FD80DHCHP-PD Recessed Mount
Roller	Top Recessed on Door
Track Mounting	Ceiling
Door Weight	Min. 77 lbs (35 kg)
	Max. 176 lbs (80 kg)
Door Thickness	Recessed: 1-5/16" (34 mm)
Door Width	If less than 98-7/16" (2500 mm) 30-7/8" ~ 59-1/16" (784 ~ 1500 mm)
	If greater than 98-7/16" (2500 mm) 33-7/16" ~ 59-1/16" (850 ~ 1500 mm)
Door Height	Max. 106-5/16" (2700 mm)

How to order:

1. Select track and track length.
2. Choose hardware set.
3. See our General Catalog, pg. 535.3-535.4 for more details.

- Load capacity: 176 lbs (80 kg).
- Use with removable jamb/trim/casing.
- Easy installation and maintenance.
- Built-in soft-close and soft-open damper.
- Two-rail system, allows all components to be fixed or adjusted through the opening without breaking the pocket.
- Rollers are recessed mounted to top of door.
- High durability, passed 200,000 cycle test (private).
- For interior use only.

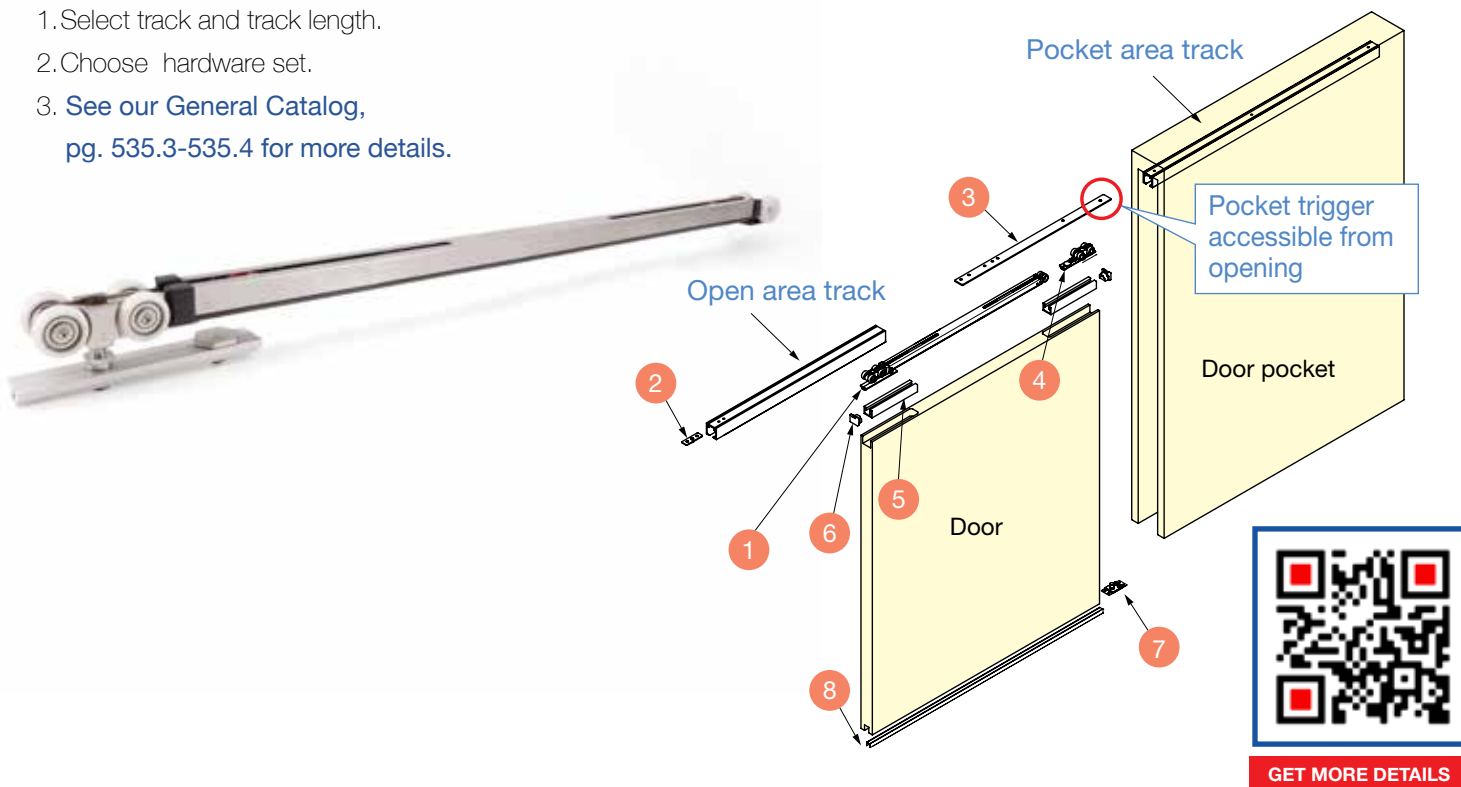

SURFACE MOUNT POCKET DOOR SYSTEM

FD80DHCMP-PD




	FD80DHCMP-PD Surface Mount
Roller	Top Surface on Door
Track Mounting	Ceiling
Door Weight	Min. 77 lbs (35 kg)
	Max. 176 lbs (80 kg)
Door Thickness	Surface: 1-3/16" (30 mm)
Door Width	If less than 98-7/16" (2500 mm) 30-7/8" ~ 59-1/16" (784 ~ 1500 mm)
	If greater than 98-7/16" (2500 mm) 33-7/16" ~ 59-1/16" (850 ~ 1500 mm)
Door Height	Max. 106-5/16" (2700 mm)

■ How to order:

1. Select track and track length
2. Choose hardware set
3. See our General Catalog, pg. 535.1-535.2 for more details.

- Load capacity: 176 lbs (80 kg).
- Use with removable jamb/trim/casing.
- Easy installation and maintenance.
- Built-in soft-close and soft-open damper.
- Two-rail system, allows all components to be fixed or adjusted through the opening without breaking the pocket.
- Rollers are surface mounted to top of door.
- High durability, passed 200,000 cycle test (private).
- For interior use only.

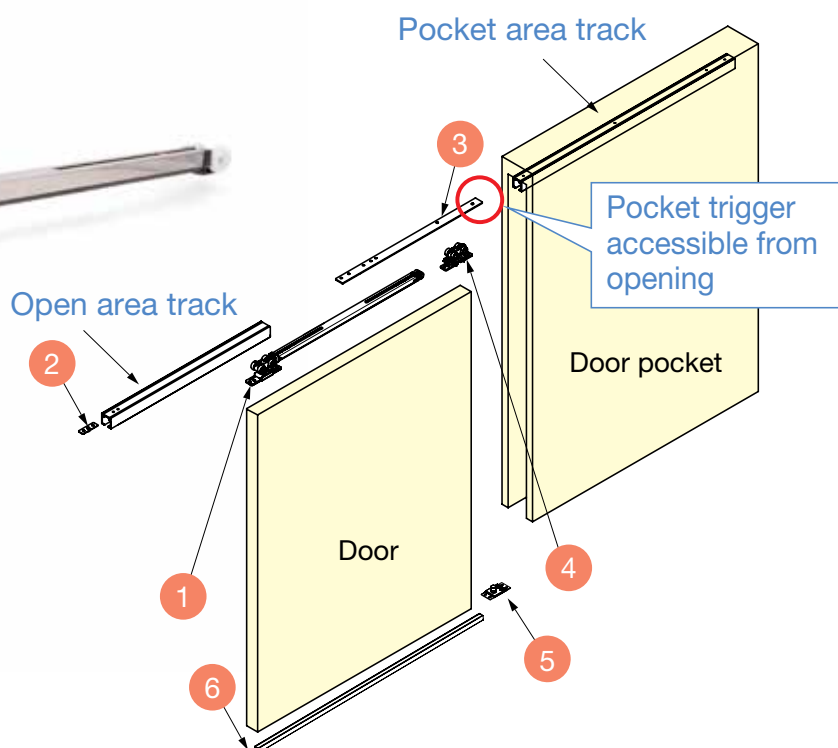

INSTALLATION

SOFT-CLOSE SYNCHRONIZED SLIDING DOOR SYSTEM

SDR-RA80SYN



	SDR-RA80SYN	
Type	Synchronized Bi-Parting	
Roller	Top Surface Mount	
Track Mounting	Ceiling	Wall with Continuous Bracket
Door Weight	Max. 176 lbs (80 kg)	
Door Thickness	Min. 1-1/16" (27 mm)	
Door Width	40 kg door (88 lbs) Min: 28-1/8" (715 mm) Max: 59-1/16" (1500 mm)	80 kg door (176 lbs) Min: 36" (915 mm) Max: 59-1/16" (1500 mm)

- Successfully passed 100,000 cycles test (private).
- 176 lbs (80 kg)
- Ceiling and Wall/Barn Door Mount
- Surface Mounted Door Brackets
- Double Rollers with Ball Bearings
- Quiet Precision Movement
- Soft Close Feature
- Vertical Adjustment $\pm 1/16"$ (1 mm)

■ How to order:


1. Select track and track length.
- 1A. Select any optional parts for track
2. Choose hardware set.

■ 1. Track Options

Track Type	Length	Item No.	Description
Standard Aluminum Track	78-3/4" (2000 mm)	SDR-RA80-2000	
	118-1/8" (3000 mm)	SDR-RA80-3000	

■ 1A. Optional Parts for Track

<p>SDR-RA80WL-2000 SDR-RA80WL-3000 Wall Mount Bracket</p>	<p>SDR-RA80-8083 End Cover for Track</p>	<p>SDR-RA80-8085 End Cover for Track & Wall Mount Bracket</p>
---	--	---

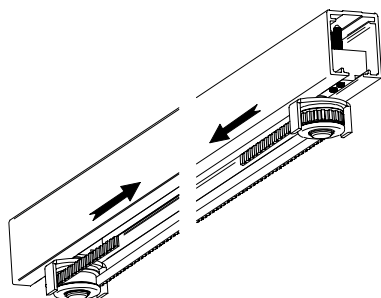

■ 2. Hardware Set


Load Rating (Per Door)	Item No.	Set Details
up to 88 lbs (40 kg)	SDR-RA80SYN-40	<p>Roller & Surface Door Mount Synchron. Set</p>
up to 176 lbs (80 kg)	SDR-RA80SYN-80	<p>Roller & Surface Door Mount Synchron. Set</p>

Adjustable Concealed Hinges

The HES2S Series




- Surface mounts to the door frame for easy installation.
- Minimum door thickness is 1-1/2" (38 mm).
- Opens to 125°, requires door stopper.
- ADJUSTABLE: D ± 3mm, V ± 3mm, H ± 1mm with spacer.
- Successfully passed 300,000 open/close private cycles.
- Compact and sturdy design combined with an exceptionally simple install.

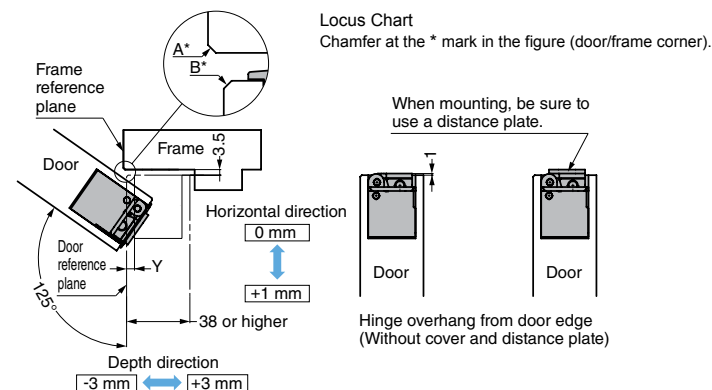

Y: Door Machining Margin	B: Door chamfering	A: Frame chamfering
4 or below	1 or higher	1 or higher
5		


CUT OUT DIMENSIONS Drill pilot holes at the positions of the adjustment and locating screws.

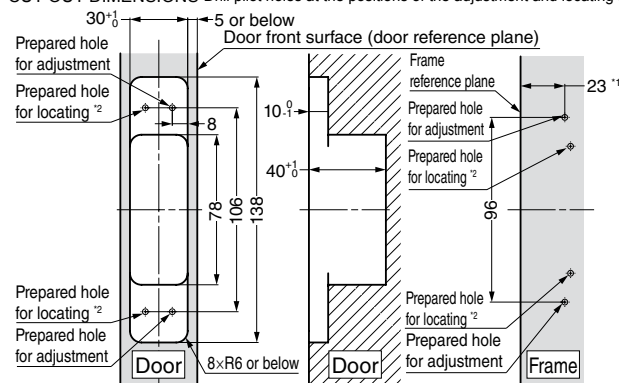

*1 When door machining margin is 5 mm.

Door Position Adjustment

• Vertical adjustment (±3 mm) • Horizontal adjustment (+1 mm) • Depth adjustment (±3 mm)

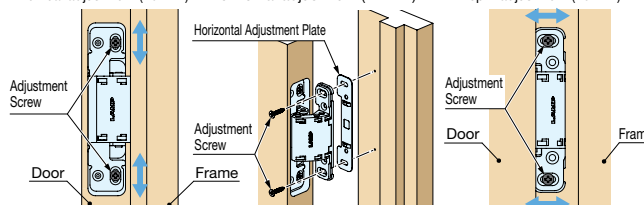

Adjust in the vertical/depth directions with oval hole screws and in the horizontal direction with the plate.




Item No.	Color	Door Width	Door Height	Door Thickness	Door Weight 2 pcs	Door Weight 3 pcs	Opening Angle
HES2S-140-A125-DGR	Dark Grey	Max. 35-7/16" (900 mm)	Max. 106-5/16" (2700 mm)	Min. 1-1/2" (38 mm)	Max. 110 lbs (50 kg)	Max. 143 lbs (65 kg)	125°
HES2S-140-A125-LGR	Light Grey						
HES2S-140-A125-BL	Matte Black						

3-Way Adjustable Concealed Hinges

The HES3D Series


EASY INSTALLATION

Here's why, Sugatsune's HES3D series hinges incorporate a feature that allows the hinge leaves to separate. One leaf is installed in the door frame, while the other is installed into the door itself. You can then install and adjust the door at any time.

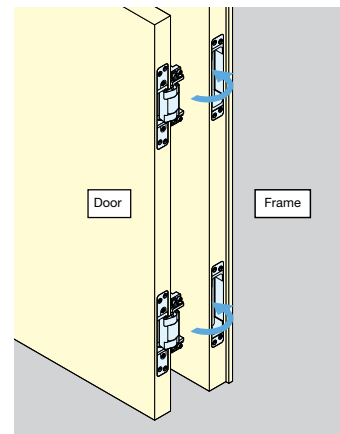


3-WAY ADJUSTABLE FEATURE

HES3D series hinges have vertical, horizontal, and depth adjustment features, so if your door isn't perfectly aligned on the first try, this feature allows adjustments in each direction.

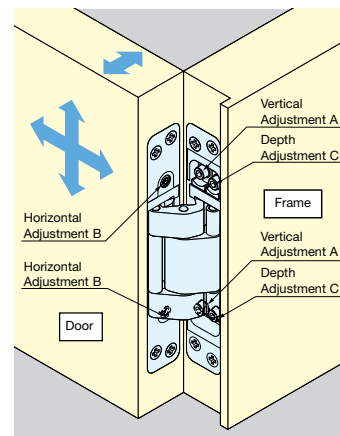

OVERALL LOOK

HES3D series hinges feature squared shape and round corners, comes with cover caps to hide all screws on the face of the hinge, so when your hinge is installed, it has a clean, sleek appearance.

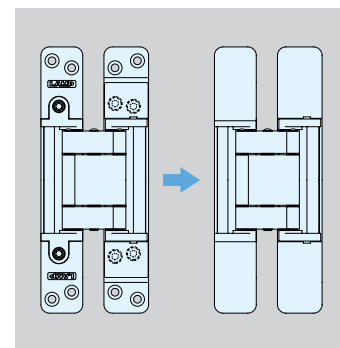

UL® LISTED

HES3D-E190 and HES3D-W190 are UL® Listed with **3 HOUR FIRE RATING.**



Cladded Doors HES3D-W190*

Min. Door Thickness: 1-5/8" (42 mm)

Max. Door Dimensions: 96-1/16" x 36" (2440 x 915 mm)

Max. Door Weight: 220 lbs (99 kg)/2 pcs or 275 lbs (125 kg)/3 pcs

Finishes: Dull Chrome, Dull Nickel, White, Polished Brass, Polished Nickel, Matte Black.

***UL Listed with
3 Hour Fire Rating**

FOR MORE DETAILS
General Catalog Pg. 185.1



HES3D-E190*

Min. Door Thickness: 1-1/2" (38 mm)

Max. Door Dimensions: 94-1/2" x 35-7/16" (2400 x 900 mm)

Max. Door Weight: 220 lbs (99 kg)/2 pcs or 275 lbs (125 kg)/3 pcs

Finishes: Dull Chrome, Dull Nickel, Polished Nickel, Matte Black, White

***UL Listed with
3 Hour Fire Rating**

FOR MORE DETAILS
General Catalog Pg. 184



HES3D-E160

Min. Door Thickness: 1-3/8" (35 mm)

Max. Door Dimensions: 94-1/2" x 35-7/16" (2400 x 900 mm)

Max. Door Weight: 121 lbs (55 kg)/2 pcs or 154 lbs (70 kg)/3 pcs

Finishes: Dull Chrome, Dull Nickel, Matte Black

FOR MORE DETAILS
General Catalog Pg. 183



HES3D-120


Min. Door Thickness: 1-1/8" (29 mm)

Max. Door Dimensions: 94-1/2" x 35-7/16" (2400 x 900 mm)

Max. Door Weight: 66 lbs (30 kg)/2 pcs or 88 lbs (40 kg)/3 pcs

Finishes: Dull Chrome, Dull Nickel, Matte Black

FOR MORE DETAILS
General Catalog Pg. 182

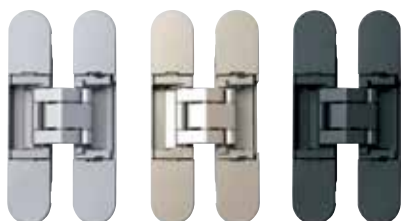

HES3D-90

Min. Door Thickness: 15/16" (23 mm)

Max. Door Dimensions: 59-1/16" x 23-5/8" (1500 x 600 mm)

Max. Door Weight: 26 lbs(12 kg)/2 pcs or 35 lbs(16 kg)/3 pcs

Finishes: Dull Chrome, Dull Nickel, Matte Black

FOR MORE DETAILS
General Catalog Pg. 310



HES3D-70

Min. Door Thickness: 3/4" (19 mm)

Max. Door Dimensions: 47-1/4" x 23-5/8" (1200 x 600 mm)

Max. Door Weight: 19.8 lbs (9 kg)/2pcs or 26.4 lbs (12 kg)/3 pcs

Finishes: Dull Chrome, Dull Nickel, Matte Black

FOR MORE DETAILS
General Catalog Pg. 309


SPRING HINGES

STAINLESS
304
STEEL
ALUMINUM


JSA

- Spring loaded for self-closing.
- Adjustable spring tension.
- Available in 2 sizes/strengths.
- Available in stainless steel and aluminum.
- Successfully passed 500,000 open/close private cycle tests.

Adjustable Spring Tension

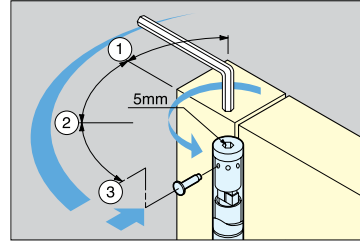

Self Closing

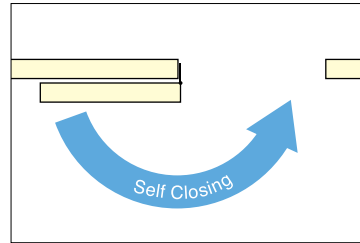

JSA-120A



JSA-180S

Item No.	Material	Finish
JSA-120A	Aluminum	Anodized
JSA-180A		
JSA-120S	304 Stainless Steel	Satin
JSA-180S		

Item No.	Load Capacity		Weight (g)	Box (pcs)	Carton (pcs)
	2 Hinges	3 Hinges			
JSA-120A	44 lbs (20 kg)	66 lbs (30 kg)	175	2	20
JSA-180A	88 lbs (40 kg)	132 lbs (60 kg)	260		
JSA-120S	44 lbs (20 kg)	66 lbs (30 kg)	303		
JSA-180S	88 lbs (40 kg)	132 lbs (60 kg)	526		

DOUBLE ACTION SPRING HINGE



JDA






JDA-120-30A




JDA-180-38S



- Spring loaded for self-closing.
- Adjustable spring tension.
- Available in 7 sizes and 2 materials.
- For 2-way swinging doors.
- Available in stainless steel and aluminum.
- Successfully passed 500,000 open/close private cycle tests.

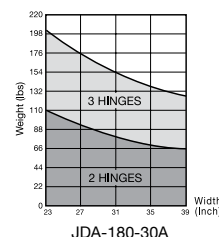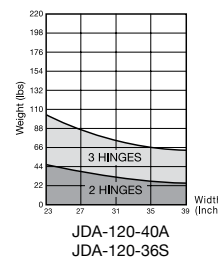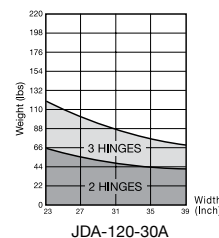

Installation

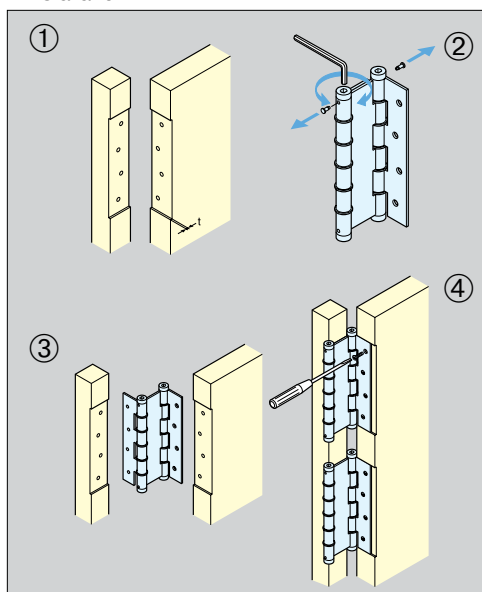

Item No.	Max. Door Thickness	Weight (g)	Material	Finish	Box (pcs)	Carton (pcs)
JDA-120-30A	1-3/16" (30 mm)	275	Aluminum	Anodized	2	20
JDA-120-40A	1-9/16" (40 mm)	320				
JDA-180-30A	1-3/16" (30 mm)	407				
JDA-180-40A	1-9/16" (40 mm)	466				
JDA-180-50A	1-31/32" (50 mm)	510	304 Stainless Steel	Satin	2	20
JDA-120-36S	1-13/32" (36 mm)	555				
JDA-180-38S	1-1/2" (38 mm)	947				





DOUBLE ACTION SPRING HINGE Wall Mount



JDAW



- Spring loaded/self closing.
- Adjustable spring tension.
- Available in 2 sizes/strengths.
- Requires 8 #8 flathead countersunk screws, 3/4" or longer (not included).

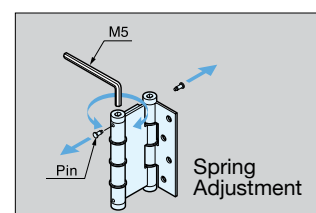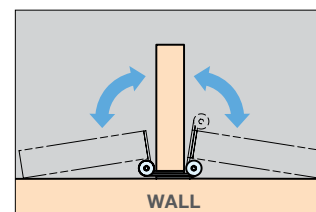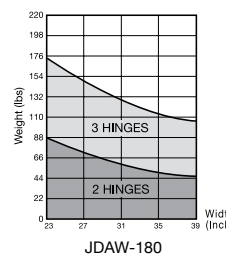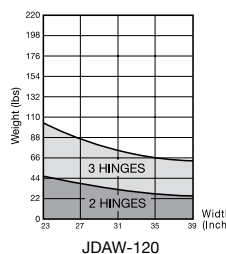

Item No.	Door Thickness	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
JDAW-120-35A	1-3/8" (35 mm)	350	2	20	Aluminum	Anodized
JDAW-180-35A						


A NEW STEP FOR HINGE TECHNOLOGY

FOR MORE DETAILS
General Catalog Pg. 293

OLYMPIA

360 POWERED BY  Lapcon.

Concealed Hinge with
Adjustable Soft-Close

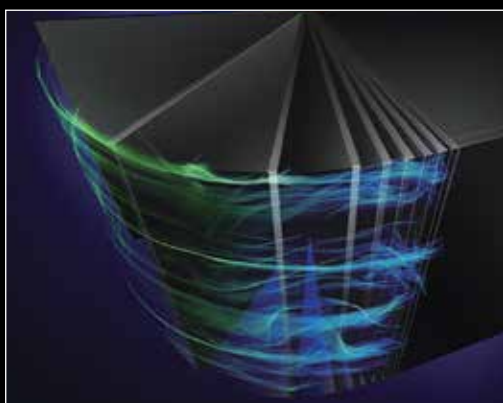

5-speed adjustable soft-close.
The first Sugatsune concealed hinge
ever built with Lapcon technology.

This is the first time Sugatsune's unique Lapcon technology has ever been used inside a concealed hinge. The innovative rotary damper is not only extremely compact with a sleek overall design, but its force can also be adjusted to perfection in 5 steps, regardless of the door size or weight.

CONCEALED HINGE with Adjustable Soft-Close

360-26/C26/D26-19T/19T85

(19 mm overlay)



(14 mm overlay)



(9 mm overlay)



- Available for 19mm, 14mm and 9mm overlays.
- Featuring 5-speed adjustable damper.
- Load capacity:
 - 6 kg (13.2 lbs)/2 pcs, 10 kg (22 lbs)/3 pcs.
- Maximum door width:
 - 600 mm (23-5/8"), thickness: 20 mm (13/16").
- Clip-on type for easy installation, 3-way placement adjustment.
- Mounting plate sold separately.
- Successfully passed 200,000 cycles test.

OLYMPIA
SOFT-CLOSE SYSTEM

CONCEALED HINGE with Adjustable Soft-Close

360-26/C26/D26/U26-OT

(Inset)



- Inset type hinge.
- Featuring 5-speed adjustable damper.
- Load capacity:
 - 6 kg (13.2 lbs)/2 pcs, 10 kg (22 lbs)/3 pcs.
- Maximum door width:
 - 600 mm (23-5/8"), thickness: 20 mm (13/16").
- Clip on type for easy installation, 3-way placement adjustment.
- Mounting plate sold separately.
- Successfully passed 200,000 cycles test.

OLYMPIA
SOFT-CLOSE SYSTEM

MOUNTING PLATES



360-P4W-32T

- Available in Standard and +5 mm types
- 2-holes plate



360-P4W-32T-DS

- Plate featuring pre-mounted screws
- 2-holes plate



360-P3W-53T

- Slim design gives a sleek look



360-P6WT

- Available in Standard and +5 mm types
- 4-holes plate


The J160 Overlay Hinge





Nickel (NI)



Black Nickel (BN)

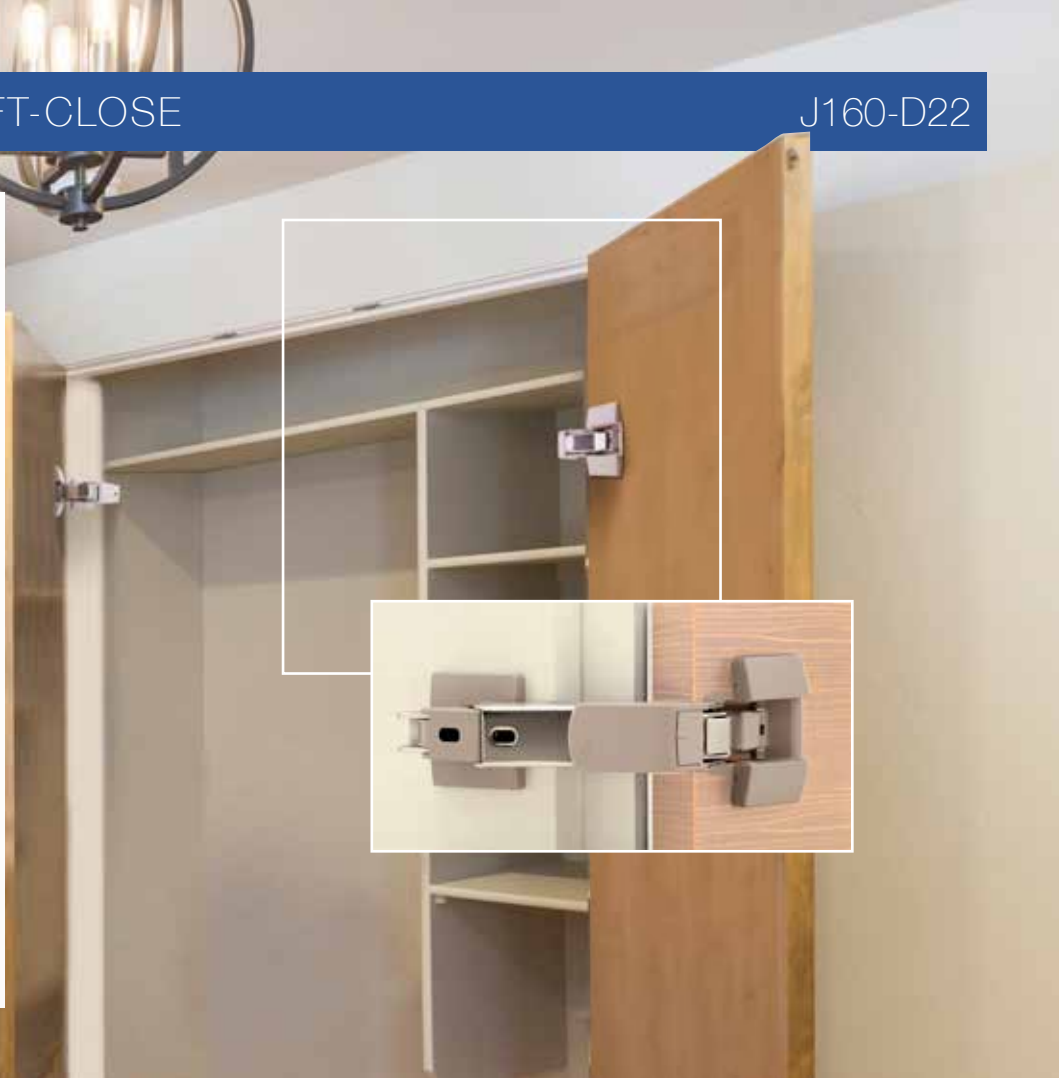

FOR MORE DETAILS
General Catalog Pg. 307.1

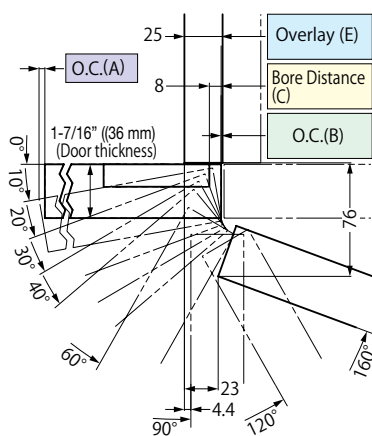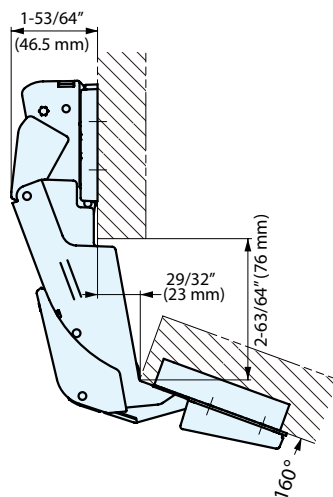

- 3-way adjustability after installation.
- Load capacity:
55 lbs (25 kg)/2 pcs,
88 lbs (40 kg)/3 pcs.
- Maximum door width:
31-1/2" (800 mm)/2 pcs,
35-7/16" (900 mm)/3 pcs.
- Wide-opening hinge allowing 160° opening.
- Successfully passed 50,000 open/close private cycle test.
- Recommended door thickness:
11/16~1-7/16" (18~36 mm).
- Includes mounting plates and screw covers.
- Built in damper allows soft-close.

Item No.	Weight (g)	Box (pcs)	Carton (pcs)	Material	Finish
J160-D22-25T-NI	710	1	12	Steel, Zinc Alloy (ZDC), Glass Filled Polyamide (PA)	Nickel (NI)
J160-D22-25T-BN					Black Nickel (BN)

The Seriously HEAVY DUTY Concealed Hinge!

Imagine using 2 or 3 hinges where 5 or 6 are usually needed, **THE J95 HEAVY DUTY CONCEALED HINGE** can do just that, with 55 lbs load capacity for one pair or 88 lbs for three hinges.

Available in free-swinging and self-closing, nickel and black finishes.



Nickel (NI)



Black Nickel (BN)



Nickel (NI)



Black Nickel (BN)

J95-24/25T

25 mm overlay
Opening angles: 95°

J95-24/16T

16 mm overlay
Opening angles: 95°



Nickel (NI)



Black Nickel (BN)

J95-24/0T

Inset
Opening angles: 95°



J95ZC, J95SC

Plate and Hinge Covers
in Gray, Black and Chrome



KBIS EXCLUSIVE Door Straighteners

Preserve Quality

Just because a cabinet leaves the shop doesn't mean that the quality shouldn't stay with it and **Sugatsune's Door Straighteners Series** can do just that. Preserve the quality of your work against warping due to moisture or extreme temperatures.

Our line of Door Straighteners can be concealed, placed at time of manufacturing or retrofitted to correct warping. See our complete line at **sugatsune.com**.




GET MORE DETAILS




sugatsune.com

DSR DOOR STRAIGHTENERS SERIES

RECESSED/SURFACE DSR701

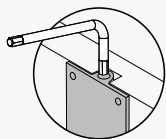


PARTIALLY RECESSED

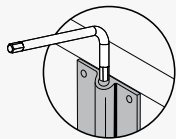

SURFACE

- Can be installed post-production to fix warping.
- Must run complete height of the door.
- Can be partially recessed or surface mounted to the back of the door.
- ±10 mm adjustment can be made from the top of the door with a M4 Allen Key (included).
- Minimum door thickness: 16 mm (9/16").
- Requires M4 flathead wood countersunk screws for partially recessed installation or wood panhead screws for surface installation.
- Can be cut from the bottom up to 400 mm.

Item No.	Length Min-Max	Materials	Finish
DSR701-1830/B-10	56-5/16" ~ 72-1/16"	Rod: Steel Casing: Aluminum	Black
DSR701-1830/S-10			Silver
DSR701-2200/B-10	70-7/8" ~ 86-5/8"		Black
DSR701-2200/S-10			Silver

 


RECESSED DSR213



Plastic cover caps included

- Installed at time of production to prevent door from warping.
- Adjustors installed 60 mm from the top and bottom of the door.
- Partially recessed door straightener with cover caps.
- ±10 mm adjustment can be made from the top of the door with a M4 Allen Key (included) or from the back of the door with a M8 slot wrench (included).
- Min. door thickness: 16 mm (5/8")
- Requires 8 M4 flathead countersunk wood screws for installation.


Item No.	Center Distance	Door Length	Finish
DSR213-1524-25	43-7/16" ~ 60"	48-3/16" ~ 64-3/4"	Plain, White
DSR213-1930-25	59-7/16" ~ 76"	64-3/16" ~ 80-11/16"	
DSR213-2330-25	75-3/16" ~ 91-3/4"	79-15/16" ~ 96-7/16"	
DSR213-2700-25	89-3/4" ~ 106-5/16"	94-1/2" ~ 111"	

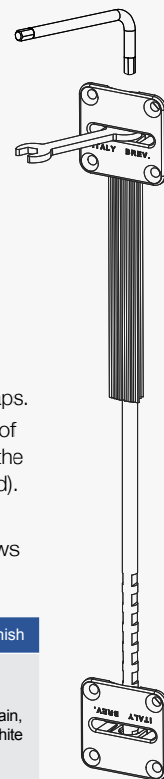

CONCEALED DSR423

- Installed at time of production to prevent door from warping.
- Adjustors installed 60 mm from the top and bottom of the door.
- Fully concealed/hidden door straightener. Recessed mounted under laminate.
- ±10 mm adjustment can be made from the top of the door with a M4 Allen Key (included).
- Min. door thickness: 12 mm (1/2").
- Optional mounting holes to secure door straightener to door using 4 M4 (U.S. #8) flathead countersunk wood screws.

Item No.	Center Distance	Door Length	Finish
DSR423-1524-25	43-7/16" ~ 60"	48-3/16" ~ 64-3/4"	Plain
DSR423-1930-25	59-7/16" ~ 76"	64-3/16" ~ 80-11/16"	
DSR423-2300-25	74" ~ 90-9/16"	78-3/4" ~ 95-1/4"	
DSR423-2700-25	89-3/4" ~ 106-5/16"	94-1/2" ~ 111"	

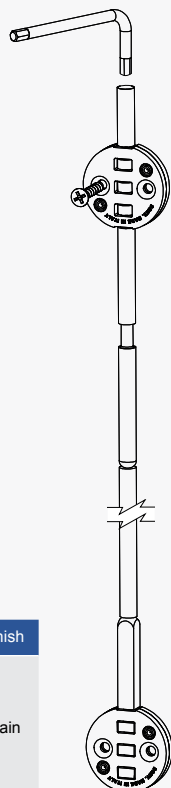


CONCEALED DSR403



Both concealed models can be installed under laminate.

- Installed at time of production to prevent warping.
- Adjustors installed 60 mm from the door edges.
- Fully Concealed. Recess mounted under finish.
- ±10 mm adjustment can be made from the top of the door with a M4 Allen Key (included).
- Min. door thickness 18 mm (11/16").
- No screw installation, pressure-fit into place.

Item No.	Center Distance	Door Length	Finish
DSR403-1524-25	43-7/16" ~ 60"	48-3/16" ~ 64-3/4"	Plain
DSR403-1930-25	59-7/16" ~ 76"	64-3/16" ~ 80-11/16"	
DSR403-2300-25	74" ~ 90-9/16"	78-3/4" ~ 95-1/4"	
DSR403-2700-25	89-3/4" ~ 106-5/16"	94-1/2" ~ 111"	

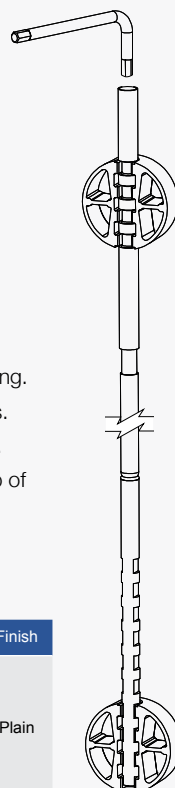

Glass Hardware

Sugatsune's premium glass hardware showcases a wide ranges of hinges, face plates, brackets, dampers, locks, catches, and more. Our glass hardware uniform designs helps accentuate the beauty of the cases and displays while keeping exhibited product accessible and secured.

Our glass hardware features sleek shapes and contours that draw the eye to the display creating the perfect showcase for your product.

GS-GB5 - Glass Bracket



GS-GH50 - Glass Hinge



GS-GL20 - Glass Door Cam Lock



Million Lock Series, Available in 3 finishes





 
Glass Hinges & Face Plates



GH-456C
Half Overlay Glass Door Hinge
Available in 3 finishes.



J95 Hinges
Heavy Duty Concealed Hinge
Available in 2 finishes & 3 configurations.




GH-360FP
Glass Door Face Plate
Designed for the Olympia Hinge, 4 finishes.



GS-GH5
Inset Glass Door Hinge
Available in 2 finishes.

Glass Locks

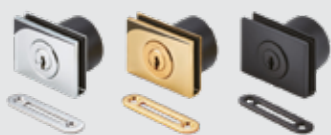

GH-GL5
Glass Door Cam Lock
Million Lock Series, Available in 3 finishes.



1310GL-SQ
Cylinder Glass Lock
Million Lock Series, Available in 4 finishes.

 


1310GLW
Glass Door Cam Lock
Million Lock Series, Available in 3 finishes.



Million Lock Keys
Compatible across models.

Glass Brackets



GS-GB20
Glass Bracket
Available in 3 finishes.



XL-GC05
Glass Bracket

Glass Door Pulls

Zwei L



ZL-1505
Glass Door Pull



ZL-1504
Glass Door Pull

LIFT-ASSIST DAMPER (Heavy Duty)





LADH



- Add a smooth soft-close to counter tops in restaurants, bars and reception desks to prevent slamming.
- Lift-Assist feature helps users lift countertop
- Holds door open at 95 degrees.
- Easy installation - surface mounted and can be retrofitted.
- Stainless steel piano hinge included.



- Set includes stainless steel piano hinge (LSN-C).
- Hinge can be cut to desired length.

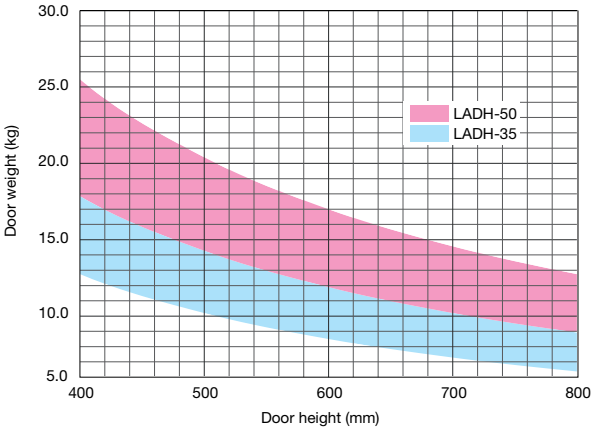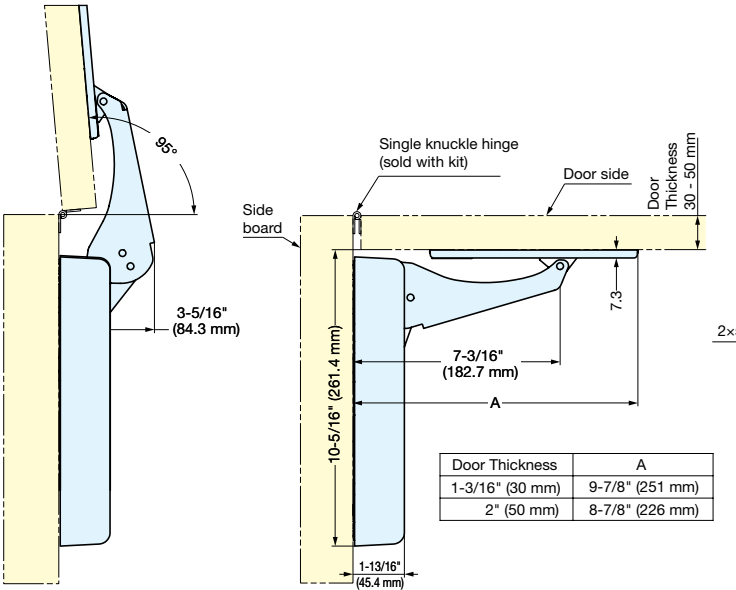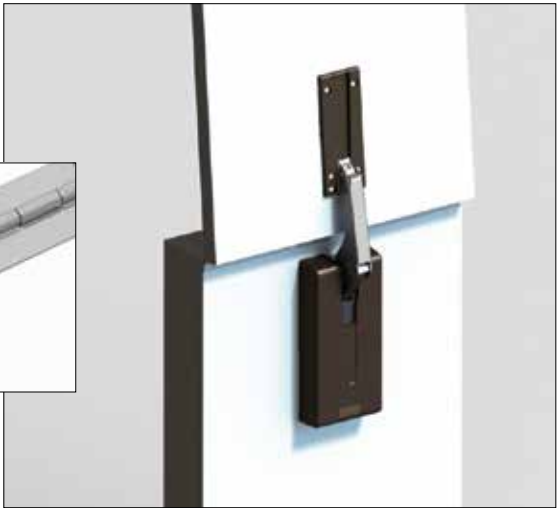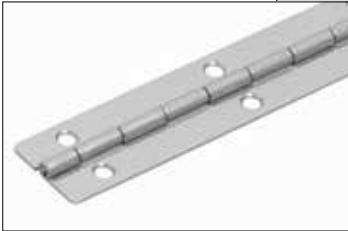

Item No.	Max. Torque/pc (lbs-in)	Panel Thickness	Wt (Kg)	Box (pcs)	Material	Finish
LADH-35	221 ~ 309	30~50 mm (1-3/16" ~ 2")	2	1	Steel (SPCC)/ Polyacetal (POM)/ABS	Arm: Nickel Chrome Body: Dark Brown
LADH-50	309 ~ 442					
LADH-35WT	221 ~ 309					Arm: Nickel Chrome Body: White
LADH-50WT	309 ~ 442					

LADH Lift-Assist Damper
can be used in pairs

The TALLMAN

Closet Rod Lift Mechanism



TAT (T-TYPE)

- The T-type model is designed for front facing installation with the use of a bracket which is sold separately (TAB).
- Create space more efficiently by separating short and long clothes.

Load capacity: Up to 17.6 lbs.
(evenly distributed).

Specification	Grey (G)
Right-Hand	TAT-800R/G
Left-Hand	TAT-800L/G

TAS (SINGLE TYPE)



TAS-800R/U (Right)

- This single-type model, designed for installation on a side wall of a cabinet or closet.
- Both right-hand and left-hand models are available.

Load capacity: Up to 17.6 lbs.

	Grey (G)	Umber (U)
RT-Hand	TAS-800R/G	TAS-800R/U
LT-Hand	TAS-800L/G	TAS-800L/U

TAW (DOUBLE TYPE)



TAW-1200/U

- The double-type model, designed for installation on side walls of a cabinet or closet.
- Adjusting the length of the rod is easily done in just one step.

Load capacity: Up to 33 lbs.


Grey (G)	Umber (U)
TAW-1200/G	TAW-1200/U

SLIDING DOOR LATCH

HC-3051 SERIES



- Recessed latch handle for wooden sliding doors.
- 4 model types available.
- The backset can be installed at any position between 1-3/16"~2" (30 mm~51 mm) from the door edge.
- Applicable door thickness: 1-3/8"~1-3/4" (35mm ~ 45 mm).
3 different lengths of spindles and 2 different lengths of screw are included. Initial setting is for 1-1/2" (38 mm) door.

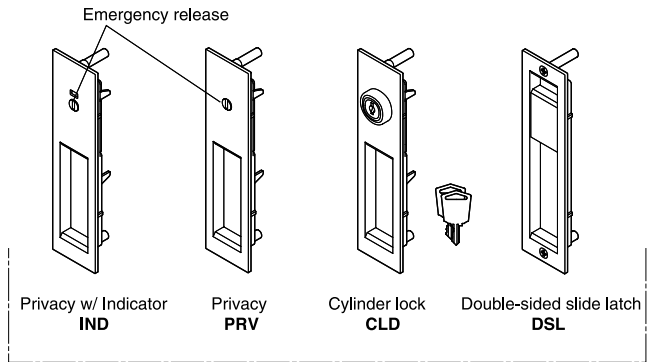


■ Latch Body & Strikeplate



■ Latch Faceplates



The opposite face of every model has a slide handle, as shown for the DSL model.

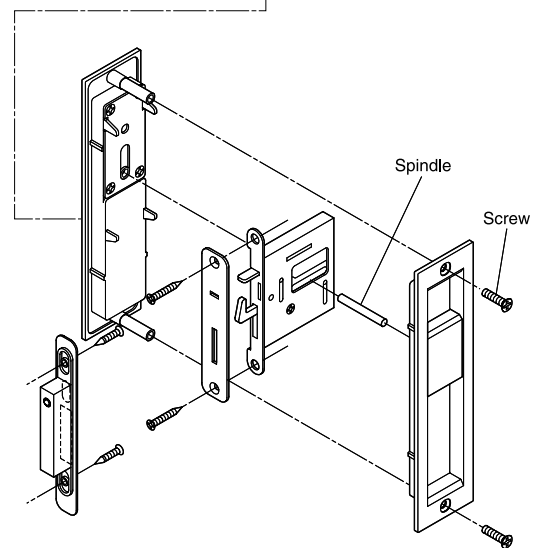


■ Parts Included

- Spindles Ø4×35, Ø4×39, Ø4×43
- Countersunk head tapping screw 3.5×25 (SUS) for strike & latch body
- Countersunk head screw M4×20, M4×25 (SUS) for latch face plates.


Item Name	Type	Weight (g)
HC-3051-PRV-NI	Privacy	531
HC-3051-IND-NI	Privacy w/ Indicator	535
HC-3051-CLD-NI	Cylinder lock	557
HC-3051-DSL-NI	Double Sided Slide	511

STAINLESS STEEL DRAWER SLIDES

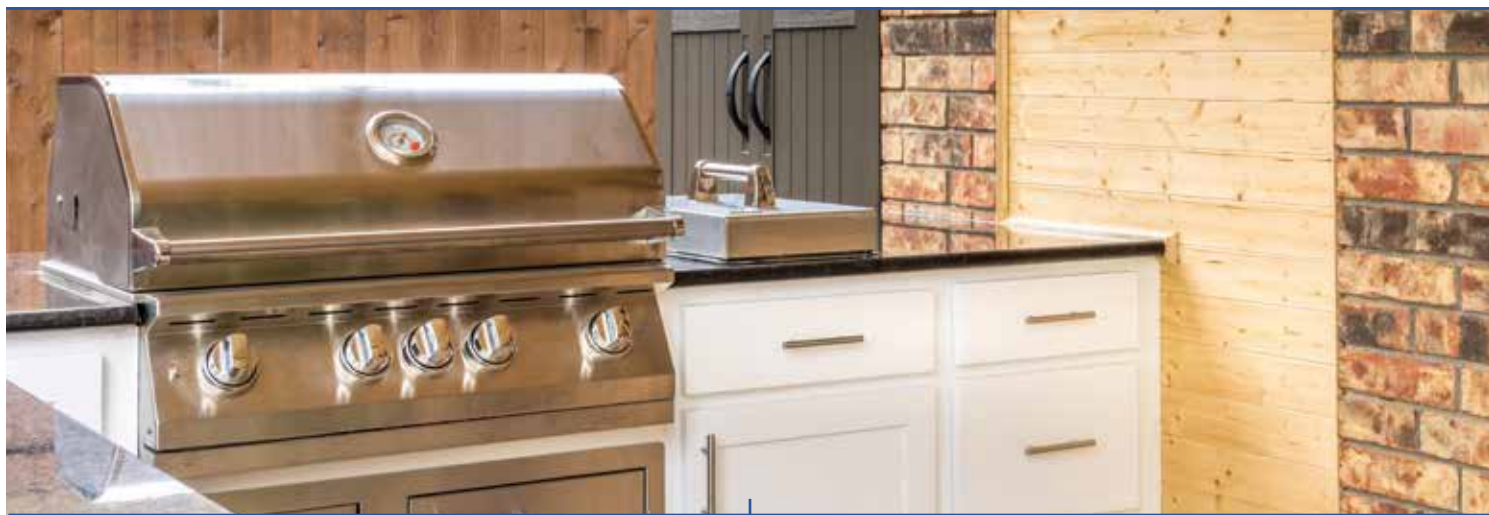

FULL EXT. SOFT CLOSE **ESR-SC4513**


- Soft close feature for smooth, silent movement.
- Full extension.
- Front disconnect, positive stop, sold in pairs.
- Hold-in detent 700 g-f (1.5 lb) max.
- Handed: specific left and right hand mounting.

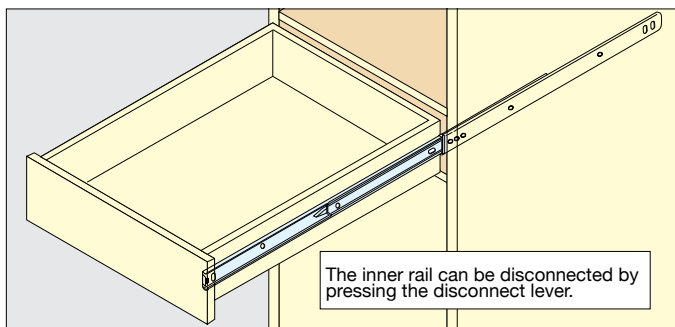

Item No.	Slide Length	Travel Length	Ld Rating
ESR-SC4513-16	15-3/4"	15-3/4"	82 lbs
ESR-SC4513-18	17-23/32"	17-23/32"	79 lbs
ESR-SC4513-20	19-11/16"	19-11/16"	77 lbs
ESR-SC4513-22	21-21/32"	21-21/32"	75 lbs
ESR-SC4513-24	23-5/8"	23-5/8"	73 lbs
ESR-SC4513-26	25-19/32"	25-19/32"	70 lbs
ESR-SC4513-28	27-9/16"	27-9/16"	68 lbs

FULL EXTENSION SLIDE **ESR-6**

- Full extension.
- Positive stop.
- Non-handed.
- Sold by each.

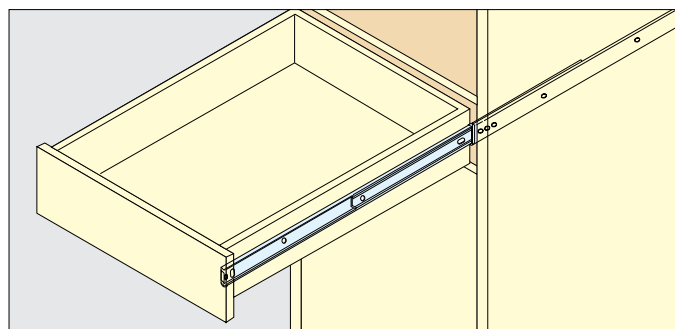

Item No.	Slide Length	Travel Length	Load Rating
ESR-6-12	12"	12-27/32"	132 lbs
ESR-6-14	14"	14-27/32"	130 lbs
ESR-6-16	16"	16-27/32"	126 lbs
ESR-6-18	18"	18-55/64"	123 lbs
ESR-6-20	20"	20-53/64"	117 lbs
ESR-6-22	22"	22-27/32"	112 lbs
ESR-6-24	24"	24-27/32"	108 lbs
ESR-6-26	26"	26-26/32"	104 lbs
ESR-6-28	28"	28-13/16"	99 lbs

STAINLESS STEEL FOLDING BRACKET with damper

EB-303/EP-D





- Automatically locks when flap is in open position.
- Press lever to release the lock.
- Hinges not required.
- Damper unit with a soft-closing feature which makes it smoother and safer.
- Durability tested 50,000 cycles (private).
- Also available without damper in 3 sizes: EB-200/EP, EB-303/EP, EB-317/EP

EB-303/EP-D

EB-303/EP-D-BL

Application Example

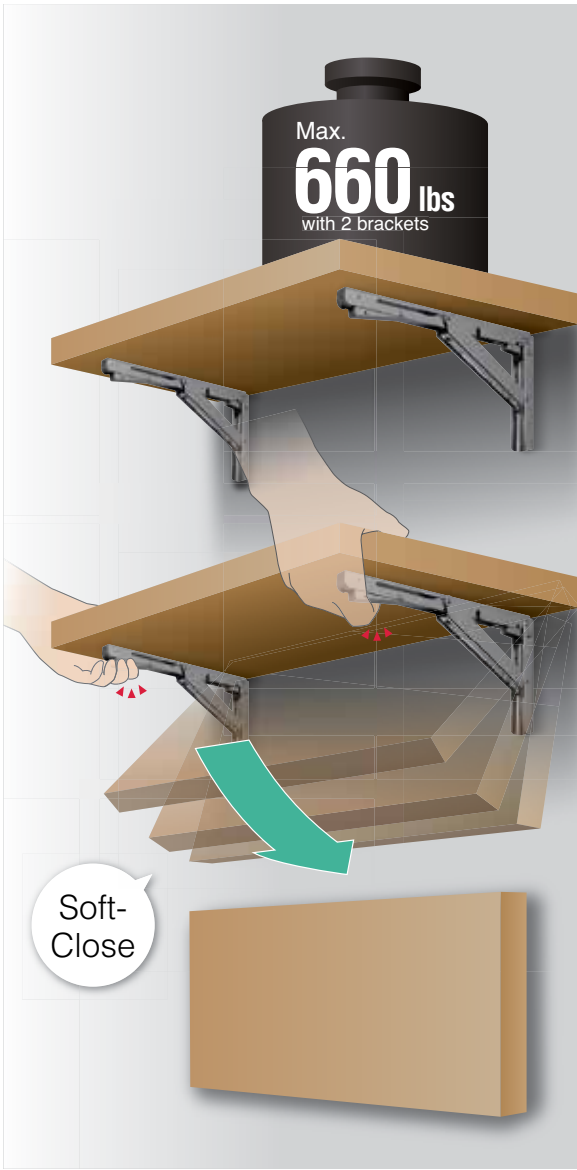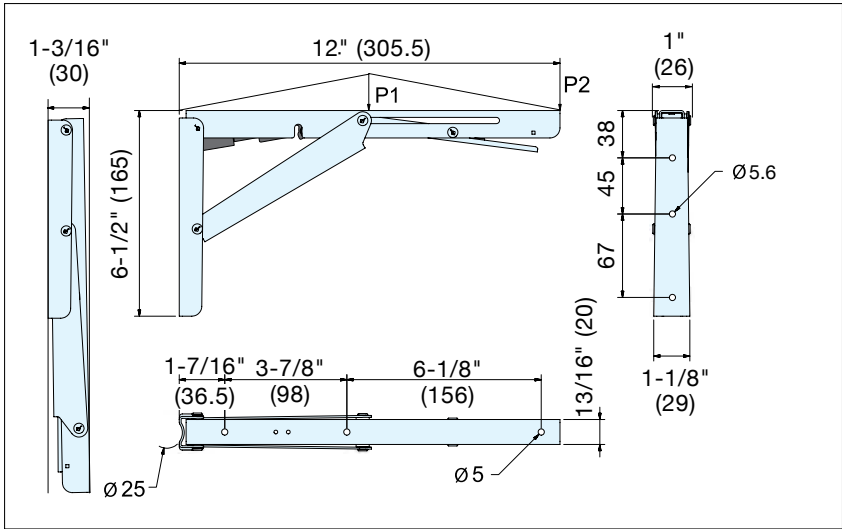

Item No.	Bracket Load Capacity P1	Bracket Load Capacity P2	Weight (g)	Carton (pcs)	Material
EB-303/EP-D	330 lbs/each	165 lbs/each	515	20	304 Stainless Steel
EB-303/EP-D-BL					

Fastmount® Panel Mounting Systems

Stratlock®
System

The Fastmount® Stratlock® System provides rapid installation of heavy panels to timber and steel or aluminum framework.

Scan for more
Fastmount® info

It is designed specifically for interior applications to reduce on-site installation time. The FEMALE CLIP (SL-SFA) installs onto side of framework and it is joint with the MALE CLIP (SL-M18). The new solid internal load chassis creates 4mm supported movement of the panel in any direction.

Item No.	Description	Load Capacity
SL-SFA	Female Clip	39.7 Lbs. per set
SL-M18	Male Clip	

A Pocket
Door SystemLike
No Other!

Closed

The new **ALT-ST Pocket Door System** is available in two sizes for four configurations (ALT-ST-15, ALT-ST-20) allowing for doors 19 ~ 44 lbs in weight.

The **ALT-ST Pocket Door System** also features 5-speed adjustable soft-close hinges, durable structure and it is very simple to install. The **ALT-ST Pocket Door System** features easy multi-level adjustments to prevent sagging.

Scan to see it
in action

Item No.	Load Capacity	Door Width Max.	Door Height
ALT-ST-15	19.8 ~ 33 lbs	23-5/8"	19-11/16 ~ 63"
ALT-ST-20	19.8 ~ 44 lbs		31-1/2 ~ 94-1/2

LAPCON DOOR DAMPER (Recessed Type)



LDD-V100



LDD-V100-NI-L shown.

Counter plate cover (Nickel/Dark brown)

[Door Hinge Side]

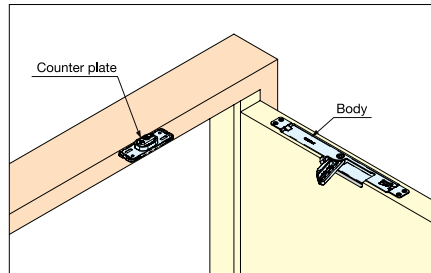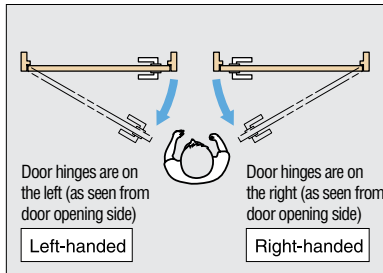


- Door damper unit for interior, swinging doors.
- Grips door at final 15° and softly, self-closes doors more gently compared to other door closers, putting less stress on the hinges.
- Heavy Duty: Holds up to 220 lbs doors (100 kg).
- "Invisible" design minimizes visibility of hardware.
- Recommended Door Specifications:
Thickness: min. 1-9/16" ~2-3/8"
Width: maximum 35-7/16"
Weight: 88~220 lbs
- Can be adjusted for door weight after installation.
- Counterplate position can be easily adjusted.
- Includes screws and paper template for installation.

FOR MORE DETAILS
General Catalog Pg. 204

Item No.	Finish/Color	Type
LDD-V100-DBR-R	Dark Brown	Right
LDD-V100-DBR-L		Left
LDD-V100-NI-R	Nickel	Right
LDD-V100-NI-L		Left

LAPCON DOOR DAMPER (Recessed Type)

LDD-V

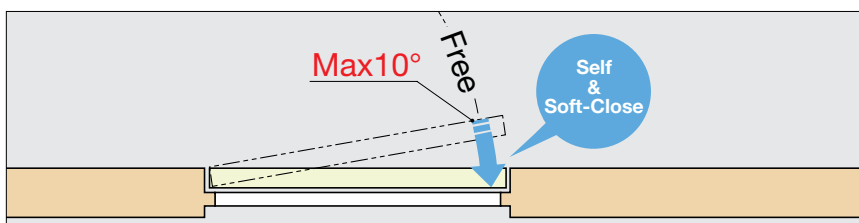

- Door damper unit for interior, swinging doors.
- Grips door at final 10° and softly, self-closes doors more gently compared to other door closers, putting less stress on the hinges.
- "Invisible" design minimizes visibility of hardware.
- Recommended Door Specifications:
Thickness: minimum 33 mm (1-5/16")
Width: maximum 914 mm (3' 0")
Weight: 15~40 kg (33~88 lbs)
- Can be adjusted for door weight after installation.
Counterplate position can be easily adjusted by removing cover and turning micro-adjustment screws.
- Includes screws and paper template for installation.

FOR MORE DETAILS
General Catalog Pg. 202

Item No.	Finish/Color	Type
LDD-V-R	Nickel/Grey	Right
LDD-V-L		Left

LAPCON DOOR DAMPER (Surface Mount Type)

LDD-S



LDD-S-R DBR
(Right - handed)

- Door damper unit for interior, swinging doors.
- Grips door at final 15° and softly, self-closes doors more gently compared to other door closers.
- Surface mounting allows hardware to be retrofitted.
- Recommended Door Specifications:
Width: Max. 914 mm (3' 0")
Weight: 15~40 kg (33~88 lbs)
- Can be adjusted for door weight after installation, damper function can also be switched off.
- Slim, unobtrusive design: damper unit is just 3/4" high, easily fitting most door frames.

FOR MORE DETAILS
General Catalog Pg. 200



- Available in the following colors:



White



Light Gray



Light Brown



Dark Brown

Item No.	Handing	Weight (kg)	Finishes
LDD-S-L	Left	0.55 (1.2 lbs)	White (WT), Light Grey (LGR), Light Brown (LBR), Dark Brown (DBR)
LDD-S-R	Right		



The Magnetic Touch

The mighty **ML-ZN80 Push-To-Open Door Latch** featuring a strong 11 lbs push force, ideal for large doors, and it features a magnet that allows tolerance with 1.5° swivel. The hidden mounting screw design offers a clean appearance and easy installation, available in two finishes.



Scan to see it
in action

The only Push-To-Open Door Latch of this category, available in the market.

Item No.	Mag. Force	Push Force	Materials	Finish/Color
ML-ZN80-WT	6.6 lbs	11 lbs	Zinc, Plastic, Stainless Steel	White
ML-ZN80-BL				Black



Scan to see
complete catalog



Pure Elegance

Similar to that of a fine handcrafted timepiece, precision is at the heart of the process to blend its gentle edges with an immaculate finish.

A process that requires the expertise of a jeweler. With its intricate design details bestowed upon marine grade stainless steel, Zwei L[®] delivers a simple, natural beauty that complements a variety of luxurious environments.

Zwei L[®]
by Sugatsune


Beyond Decorative!

Decorative Hooks can be the finishing touches to any environment. They add interesting details to simple and minimalistic styles, they also add personality and provide an opportunity to express unique personal style.

PXB-BN05-211/231

Our Forged Brass Double Hook is the perfect accent to any classical or contemporary style. Built from luxurious solid brass, forged to perfection and finished with a clear lacquer to prevent tarnishing.

Polished
Brass

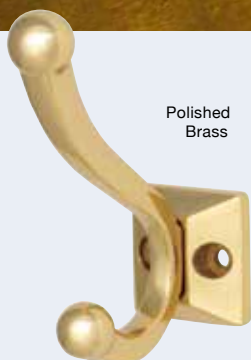

Blasted Metal

Satin Brass

Antique Brass

Matte Black

Aged and Forged Metals



Scan QR code to explore our full selection of decorative hooks



AGED CAST
PXB-AC05-111
Base: Brass



AGED BASE
PXB-AB05-101,111
Base: Brass



AGED SCREW
PXB-AS05
Base: Brass



PXB-BN05-211



PXB-WM05-111-211



PXB-GR05-211


Premium Materials



PREMIUM WOOD
PXB-WM-5-111
Base: Zinc Alloy, Steel
Arm: Birch, Walnut, Hornbeam



LEATHER CHIC
PXB-LE05-111
Silicone Rubber, Zinc Alloy

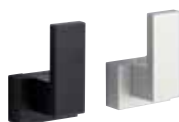

URBAN METAL
PXB-UM05-101
Aluminum Alloy



URBAN METAL QUEST
PXB-UM05101-Q1
Aluminum Alloy, Brass



NORDIC RUBBER
PXB-GN05-101
Silicone Rubber, Stainless Steel

Exceptionally Colorful



GOMU RANGER DOUBLE
PXB-GR05-211
Silicone Rubber,
304 Stainless Steel



GOMU RANGER SINGLE
PXB-GR05-111
Silicone Rubber,
304 Stainless Steel



RUBBER HOOK NORDIC
PXB-GN05-101
Silicone Rubber, Zinc Alloy

All our rubber hooks are reinforced with metal to provide a higher load capacity while staying safe in any environment and adding a colorful and playful accent to your room.



SLIDING DOOR HANDLES

FOR MORE DETAILS
General Catalog Pgs. 18 - 21

DSI-4251

■ Available in 6 sizes



Material	Finish
304 Stainless Steel	Satin, Black

DSI-4253

■ Available in 5 sizes



Material	Finish
304 Stainless Steel	Satin, Black

DSI-3250

■ Available in 4 sizes
 ■ Available in 3 finishes

Material	Finish
304 Stainless Steel or Brass	Black, Satin Antique Brass



Black

Satin

Antique Brass

DSI-4258

■ Available in 2 sizes



Material	Finish
304 Stainless Steel	Satin, Black

DSI-4257

■ Available in 2 sizes



Material	Finish
304 Stainless Steel	Satin, Black

DOOR STOPPERS

FOR MORE DETAILS
General Catalog Pgs. 206 - 209

SMDH


- Can be wall or floor mounted



Material	Finish
Polycarbonate	Brown, Ivory

DSD-03

- Wall mount type
- Available in 3 sizes

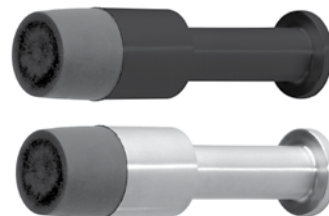

Material	Finish
304 Stainless Steel	Satin, Black



KMDH

- Can be wall or floor mounted



Material	Finish
Polycarbonate	Brown, Ivory

DSD-02

- Floor mount type
- Available in 2 sizes



Material	Finish
304 Stainless Steel	Satin, Black



SODH

- Can stop door at any angle



Material	Finish
Polyacetal, Rubber	Black, Brown

HT-32P

- Features clear acrylic bumper



Material	Finish
304 Stainless Steel	Satin

sugatsune.com



Sugatsune America
18101 Savarona Way,
Carson, CA 90746
Toll Free: 800-562-5267
sales@sugatsune.com



Sugatsune Canada, Inc.
3775 Boulevard du Tricentenaire,
Montréal, Québec H1B-5W3
Toll Free: 833-312-5267
support@sugatsune.ca
www.sugatsune.ca

LIT-KBIS-2023